


# A-P·TP·TM SERIES

## A-P ELASTOMER FEET SCREW MOUNTING TYPE

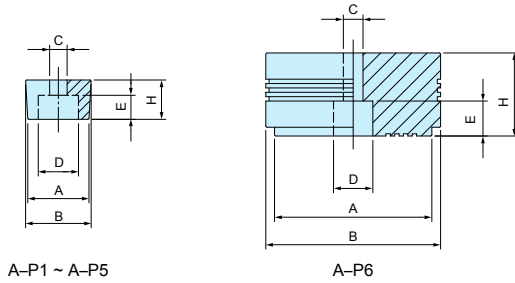

A-P1 ~ A-P5

A-P6

- No color bleeding.
- Screw mounting type (Screw is not included).

### Part no. / Dimensions

1pack = 10pcs

Part no.	A	B	H	C	D	E	Color	Material
A-P1	9.4	10.8	4	3.3	6.8	2	Black	Elastomer
A-P2	13.4	14.2	5.5	3	8	3.5	Black	Elastomer
A-P3	14	15	9	4	9.5	6	Black	Elastomer
A-P4	20	21	8	4	8.2	5	Black	Elastomer
A-P5	20	24	14	5.5	8.6	8.5	Black	Elastomer
A-P6	36	40	19	4.5	9	7.5	Black	Elastomer


## TP ELASTOMER FEET SNAP-IN TYPE




### Part no. / Dimensions

1pack = 10pcs

Part no.	A	B	H	Mounting hole $\Phi$	Panel thickness	Color	Material	Pin
TP-1	12	12.7	4.4	5	1.0-2.0	Black	Elastomer	PP
TP-2	15	15.7	4.4	5	1.0-2.0	Black	Elastomer	PP
TP-3	17.2	19.2	7.9	8	0.8-1.2	Black	Elastomer	PP
TP-4	18	20	10	8	1.0-2.5	Black	Elastomer	PP
TP-5	19.8	20.8	6.4	8	1.0-2.5	Black	Elastomer	PP
TP-6	19.5	23.7	13.7	8	1.0-2.5	Black	Elastomer	PP
TP-7	26.5	29.4	15	10	1.0-3.5	Black	Elastomer	PP

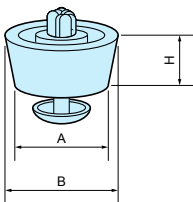

## TM PLASTIC FEET

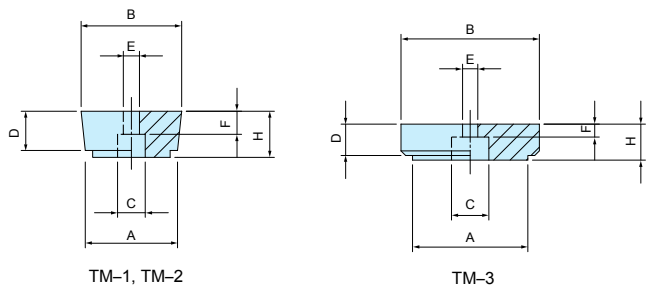

TM-1, TM-2

TM-3

- With elastomeric foam pad on the bottom of plastic feet.

### Part no. / Dimensions

1pack = 10pcs

Part no.	A	B	C	D	E	F	H	Color	Material	Pad
TM-1	20	21.8	7.2	8.5	3.5	4.5	10	Black	ABS (UL94HB)	EVA
TM-2	20	21.8	7.2	13.5	3.5	4.5	15	Black	ABS (UL94HB)	EVA
TM-3	25	30	8.1	6.8	3.3	2.7	7.8	Black	ABS (UL94HB)	EVA