


# SG·NG SERIES

## SG CLOSED GROMMET

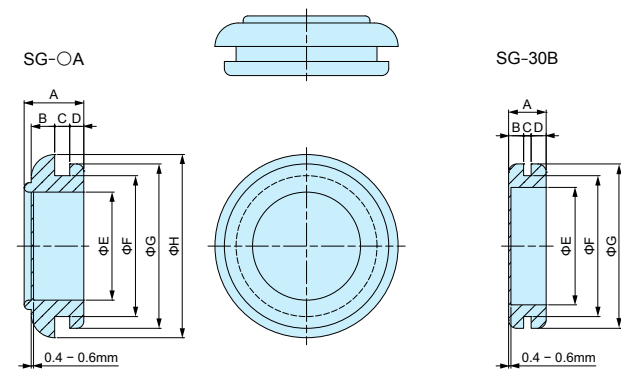

### Components


Material	Color
Rubber	Black

### Part no. / Dimensions

1pack = 10pcs

Part no.	A	B	C	D	E	F	G	H
SG- 9A	8.5	3.5	2.3	2	4.5	9	13	16
12A	6.3	2.5	1.6	1.5	7	12	16	19
14A	8	2.7	2.3	2	9	14	18	21
16A	8.1	3.5	1.6	2	11	16	20	23
18A	8.8	3.5	2.3	2	13	18	22	25
20A	9.1	4	1.6	2.5	15	20	24	27
22A	9.8	4	2.3	2.5	17	22	26	29
24A	11.3	5	2.3	3	19	24	28	31
26A	12.2	5	3.2	3	19	26	31	35
28A	11.8	5	2.3	3	21	28	33	37
30A	12.7	5	3.2	3	23	30	35	39
30B	8	3.2	1.6	3.2	25	30	35	-
32A	11.8	5	2.3	3	25	32	37	41
34A	12.7	5	3.2	3	27	34	39	43
36A	13.8	6	2.3	4	28	36	42	45
38A	14.7	6	3.2	4	30	38	44	48
42A	14.7	6	3.2	4	34	42	48	52

## NG GROMMET

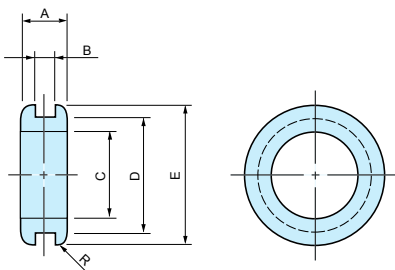

### Components

Material	Color
Rubber	Black

### Part no. / Dimensions

1pack = 10pcs

Part no.	A	B	C	D	E	R
NG-79-1	3.7	1.2	3.5	6	9	0.6
79-A1	4	1	5	8	11	0.6
79-A	4.5	1.5	5	8	11	0.6
79-A2	5	2	5	8	11	0.6
79-B	6	3	5	8	11	0.6
79-C	4.5	1.5	7	10	13	0.6
79-D	6	3	7	10	13	0.6
79-E	4.5	1.5	9	12	15	0.6
79-F	6	3	9	12	15	0.6
79-G	5.5	1.5	11	15	19	1
79-H	7	3	11	15	19	1
79-J	5.5	1.5	13	17	21	1
79-K	7	3	13	17	21	1
79-L	5.5	1.5	15	19	23	1
79-M	7	3	15	19	23	1
79-N	6.5	1.5	20	25	30	1.2
79-O	8	3	20	25	30	1.2
79-P	6.5	1.5	25	30	35	1.2
79-Q	8	3	25	30	35	1.2
79-R	7.5	1.5	30	36	42	1.2
79-S	9	3	30	36	42	1.2
74	4	1	3	5	7	1
742	5	2	3	5	7	1