


Accessories (Optional parts)

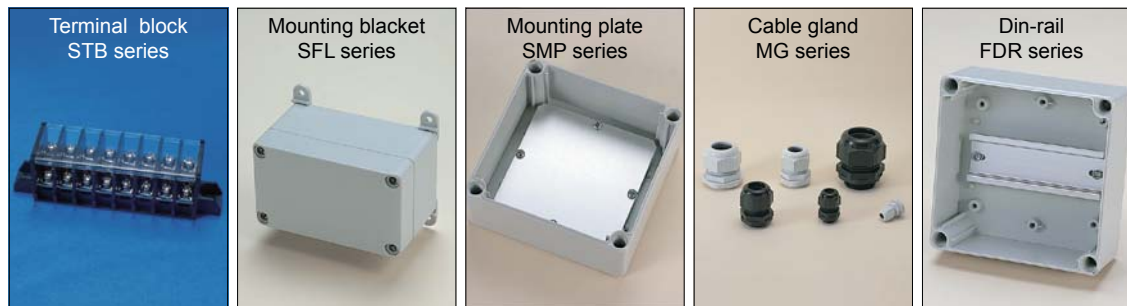

Color Type

Color code	Cover	Body
G	White gray	White gray
T	Transparence	White gray

Part no. / Dimensions

• Please suffix color code at the end of part number □ when ordering SPCM series.

Part no.	W	D	H	Weight (g)
SPCM081306□	75	125	60	159
SPCM081308□	75	125	75	208
SPCM081310□	75	125	100	275
SPCM081313□	75	125	125	299
SPCM101006□	100	100	60	164
SPCM131306□	125	125	60	243
SPCM131308□	125	125	75	292
SPCM131310□	125	125	100	366
SPCM131313□	125	125	125	401
SPCM131806□	125	175	60	294
SPCM131808□	125	175	75	373
SPCM131810□	125	175	100	450
SPCM131813□	125	175	125	519
SPCM131815□	125	175	150	588
SPCM181808□	175	175	75	468
SPCM181810□	175	175	100	569
SPCM181813□	175	175	125	639
SPCM181815□	175	175	150	723
SPCM182508□	175	250	75	633
SPCM182510□	175	250	100	745
SPCM182515□	175	250	150	946

SPCM Dimensions

• CAD data is downloadable from our web.

Part no.	H	a	b
SPCM081306□	60	10	45.5
SPCM081308□	75	25	60.5
SPCM081310□	100	50	85.5
SPCM081313□	125	75	110.5

