

The thin tube tip blows air directly.
The ergonomic design for easy use, and the adjustment of the air volume can also be delicately controlled by the grip condition of the large lever.

Maximum Pressure
1.6MPa



AIR BLOW GUN

Models	Type	Dimensions (mm)					Remarks	Qty./ Carton (Generally)	Weight (g)
		A	L	H	Nose inner diameter	Nose outer diameter			
AG-101	I	95	250	133	4	6	With plug	3	161
AG-301	II	300	455	133	4	6	With plug	1	186
AG-501	II	500	655	133	4	6	With plug	1	211


※ Maximum Pressure 1.6MPa (16kgf/cm²,16bar)
※ Operating temp. range- 20-80°C
※ The coupler screw diameter R1/4 (PT1/4)

• For air compressors

Option

Models	Descriptions
AGN-101	Nose for air blow gun (Length 95mm and standard accessory)
AGN-301	Nose for air blow gun (Length 300mm)
AGN-501	Nose for air blow gun (Length 500mm)
TAGR-01	Rubber nose for air blow gun
TAGV-01	Venturi nose for air blow gun
TAGV-02	Venturi nose for air blow gun
TAGS-01	Shield nose for air blow gun
TAGP-01	Plug for air blow gun

※ Please see P485 for details.

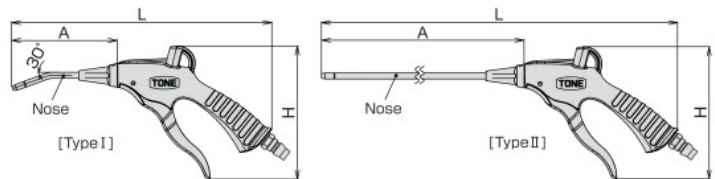

CAUTION

- Do not clean / remove contaminants, such as chip powders, chemical soluble etc.
- Do not point nose-top to face.



STAINLESS TOOL
TITANIUM TOOL

TOOL SET

TOOL CASE

SOCKET
WRENCH

HEXAGON
WRENCH

T-TYPE
WRENCH

SPANNER
OFFSET WRENCH

SCREWDRIVER

BIT

ADJUSTABLE
WRENCH
PLIERS

SPECIALIZED
CAR EQUIPMENT

CYCLE TOOL

LED LIGHT

OTHER HAND
TOOLS

TORQUE
WRENCH

AIR TOOL