

AIR IMPACT WRENCH, STRAIGHT TYPE

Max. torque output 2,100N·m

Models **AIS8330L**



Tire replacement of buses and trucks or maintenance of heavy equipment and construction machinery
 Light & powerful.
 Reliable twin hammer mechanism delivers maximum power while increasing reliability.
 Excellent stability with side grip.
 Easy operation flip lever forward and reverse in 4 positions.
 Output power management is also possible by adjusting pressing strength.
 Long anvil type, easy to handle .



Long anvil




AIS8330L



- ① Rotation direction switching lever
- ② Output adjustment dial



Twin hammer

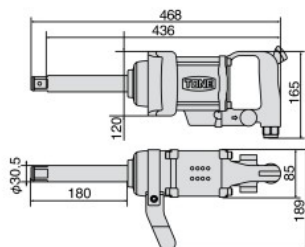

OPTION

Impact socket (BNV-○○) P.239

AIR IMPACT WRENCH, STRAIGHT TYPE

Max. torque output 3,390N·m

Models **AIS8500L**



Tire replacement of buses and trucks or maintenance of heavy equipment and construction machinery.
 Reliable pinless hammer mechanism, light but good in durability.
 Excellent stability with side grip.
 Easy operation flip lever forward and reverse in 4 positions.
 Output power management is also possible by adjusting pressing strength.



Long anvil




AIS8500L



- ① Rotation direction switching lever
- ② Output adjustment dial



Pinless hammer

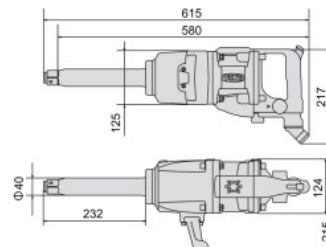

OPTION

Impact socket (BNV-○○) P.239

WARNING

- Please read instruction manual carefully before use.
- Use goggles and protecting devices.

Accessories

Models	Plug	Oil	Side grip (Metal fittings and bolt are included)	L-type hex wrench	Instruction manual
AI6300	R3/8 (PT3/8) 1	1	—	—	○
AIS8330S	R1/2 (PT1/2) 1	1	○	6mm 1	○
AIS8330L	R1/2 (PT1/2) 1	1	○	6mm 1	○
AIS8500L	R1/2 (PT1/2) 1	1	○	5mm 1	○



CAUTION

- Tightening torque may differ by conditions.



STAINLESS TOOL
TITANIUM TOOL

TOOL SET

TOOL CASE

SOCKET
WRENCH

HEXAGON
WRENCH

T-TYPE
WRENCH

SPANNER
OFFSET WRENCH

SCREWDRIVER

BIT

ADJUSTABLE
WRENCH
PLIERS

SPECIALIZED
CAR EQUIPMENT

CYCLE TOOL

LED LIGHT

OTHER HAND
TOOLS

TORQUE
WRENCH

AIR TOOL