



 


## Type Index Classification Index

## Level Classification


<p><b>Aluminum Level/Scaffold Assembly Level</b> (with shackle for temporary workers)</p>  <p style="text-align: right;">p. 1-2076 to 2093</p>	<p><b>Iron Level</b></p>  <p style="text-align: right;">p. 1-2094</p>
<p><b>Plastic Level</b></p>  <p style="text-align: right;">p. 1-2095 to 2097</p>	<p><b>Acrylic Level (transparent type)</b></p>  <p style="text-align: right;">p. 1-2097 to 2100</p>
<p><b>Digital Level</b></p>  <p style="text-align: right;">p. 1-2101 to 2104</p>	



**Stock**  
38,650 Items

## Aluminum Level

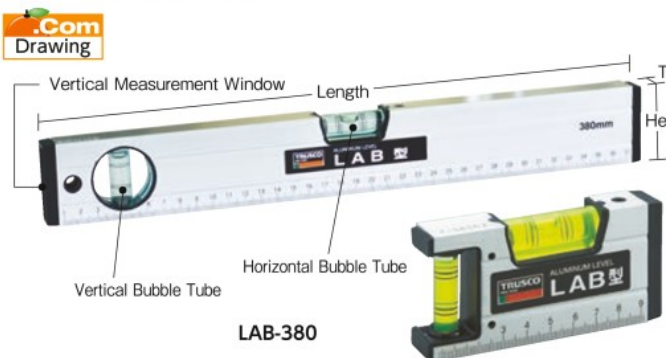

- Features**
- Platypus type bubble tube magnified by a lens for larger view. (horizontal)
  - Box type frame/with scale attachment.
  - Luminescent sheet, precision retention with shock-resistant cover.
  - With 4 line scale.
  - With vertical bubble tube.
  - Adjustment method: Adjust horizontal/vertical precision using torx screwdriver T10. (LAB-100, LABM-100 vertical excluded)
- Use Specs**
- For horizontal/vertical measurement.
  - Precision: within  $\pm 1.5\text{mm/m} = \pm 0.0859^\circ$
  - Sensitivity:  $0.5\text{mm/m} = 0.0286^\circ$
- Materials**
- Main body: Aluminum
  - Bubble Tube: Acrylic Plastic (PMMA)
- Origin**
- Japan

**LAB-100/LABM-100**  
(vertical precision can not be control)

**With a magnet** Features • Convenient for steel work with iron frame magnets measurement.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
229-6977	LAB-100	¥2,296	¥2,480	100 x 50.5 x 19	None	5	85
229-6993	LAB-150	¥2,407	¥2,600	150 x 50.5 x 19	None	5	140
229-7019	LAB-230	¥2,546	¥2,750	230 x 50.5 x 19	None	5	192
229-7035	LAB-300	¥2,703	¥2,920	300 x 50.5 x 19	None	5	243
229-7051	LAB-380	¥2,851	¥3,080	380 x 50.5 x 19	None	5	296
229-7078	LAB-450	¥3,055	¥3,300	450 x 50.5 x 19	None	5	348
229-7094	LAB-600	¥3,518	¥3,800	600 x 50.5 x 19	None	5	453
229-7116	LAB-750	¥4,046	¥4,370	750 x 50.5 x 19	None	1	557
229-7132	LAB-900	¥4,573	¥4,940	900 x 50.5 x 19	None	1	661

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
229-6985	LABM-100	¥3,305	¥3,570	100 x 50.5 x 19	1 Location	5	115
229-7001	LABM-150	¥3,434	¥3,710	150 x 50.5 x 19	1 Location	5	170
229-7027	LABM-230	¥3,601	¥3,890	230 x 50.5 x 19	1 Location	5	222
229-7043	LABM-300	¥4,249	¥4,590	300 x 50.5 x 19	2 Locations	5	303
229-7060	LABM-380	¥4,416	¥4,770	380 x 50.5 x 19	2 Locations	5	356
229-7086	LABM-450	¥4,647	¥5,020	450 x 50.5 x 19	2 Locations	5	408
229-7108	LABM-600	¥5,101	¥5,510	600 x 50.5 x 19	2 Locations	5	513
229-7124	LABM-750	¥5,647	¥6,100	750 x 50.5 x 19	2 Locations	1	617
229-7141	LABM-900	¥6,128	¥6,620	900 x 50.5 x 19	2 Locations	1	721


Contact us: 0120-509-849 <http://www.orange-book.com/>



**Stock**  
38,650 Items

## Aluminum Level

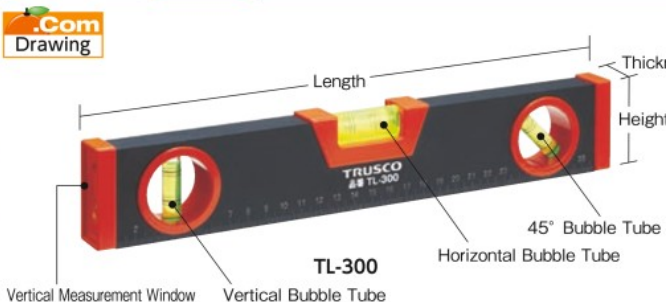

- Features**
- Platypus type bubble tube magnified by a lens for larger view. (horizontal)
  - It can measure 45°.
  - Box type frame/with scale attachment.
  - Since the edge cover is flat, measurement is possible while it firmly attaches on a wall, etc.
- Use Specs**
- For inclination measurement.
  - Precision: within  $\pm 1.5\text{mm/m} = \pm 0.0859^\circ$
  - Sensitivity:  $0.5\text{mm/m} = 0.0286^\circ$
- Materials**
- Main body: Aluminum
  - Bubble Tube: Acrylic Plastic (PMMA)
- Origin**
- Japan

**With a magnet** Features • Convenient for steel work with iron frame magnets measurement.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
415-8156	TL-230	¥2,481	¥2,680	230 x 50.5 x 19	None	5	180
415-8164	TL-300	¥2,647	¥2,860	300 x 50.5 x 19	None	5	220
415-8172	TL-380	¥2,740	¥2,960	380 x 50.5 x 19	None	5	270
415-8181	TL-450	¥2,944	¥3,180	450 x 50.5 x 19	None	5	300
415-8199	TL-600	¥3,315	¥3,580	600 x 50.5 x 19	None	5	400
415-8202	TL-900	¥4,351	¥4,700	900 x 50.5 x 19	None	1	580

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
415-8211	TL-230M	¥3,425	¥3,700	230 x 50.5 x 19	1 Location	5	210
415-8245	TL-300M	¥4,073	¥4,400	300 x 50.5 x 19	2 Locations	5	280
415-8229	TL-380M	¥4,258	¥4,600	380 x 50.5 x 19	2 Locations	5	330
415-8237	TL-450M	¥4,443	¥4,800	450 x 50.5 x 19	2 Locations	5	360
415-8253	TL-600M	¥4,906	¥5,300	600 x 50.5 x 19	2 Locations	5	460
415-8261	TL-900M	¥5,925	¥6,400	900 x 50.5 x 19	2 Locations	1	640

Contact us: 0120-509-849 <http://www.orange-book.com/>