


Prices displayed include 8% tax.



Stock 38,650 Items

Aluminum Level

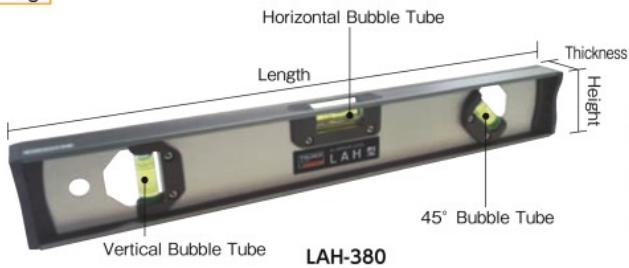

- Features**
- Standard product for I beam type frame. Easy viewing with large diameter bubble tube.
 - With 4 line scale.
 - 45° is measurable.
 - (150mm is without bubble tube for 45° measurement)
 - With V-groove.
 - With vertical bubble tube.
 - For horizontal/vertical, and 45° measurements.
- Use**
- Specs**
- Precision: within $\pm 1.5\text{mm/m} = \pm 0.0859^\circ$
 - Sensitivity: $0.5\text{mm/m} = 0.0286^\circ$
- Materials**
- Main body: Aluminum
 - Bubble Tube: Acrylic Plastic (PMMA)
- Origin**
- Japan

With a magnet Features • Convenient for steel work with iron frame magnets measurement.

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
229-6471	LAH-150	¥1,833	¥1,980	150 x 56 x 26	None	10	160
229-6497	LAH-230	¥1,944	¥2,100	230 x 56 x 26	None	10	240
229-6519	LAH-300	¥2,138	¥2,310	300 x 56 x 26	None	10	320
229-6535	LAH-380	¥2,343	¥2,530	380 x 56 x 26	None	10	390
229-6551	LAH-450	¥2,555	¥2,760	450 x 56 x 26	None	10	450
229-6578	LAH-600	¥2,916	¥3,150	600 x 56 x 26	None	10	570
229-6594	LAH-750	¥3,574	¥3,860	750 x 56 x 26	None	1	680
229-6616	LAH-900	¥4,370	¥4,720	900 x 56 x 26	None	1	820

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
229-6489	LAHM-150	¥3,277	¥3,540	150 x 56 x 26	1 Location	10	200
229-6501	LAHM-230	¥3,398	¥3,670	230 x 56 x 26	1 Location	10	280
229-6527	LAHM-300	¥3,619	¥3,910	300 x 56 x 26	2 Locations	10	400
229-6543	LAHM-380	¥3,795	¥4,100	380 x 56 x 26	2 Locations	10	470
229-6560	LAHM-450	¥4,008	¥4,330	450 x 56 x 26	2 Locations	10	530
229-6586	LAHM-600	¥4,370	¥4,720	600 x 56 x 26	2 Locations	10	650
229-6608	LAHM-750	¥4,962	¥5,360	750 x 56 x 26	2 Locations	1	760
229-6624	LAHM-900	¥5,757	¥6,220	900 x 56 x 26	2 Locations	1	900

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 107 Items

Aluminum Level

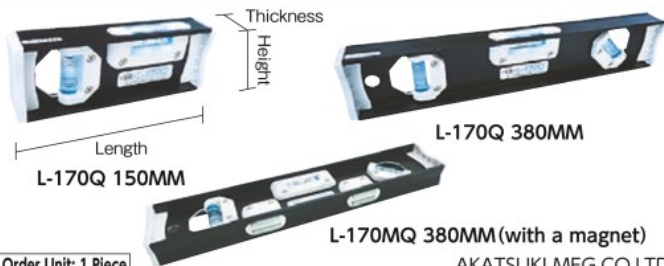

- Features**
- Professional aluminum I-beam level.
 - Robust with the edge cover.
 - Large easy-to-see vials.
 - For horizontal/vertical, and 45° measurements.
- Use**
- Specs**
- Precision: within $\pm 1.5\text{mm/m} = \pm 0.0859^\circ$
 - Sensitivity: $0.5\text{mm/m} = 0.0286^\circ$
- Materials**
- Main body: Aluminum
 - Bubble Tube: Acrylic Plastic (PMMA)
- Origin**
- Japan

With a magnet Features • Convenient for steel work with iron frame magnets measurement.

Order Unit: 1 Piece AKATSUKI MFG.CO.LTD.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
474-5515	L-170Q 150MM	¥1,833	¥2,375	150 x 56 x 26	None	10	125
474-5523	L-170Q 230MM	¥2,006	¥2,600	230 x 56 x 26	None	10	180
474-5531	L-170Q 300MM	¥2,276	¥2,950	300 x 56 x 26	None	10	235
474-5540	L-170Q 380MM	¥2,527	¥3,275	380 x 56 x 26	None	10	290
474-5558	L-170Q 450MM	¥2,661	¥3,450	450 x 56 x 26	None	10	345
474-5566	L-170Q 600MM	¥3,047	¥3,950	600 x 56 x 26	None	10	455

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
474-5451	L-170MQ 150MM	¥2,044	¥2,650	150 x 56 x 26	1 Place	10	185
474-5469	L-170MQ 230MM	¥2,314	¥3,000	230 x 56 x 26	1 Place	10	240
474-5477	L-170MQ 300MM	¥2,643	¥3,425	300 x 56 x 26	2 Places	10	295
474-5485	L-170MQ 380MM	¥2,952	¥3,825	380 x 56 x 26	2 Places	10	350
474-5493	L-170MQ 450MM	¥2,991	¥3,875	450 x 56 x 26	2 Places	10	405
474-5507	L-170MQ 600MM	¥3,568	¥4,625	600 x 56 x 26	2 Places	10	515

Contact us: 0773-42-1001 <http://www.kod-level.co.jp/>



Stock 107 Items

Box Type Aluminum Level

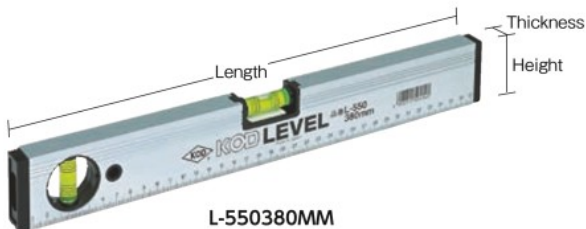

- Features**
- Equipped with the easy-to-see large vials.
 - With a window for vertical measurement that is convenient for temporary framing carpenters.
- Use**
- For carpenter works, installation of machines, drainage/electrical construction, or other overall works.
- Specs**
- Precision: within $\pm 1.5\text{mm/m} = \pm 0.0859^\circ$
 - Sensitivity: $0.5\text{mm/m} = 0.0286^\circ$
- Materials**
- Main body: Aluminum
 - Bubble Tube: Acrylic Plastic (PMMA)
- Origin**
- Japan

With a magnet Features • Convenient for steel work with iron frame magnets measurement.

Order Unit: 1 Piece AKATSUKI MFG.CO.LTD.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
405-0606	L-550150MM	¥1,317	¥1,950	150 x 50.5 x 19	None	5	140
405-0614	L-550230MM	¥1,425	¥2,110	230 x 50.5 x 19	None	5	192
405-0622	L-550300MM	¥1,491	¥2,210	300 x 50.5 x 19	None	5	243
405-0631	L-550380MM	¥1,634	¥2,420	380 x 50.5 x 19	None	5	296
405-0649	L-550450MM	¥1,701	¥2,520	450 x 50.5 x 19	None	5	348
405-0657	L-550600MM	¥1,896	¥2,810	600 x 50.5 x 19	None	5	453
405-0665	L-550900MM	¥2,754	¥4,080	900 x 50.5 x 19	None	1	661
405-0592	L-5501200MM	¥3,159	¥4,680	1200 x 50.5 x 19	None	1	869

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
405-0681	L-550M150MM	¥1,722	¥2,550	150 x 50.5 x 19	1 Location	5	170
405-0690	L-550M230MM	¥1,823	¥2,700	230 x 50.5 x 19	1 Location	5	222
405-0703	L-550M300MM	¥2,039	¥3,020	300 x 50.5 x 19	2 Locations	5	303
405-0711	L-550M380MM	¥2,174	¥3,220	380 x 50.5 x 19	2 Locations	5	356
405-0720	L-550M450MM	¥2,262	¥3,350	450 x 50.5 x 19	2 Locations	5	408
405-0738	L-550M600MM	¥2,457	¥3,640	600 x 50.5 x 19	2 Locations	5	513
405-0746	L-550M900MM	¥3,335	¥4,940	900 x 50.5 x 19	2 Locations	1	721
405-0673	L-550M1200MM	¥3,740	¥5,540	1200 x 50.5 x 19	2 Locations	1	929

Contact us: 0773-42-1001 <http://www.kod-level.co.jp/>