

# Sarae Nut Dies

The number next to the logo mark indicates items in stock for each brand.

Threading Tools

Spiral Fluted Taps

Point Taps

Roll Taps

Hand Taps

Hexagonal Shank Tapping Drills

Tap Holders

Taps for Pipe

Thread Mills for Machining Center

Dies

Thread Repair Tools

Tap and Bolt Burr Removing Tools


Screw

68700 items in stock  
11 cutting tool manufacturers



Stock 38,650 Items

## Hexagonal head sarae nut dice (PT Screw) for Gas Pipe

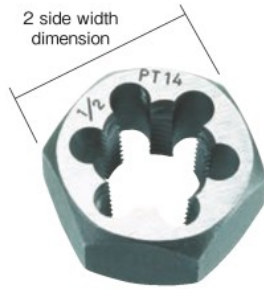

TD6-1/2PT14

**Warning**

- Hexagon sarae nut die, unlike round die, does not have adjustment screw to adjust size. Therefore, hexagon sarae nut die may not fit depending on the screw precision.
- Cannot be used for stainless steel screw.

- Features**
- Used to clean bolt and screw.
  - You can work with an adjustable wrench.
  - Substitute for round die when repairing ridge.
- Use**
- For repairing PT (taper) ridge.
- Materials**
- Low-Alloy Steel (SKS)
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Dimension	Number of Ridges	Thickness (mm)	2 Side Width Dimension (mm)	SPQ (piece)	Weight (g)
352-0790	TD6-1/8PT28	¥ 2,543	¥ 3,140	1/8	28	9.5	19.1	1	15
352-0731	TD6-1/4PT19	¥ 3,353	¥ 4,140	1/4	19	12.7	27.0	1	37
352-0871	TD6-3/8PT19	¥ 4,034	¥ 4,980	3/8	19	15.8	32.0	1	62
352-0706	TD6-1/2PT14	¥ 5,168	¥ 6,380	1/2	14	19.0	36.5	1	84
432-9201	TD6-5/8PT14	¥ 7,558	¥ 9,330	5/8	14	22.2	41.0	1	150
352-0846	TD6-3/4PT14	¥ 8,983	¥ 11,090	3/4	14	25.4	46.0	1	180
432-9210	TD6-7/8PT14	¥ 12,069	¥ 14,900	7/8	14	25.4	50.0	1	230
352-0897	TD6-1PT11	¥ 13,333	¥ 16,460	1	11	25.4	55.5	1	263

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

## Hexagon Sarae Nut Die for Gas Pipe (PS thread)

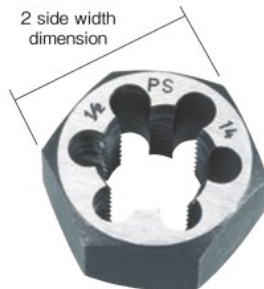

TD6-1/2PS14

**Warning**

- Hexagon sarae nut die, unlike round die, does not have adjustment screw to adjust size. Therefore, hexagon sarae nut die may not fit depending on the screw precision.
- Cannot be used for stainless steel screw.

- Features**
- Used to clean bolt and screw.
  - You can work with an adjustable wrench.
  - Substitute for round die when repairing ridge.
- Use**
- For repairing PS (straight) ridge
- Materials**
- Low-Alloy Steel (SKS)
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Dimension	Number of Ridges	Thickness (mm)	2 Side Width Dimension (mm)	SPQ (piece)	Weight (g)
352-0781	TD6-1/8PS28	¥ 2,236	¥ 2,760	1/8	28	9.5	19.1	1	15
352-0722	TD6-1/4PS19	¥ 3,054	¥ 3,770	1/4	19	12.7	27.0	1	37
352-0862	TD6-3/8PS19	¥ 3,888	¥ 4,800	3/8	19	15.8	32.0	1	62
352-0714	TD6-1/2PS14	¥ 4,649	¥ 5,740	1/2	14	19.0	36.5	1	84
432-9228	TD6-5/8PS14	¥ 6,399	¥ 7,900	5/8	14	22.2	41.0	1	150
352-0765	TD6-3/4PS14	¥ 7,889	¥ 9,740	3/4	14	25.4	46.0	1	180
432-9236	TD6-7/8PS14	¥ 11,016	¥ 13,600	7/8	14	25.4	50.0	1	230
352-0811	TD6-1PS11	¥ 12,069	¥ 14,900	1	11	25.4	55.5	1	263

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

## Hexagon Sarae Nut Die (PF thread)



TD6-3/8PF19

**Warning**

- Hexagon sarae nut die, unlike round die, does not have adjustment screw to adjust size. Therefore, hexagon sarae nut die may not fit depending on the screw precision.
- Cannot be used for stainless steel screw.

- Features**
- Used to clean bolt and screw.
  - You can work with an adjustable wrench.
  - Substitute for round die when repairing ridge.
- Use**
- For repairing PF (straight) ridge
- Materials**
- Low-Alloy Steel (SKS)
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Dimension	Number of Ridges	Thickness (mm)	2 Side Width Dimension (mm)	SPQ (piece)	Weight (g)
432-9287	TD6-1/8PF28	¥ 2,520	¥ 3,110	1/8	28	9.5	19.1	1	15
432-9295	TD6-1/4PF19	¥ 3,467	¥ 4,280	1/4	19	12.7	27.0	1	40
432-9309	TD6-3/8PF19	¥ 4,406	¥ 5,440	3/8	19	15.8	32.0	1	70
432-9317	TD6-1/2PF14	¥ 5,249	¥ 6,480	1/2	14	19.0	36.5	1	90
432-9325	TD6-5/8PF14	¥ 6,399	¥ 7,900	5/8	14	22.2	41.0	1	150
432-9333	TD6-3/4PF14	¥ 8,910	¥ 11,000	3/4	14	25.4	46.0	1	180
432-9341	TD6-7/8PF14	¥ 11,016	¥ 13,600	7/8	14	25.4	50.0	1	230
432-9350	TD6-1PF11	¥ 13,640	¥ 16,840	1	11	25.4	55.5	1	270

Contact us:0120-509-849 <http://www.orange-book.com/>