

Long Calipers

The number next to the logo mark indicates items in stock for each brand.

MITUTOYO
Mitutoyo Stock 466 Items

Long Type Digimatic Caliper

Repairing OK **Calibration OK**
Approx. 2 Weeks



- Features**
- Since ABS (absolute) scale with absolute origin is built in, zero set for each power on is unnecessary. Because over speed error never occurs, reliability also improves.
 - CE standard product.
- Use**
- For step measurement, inside measurement, outside measurement, etc.
- Specs**
- Power supply: Button type silver oxide battery (SR44) x 1 (accessory)
 - With measurement data output terminal
- Origin**
- Japan


SPQ: 1 Piece

Micrometers

Example

Order Unit: 1 Piece

MITUTOYO CORPORATION

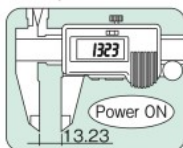

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Outer Side Jaws (mm)	Interior Jaws (mm)	Depth Bar	Weight (kg)
105-2195	CD-45C	¥ 81,000	¥ 80,000	500-500-10	0 to 450	±0.05	0.01	90	38	None	1.17
105-2209	CD-60C	¥ 84,138	¥ 83,100	500-501-10	0 to 600	±0.05	0.01	90	38	None	1.35
105-2217	CD-100C	¥ 129,903	¥ 128,300	500-502-10	0 to 1000	±0.07	0.01	130	50	None	3.30

Contact us: 050-3786-3214 <http://www.mitutoyo.co.jp/>

Micrometer Stands

Hole Tests

Micrometer Heads

MITUTOYO
Mitutoyo Stock 466 Items

Coolant Proof Carbon Digimatic Caliper

Repairing OK **Calibration OK**
Approx. 2 Weeks



- Features**
- CFPR (carbon fiber reinforced plastic) is used for the beam part and makes the caliper lightweight.
 - With auto power ON/OFF function.
- Use**
- For outside and inside measurement.
- Specs**
- Protection grade: IP66
 - Power supply: Button type silver oxide battery (SR44) x 1 (accessory)
 - With measurement data output terminal
- Origin**
- Japan

SPQ: 1 Piece

Calipers

Height Gauges

Depth Gauges

Dial Indicators

Thickness Gauges

Bore Gauges

Order Unit: 1 Piece

MITUTOYO CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Jaw Dimension (mm)	Depth Bar	Weight (kg)
337-2090	CFC-60G	¥ 89,607	¥ 88,500	552-303-10	0 to 600 (outside), 20 to 620 (inside)	±0.04	0.01	100	None	0.79
337-2103	CFC-100G	¥ 137,700	¥ 136,000	552-304-10	0 to 1000 (outside), 20 to 1020 (inside)	±0.05	0.01	150	None	1.76

Contact us: 050-3786-3214 <http://www.mitutoyo.co.jp/>

Gauges

KANON
KANON Stock 442 Items

Long Digital Caliper

Repairing OK **Calibration OK** **RoHS**
Approx. 2 Weeks



- Features**
- A standard long digital caliper.
 - The material quality is stainless steel (SUS420J2).
- Use**
- For measurement of large size measuring objects.
- Specs**
- Power Supply: Lithium Coin Cell Battery (CR2032) x 1 (accessory)
- Origin**
- China

SPQ: 1 Piece

Squares, Levelers

Linear Scales

Squares

Scales

Order Unit: 1 Piece

NAKAMURA Mfg Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Outer Side Jaws (mm)	Interior Jaws (mm)	Depth Bar	Weight (kg)
392-2928	EMA60J	¥ 64,800	¥ 60,000	170158	0 to 600	±0.05	0.01	89	38	None	1.4
392-2910	EMA100J	¥ 105,840	¥ 98,000	170159	0 to 1000	±0.07	0.01	128	50	None	2.0

Contact us: 03-3775-1521 <http://www.bestool-kanon.co.jp/>

Protractors


Scribers

Surface Plates

SK
SK Stock 1,103 Items

Long Digital Caliper

Repairing OK **Calibration OK**
Approx. 2 Weeks

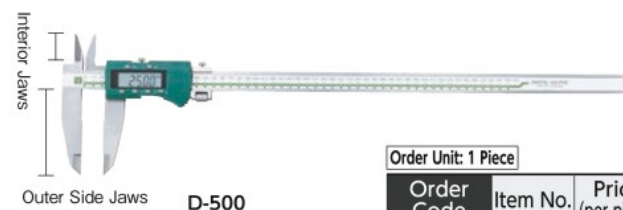

- Features**
- Easy to see with the digital display.
 - With preset function.
 - Vernier can perform the fine feed.
- Use**
- For outside measurement, inside measurement, and step difference measurement.
- Specs**
- Power Supply: Lithium Coin Cell Battery (CR2032) x 1 (accessory)
- Origin**
- China

SPQ: 1 Piece

Order Unit: 1 Piece

(Price revision date: Jun, 2015) NIIGATASEIKI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Outer Side Jaws (mm)	Interior Jaws (mm)	Depth Bar	Weight (kg)
333-8444	D-500	¥ 77,760	¥ 72,000	151053	0 to 500	±0.05	0.01	100	38.0	None	1.0
333-8452	D-600	¥ 84,240	¥ 78,000	151054	0 to 600	±0.08	0.01	100	38.0	None	1.1
333-8436	D-1000	¥ 138,240	¥ 128,000	151055	0 to 1000	±0.10	0.01	125	51.0	None	2.4
377-5038	D-1500	¥ 291,600	¥ 270,000	151156	0 to 1500	±0.14	0.01	150	61.0	None	5.0
377-5143	D-2000	¥ 453,600	¥ 420,000	151157	0 to 2000	±0.20	0.01	150	61.0	None	6.5

Contact us: 0256-31-5660 <http://www.sokuteikou.com/>