

MITUTOYO **Stock 466 Items**

Digimatic Height Gauge

Repairing OK

Calibration OK
Approx. 2 Weeks

For Scribers.
See p. 1-1270



HD-30AX

Total Height

- Features**
- Stable measurement with a double column structure is possible.
 - The display character size is increased (11mm), making it superior in visibility.
 - By tilting the drive handle, it is excellent in operability.
- Use**
- For height measurement.
- Specs**
- Power supply: Button type silver oxide battery (SR44) x 1 (accessory)
 - With measurement data output terminal
- Origin**
- Japan

General Purpose Type Accessories • Scriber: No.07GZA000

Order Unit: 1 Piece

MITUTOYO CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Height (mm)	SPQ (piece)	Weight (kg)
336-1691	HD-30AX	¥ 92,948	¥ 91,800	192-613-10	0 to 300	±0.02	0.01/0.005	475	1	4.7
336-1705	HD-60AX	¥ 153,090	¥ 151,200	192-614-10	0 to 600	±0.05	0.01/0.005	802	1	8.3
★423-6661	HD-100AX	¥ 273,375	¥ 270,000	192-615-10	0 to 1000	±0.07	0.01/0.005	1228	1	15.7

Touch probe available

- Specs**
- Two point type touch probe (sold separately) can be used
- Accessories**
- Scriber: No.905200

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Height (mm)	SPQ (piece)	Weight (kg)
336-1713	HDM-30AX	¥ 125,753	¥ 124,200	192-663-10	0 to 300	±0.02	0.01	510	1	5.7
336-1721	HDM-60AX	¥ 180,428	¥ 178,200	192-664-10	0 to 600	±0.04	0.01	802	1	8.3
★423-6670	HDM-100AX	¥ 295,245	¥ 291,600	192-665-10	0 to 1000	±0.06	0.01	1228	1	15.7

Contact us:050-3786-3214 <http://www.mitutoyo.co.jp/>

MITUTOYO **Stock 466 Items**

Digimatic ABS Built-in Height Gauge

Repairing OK

Calibration OK
Approx. 2 Weeks

For Scribers.
See p. 1-1270



HDS-H30C

Total Height

- Features**
- With the absolute origin setting function. (memorize a surface plate, etc. as absolute origin)
 - Has a hold function. (display values can be retained)
 - Built-in ABS (absolute) scale eliminates origin alignment for each power on.
 - Measurement by smooth up-and-down motions of a handle for sliding movement that is same as the reputed double-column height gauge.
 - CE standard product.

- Use**
- For height measurement.
- Specs**
- Power supply: Button type silver oxide battery (SR44) x 1 (accessory)
 - With measurement data output terminal

- Accessories**
- Scriber: No.07GZA000
 - Scriber Clamp: No.05GZA033
 - Holder Arm: No.953638 (*for installation of test indicator)
 - Clamp (with dovetail groove): No.902053 (*for installation of test indicator)

- Origin**
- China

Warning

- Instrument error is at measurement with a scriber.



Order Unit: 1 Piece

MITUTOYO CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Height (mm)	SPQ (piece)	Weight (kg)
310-7060	HDS-H30C	¥ 67,838	¥ 67,000	570-322	0 to 300	±0.03	0.01	507	1	4.66
310-7078	HDS-H60C	¥ 138,713	¥ 137,000	570-324	0 to 600	±0.05	0.01	812	1	6.46

Contact us:050-3786-3214 <http://www.mitutoyo.co.jp/>

KANON **Stock 442 Items**

Digital Height Gauge with Rotation Scriber

Repairing OK

Calibration OK
Approx. 2 Weeks

RoHS



EHK30J

450.5 mm


- Features**
- Multiple measurement is now available with installation of rotation scriber.
 - Groove measurement is also possible other than height measurement and measurement time can be greatly shortened.
 - The material quality is stainless steel (SUS420J2).

- Use**
- For scribing work.
 - For height measurement.
- Specs**
- Power Supply: Button Type Silver Oxide Battery (SR44) x 1 (accessory)


- Accessories**
- Scriber (head with carbide tip)

- Origin**
- China

Measurement Example

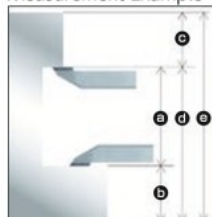

- ①. Measurement of direct groove width
- ②. Measurement from a flat surface to a step
- ③. Measurement from ceiling to top
- ④. Measurement from a flat surface to ceiling
- ⑤. Measurement from a flat surface to a top part

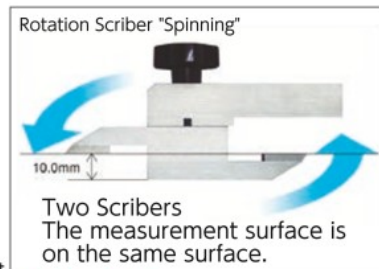

Two Scribers
The measurement surface is on the same surface.

Order Unit: 1 Piece

(Price revision date: Jun, 2017) NAKAMURA Mfg Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Height (mm)	SPQ (piece)	Weight (kg)
356-8415	EHK30J	¥ 90,072	¥ 83,400	174101	10 to 300	±0.03	0.01	450.5	1	2.2

Contact us:03-3775-1521 <http://www.bestool-kanon.co.jp/>