

Hand-held Loupes (with light) / Hand-held Loupes

For Batteries, see p. 10-461 to 474

The number next to the logo mark indicates items in stock for each brand.

Optical Precision Measuring Instruments

Surface Roughness Testers

Shape Measuring Instruments

Stereo Microscopes

Microscopes

Illuminated Magnifiers

Lighting for Inspection

Loupe

Inspection Mirrors

Binoculars, Monocles

Drones

Wearable Cameras

Time Lapse Cameras

3D Printers

TRUSCO Stock **38,650** Items

Hand-held Loupe with LED



- Features**
- A lens with a ϕ 130 large diameter makes it very easy to see.
 - A 1.8x ϕ 130 lens is integrated with a small 5x lens.
 - Since it is equipped with LED, it can be used even if it is dark at hand.
- Use**
- For general inspections
- Specs**
- Power Supply: AAA Dry Battery x 1 (sold separately)
 - Replacement Lamp: No
- Materials**
- Lens: Acrylic
- Origin**
- China




Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
478-9318	TL-130LED	¥3,610	¥3,900	1.8/5	ϕ 130	260	10	225

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

Loupe with Handle

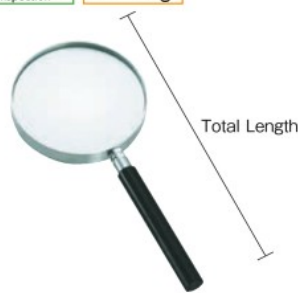

- Features**
- One at hand, you can use it for a wide range of applications.
- Use**
- For general expansion inspection.
- Materials**
- Lens: Glass
- Origin**
- Taiwan

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
255-0814	TL-PC75	¥1,462	¥1,580	2.0	ϕ 76.5	165.0	6	100
255-0822	TL-PC100	¥1,778	¥1,920	2.0	ϕ 101.5	212.5	6	195
255-0806	TL-PC65	¥1,203	¥1,300	2.5	ϕ 65.0	153.0	6	74
250-9083	TL-101	¥555	¥600	3.0	ϕ 38.0	92.0	6	402


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

Bifocal Loupe



- Features**
- One lens proving 2 types of magnification.
- Use**
- For general expansion inspection.
- Materials**
- Lens: Acrylic
- Origin**
- China

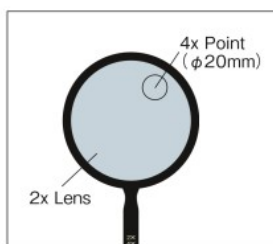

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
250-8958	TL-DL75	¥879	¥950	2/4	ϕ 75	185	6	55
250-8940	TL-DL90	¥1,203	¥1,300	2/4	ϕ 90	210	6	86

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

High Magnification Loupe



- Features**
- Work efficiency is increased by high precision, high magnification magnifier for precision work.
- Use**
- For precision parts check, small letters such as books etc.
- Materials**
- Lens: Glass
- Origin**
- Japan

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
276-8542	TL-HL10K	¥2,499	¥2,700	10	ϕ 28	104	10	38
276-8551	TL-HL15K	¥2,722	¥2,940	15	ϕ 21	88	10	30

Contact us: 0120-509-849 <http://www.orange-book.com/>

LEAF Stock **82** Items

Loupe with Handle



- Features**
- The handle bar is made of an aluminum shaft.
- Use**
- For precision parts check, small letters such as books etc.
- Materials**
- Lens: Glass
- Origin**
- Japan

LEAF Stock **82** Items

High Magnification Loupe with Handle



- Features**
- A high magnification loupe.
 - The shaft is 6mm.
- Use**
- For precision parts check, small letters such as books etc.
- Materials**
- Lens: Glass
- Origin**
- Japan

Order Unit: 1 Piece (Price revision date: Jan, 2015) KEIYO MAGNIFIERS'Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
219-0940	RGH-100	¥3,911	¥3,900	2.0	ϕ 100	230	12	230
219-1199	RGH-75	¥2,908	¥2,900	2.3	ϕ 75	207	12	110
219-0923	RGH-50	¥2,006	¥2,000	2.7	ϕ 50	145	12	60

Contact us: 043-251-5037 <http://www.keiyo-kouki.jp/>

Order Unit: 1 Piece (Price revision date: Jan, 2015) KEIYO MAGNIFIERS'Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
219-0907	5212	¥3,811	¥3,800	10	ϕ 28	128	12	48
219-0915	5213	¥4,011	¥4,000	15	ϕ 21	121	12	40

Contact us: 043-251-5037 <http://www.keiyo-kouki.jp/>

Item No.	Lens Type
5212	Double lens
5213	Three lens