

For Batteries, see p. 10-461 to 474

The number next to the logo mark indicates items in stock for each brand.

Test Instruments

Multimeters  
Crampmeters  
Insulation Resistance Testers  
Detectors  
Phase Detectors  
Cable Locators  
Static Electricity Meters  
Thermometers, Hygrometers  
Heat Sensor/Measuring Instruments  
Test Instruments for Environments  
Gas Detectors  
Water Measuring Instruments  
Vibration Meters, Tacho Meters  
Hardness Testers  
Viscometers  
Coating Thickness Meters, Detectors  
Nondestructive Inspection Systems  
Flowmeters  
Pressure Gauges  
Vacuum Gauges  
Stopwatches, Timers  
Counters  
Balances  
Tension Gauges  
Torque Equipments

**TRUSCO** Stock **38,650** Items

## Analog Thermometer

**Com Drawing** **td TRUSCO UNIVERSAL DESIGN**

**Features**


- A 25cm diameter large dial which uses universal design characters is easy to see even from a distance.
- A functional and simple design.

**Specs**

- Measurement Item: Temperature
- W x D x H: 285 x 35 x 285mm

**Origin**

- Japan



285mm  
285mm

**TAO-250-U**

**TRUSCO** Stock **38,650** Items

## Analog Thermo-Hygrometer

**Com Drawing** **td TRUSCO UNIVERSAL DESIGN**

**Features**


- Large dial with a diameter of 25cm, simple and functional design.
- Adopts universal design characters to improve visibility.

**Specs**

- Measurement Item: Temperature, Humidity
- W x D x H: 285 x 35 x 285mm
- Temperature Min Display: 2°C
- Humidity Min Display: 5%RH

**Origin**

- Japan



285mm  
285mm

**TAOT-250-U**

Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measuring Temperature Range (°C)	Temperature Min Display (°C)	SPQ (piece)	Weight (g)
473-6796	TAO-250-U	¥3,904	¥4,820	-30 to 50	2	10	730

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measuring Temperature Range (°C)	Measurement Humidity Range (%RH)	SPQ (piece)	Weight (g)
473-6800	TAOT-250-U	¥5,014	¥6,190	-30 to 50	20 to 100	10	730

Contact us: 0120-509-849 <http://www.orange-book.com/>

**SATO** **SK** Thermo-Hygrometer "Highest 1 Type" **Repairing OK** **Calibration OK** Approx. 2 Weeks

**Features**


- Hair is used in the humidity sensor of this thermo-hygrometer which has been developed with an aim to have high reliability.

**Specs**

- Measurement Item: Temperature, Humidity
- Diameter x thickness: 150 x 40mm
- Temperature Min Display: 2°C
- Humidity Min Display: 1%RH

**Origin**

- Japan

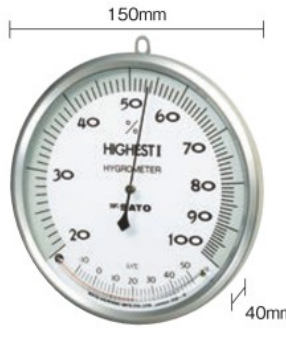

150mm  
40mm

**7540-00**

**SATO** **SK** Thermo-Hygrometer "Highest 2 Type" **Repairing OK** **Calibration OK** Approx. 2 Weeks

**Features**


- Hair is used in the humidity sensor and thermister in the temperature sensor of this thermo-hygrometer, which has been developed with an aim to have high reliability.

**Specs**

- Measurement Item: Temperature, Humidity
- Power Supply: AA Dry Battery (R6P) x 1 (accessory)
- Diameter x thickness: 135 x 33mm
- Temperature Min Display: 0.1°C
- Humidity min display: 2% RH

**Origin**

- Japan



135mm  
33mm

**7542-00**

Order Unit: 1 Piece SATO KEIRYOUKI MFG, Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measuring Temperature Range (°C)	Measurement Humidity Range (%RH)	SPQ (piece)	Weight (g)
406-9234	7540-00	¥11,643	¥11,500	-10 to 50	20 to 100	1	280

Contact us: 03-3254-8111 <http://www.sksato.co.jp/>

Order Unit: 1 Piece SATO KEIRYOUKI MFG, Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measuring Temperature Range (°C)	Measurement Humidity Range (%RH)	SPQ (piece)	Weight (g)
330-6399	7542-00	¥13,163	¥13,000	0 to 50	20 to 100	1	230

Contact us: 03-3254-8111 <http://www.sksato.co.jp/>

**CITIZEN** Stock **28** Items

## Analog Thermo-Hygrometer

**Com Drawing** **td TRUSCO UNIVERSAL DESIGN**

**Features**


- An analog thermo-hygrometer that helps to know about comfortable space.

**Specs**

- Measurement Item: Temperature, Humidity
- Temperature min display: -30°C
- Humidity min display: 0% RH


**Origin**

- China



200mm  
200mm

**9CZ057-002**



**9CZ057-003**

**CITIZEN** Stock **28** Items

## Analog Thermo-Hygrometer

**Com Drawing** **td TRUSCO UNIVERSAL DESIGN**

**Features**


- An analog thermo-hygrometer that helps to know about comfortable space.

**Specs**

- Measurement Item: Temperature, Humidity
- Temperature min display: -20°C
- Humidity min display: 10% RH


**Origin**

- China



150mm  
150mm

**9CZ013-002**



**9CZ013-003**

Order Unit: 1 Piece RHYTHM WATCH Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measuring Temperature Range (°C)	Measurement Humidity Range (%RH)	SPQ (piece)	Weight (g)
835-4818	9CZ057-002	¥2,835	¥2,800	-30 to 50	0 to 100	12	280
835-4819	9CZ057-003	¥2,835	¥2,800	-30 to 50	0 to 100	12	280

Contact us: 0120-557-005 <http://www.rhythm.co.jp/>

Order Unit: 1 Piece RHYTHM WATCH Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Measuring Temperature Range (°C)	Measurement Humidity Range (%RH)	SPQ (piece)	Weight (g)
835-4820	9CZ013-002	¥2,025	¥2,000	-20 to 40	10 to 90	24	280
835-4821	9CZ013-003	¥2,025	¥2,000	-20 to 40	10 to 90	24	280

Contact us: 0120-557-005 <http://www.rhythm.co.jp/>