


Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Polyethylene Foam Sheet (soft Type)

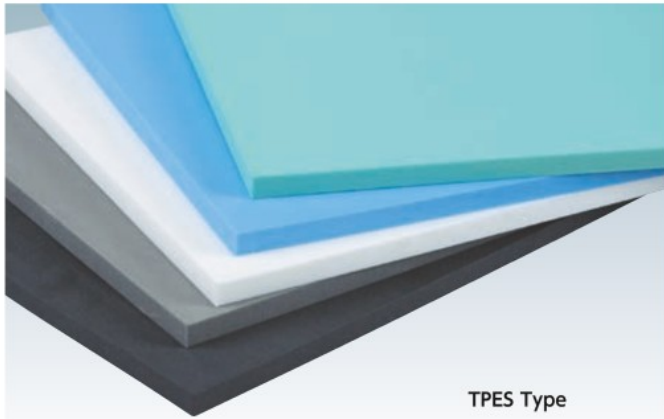

TPES Type

- Features**
- A material of a polyethylene foam sheet with elasticity.
 - You can cut it to your preferred size.
 - Excellent weather resistance, heat insulation, chemical resistance, heat retention, and cold retention.
- Use**
- Box cushioning material, cushioning material, organizing sheet, work.
- Specs**
- Working Temperature Range: -20 to 70°C
 - Density: 25kg/m³
- Materials**
- Polyethylene Foam
- Origin**
- Japan

Warning

- Cut surface is not processed for appearance.
- The material is soft and is easily scratched.

Order Unit: 1 Sheet

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Sheet


Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Color	Thickness (mm)	W x L (mm)	SPQ (sheet)	Weight (g)
764-3373	TPES-0510B	¥1,342	¥1,450	Blue	5	1000 x 1000	10	125
764-3381	TPES-0510BK	¥1,342	¥1,450	Black	5	1000 x 1000	10	125
764-3390	TPES-0510GY	¥1,342	¥1,450	Gray	5	1000 x 1000	10	125
764-3403	TPES-0510W	¥1,342	¥1,450	White	5	1000 x 1000	10	125
789-7766	TPES-0510GN	¥1,342	¥1,450	Green	5	1000 x 1000	10	125
764-3411	TPES-1010B	¥2,361	¥2,550	Blue	10	1000 x 1000	10	250
764-3420	TPES-1010BK	¥2,361	¥2,550	Black	10	1000 x 1000	10	250
764-3438	TPES-1010GY	¥2,361	¥2,550	Gray	10	1000 x 1000	10	250
764-3446	TPES-1010W	¥2,361	¥2,550	White	10	1000 x 1000	10	250
789-7774	TPES-1010GN	¥2,361	¥2,550	Green	10	1000 x 1000	10	250
764-3454	TPES-1510B	¥3,471	¥3,750	Blue	15	1000 x 1000	10	375
764-3462	TPES-1510BK	¥3,471	¥3,750	Black	15	1000 x 1000	10	375
764-3471	TPES-1510GY	¥3,471	¥3,750	Gray	15	1000 x 1000	10	375
764-3489	TPES-1510W	¥3,471	¥3,750	White	15	1000 x 1000	10	375
789-7782	TPES-1510GN	¥3,471	¥3,750	Green	15	1000 x 1000	10	375

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Color	Thickness (mm)	W x L (mm)	SPQ (sheet)	Weight (g)
764-3497	TPES-2010B	¥4,453	¥4,810	Blue	20	1000 x 1000	10	500
764-3501	TPES-2010BK	¥4,453	¥4,810	Black	20	1000 x 1000	10	500
764-3519	TPES-2010GY	¥4,453	¥4,810	Gray	20	1000 x 1000	10	500
764-3527	TPES-2010W	¥4,453	¥4,810	White	20	1000 x 1000	10	500
789-7791	TPES-2010GN	¥4,453	¥4,810	Green	20	1000 x 1000	10	500
764-3535	TPES-2510B	¥5,350	¥5,780	Blue	25	1000 x 1000	10	625
764-3543	TPES-2510BK	¥5,350	¥5,780	Black	25	1000 x 1000	10	625
764-3551	TPES-2510GY	¥5,350	¥5,780	Gray	25	1000 x 1000	10	625
764-3560	TPES-2510W	¥5,350	¥5,780	White	25	1000 x 1000	10	625
789-7804	TPES-2510GN	¥5,350	¥5,780	Green	25	1000 x 1000	10	625
764-3578	TPES-3010B	¥6,434	¥6,950	Blue	30	1000 x 1000	10	750
764-3586	TPES-3010BK	¥6,434	¥6,950	Black	30	1000 x 1000	10	750
764-3594	TPES-3010GY	¥6,434	¥6,950	Gray	30	1000 x 1000	10	750
764-3608	TPES-3010W	¥6,434	¥6,950	White	30	1000 x 1000	10	750
789-7812	TPES-3010GN	¥6,434	¥6,950	Green	30	1000 x 1000	10	750

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Polyethylene Foam Sheet (hard Type)

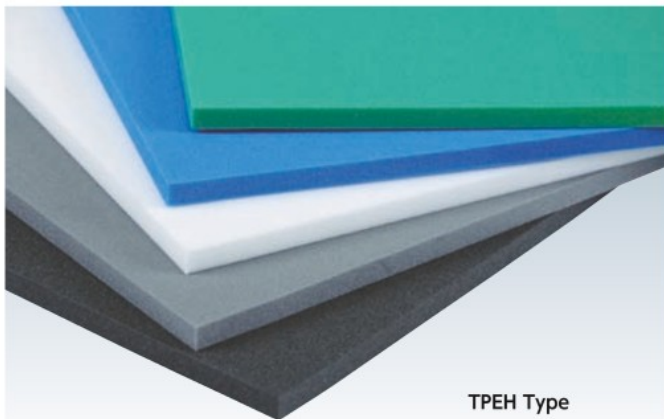

TPEH Type

- Features**
- A material of a polyethylene foam sheet.
 - You can cut it to your preferred size.
 - Excellent weather resistance, heat insulation, chemical resistance, heat retention, and cold retention.
- Use**
- Box cushioning material, cushioning material, organizing sheet, work.
- Specs**
- Working Temperature Range: -20 to 70°C
 - Density: 65kg/m³
- Materials**
- Polyethylene Foam
- Origin**
- Japan

Warning

- Cut surface is not processed for appearance.

Order Unit: 1 Sheet

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Color	Thickness (mm)	W x L (mm)	SPQ (sheet)	Weight (g)
764-3136	TPEH-0510B	¥1,666	¥1,800	Blue	5	1000 x 1000	10	325
764-3144	TPEH-0510BK	¥1,666	¥1,800	Black	5	1000 x 1000	10	325
764-3152	TPEH-0510GY	¥1,666	¥1,800	Gray	5	1000 x 1000	10	325
764-3161	TPEH-0510W	¥1,666	¥1,800	White	5	1000 x 1000	10	325
789-7707	TPEH-0510GN	¥1,666	¥1,800	Green	5	1000 x 1000	10	325
764-3179	TPEH-1010B	¥2,870	¥3,100	Blue	10	1000 x 1000	10	650
764-3187	TPEH-1010BK	¥2,870	¥3,100	Black	10	1000 x 1000	10	650
764-3195	TPEH-1010GY	¥2,870	¥3,100	Gray	10	1000 x 1000	10	650
764-3209	TPEH-1010W	¥2,870	¥3,100	White	10	1000 x 1000	10	650
789-7715	TPEH-1010GN	¥2,870	¥3,100	Green	10	1000 x 1000	10	650
764-3217	TPEH-1510B	¥4,119	¥4,450	Blue	15	1000 x 1000	10	975
764-3225	TPEH-1510BK	¥4,119	¥4,450	Black	15	1000 x 1000	10	975
764-3233	TPEH-1510GY	¥4,119	¥4,450	Gray	15	1000 x 1000	10	975
764-3241	TPEH-1510W	¥4,119	¥4,450	White	15	1000 x 1000	10	975
789-7723	TPEH-1510GN	¥4,119	¥4,450	Green	15	1000 x 1000	10	975

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Color	Thickness (mm)	W x L (mm)	SPQ (sheet)	Weight (g)
764-3250	TPEH-2010B	¥5,277	¥5,700	Blue	20	1000 x 1000	10	1300
764-3268	TPEH-2010BK	¥5,277	¥5,700	Black	20	1000 x 1000	10	1300
764-3276	TPEH-2010GY	¥5,277	¥5,700	Gray	20	1000 x 1000	10	1300
764-3284	TPEH-2010W	¥5,277	¥5,700	White	20	1000 x 1000	10	1300
789-7731	TPEH-2010GN	¥5,277	¥5,700	Green	20	1000 x 1000	10	1300
764-3292	TPEH-2510B	¥6,850	¥7,400	Blue	25	1000 x 1000	10	1625
764-3306	TPEH-2510BK	¥6,850	¥7,400	Black	25	1000 x 1000	10	1625
764-3314	TPEH-2510GY	¥6,850	¥7,400	Gray	25	1000 x 1000	10	1625
764-3322	TPEH-2510W	¥6,850	¥7,400	White	25	1000 x 1000	10	1625
789-7740	TPEH-2510GN	¥6,850	¥7,400	Green	25	1000 x 1000	10	1625
764-3331	TPEH-3010B	¥8,239	¥8,900	Blue	30	1000 x 1000	10	1950
764-3349	TPEH-3010BK	¥8,239	¥8,900	Black	30	1000 x 1000	10	1950
764-3357	TPEH-3010GY	¥8,239	¥8,900	Gray	30	1000 x 1000	10	1950
764-3365	TPEH-3010W	¥8,239	¥8,900	White	30	1000 x 1000	10	1950
789-7758	TPEH-3010GN	¥8,239	¥8,900	Green	30	1000 x 1000	10	1950

Contact us: 0120-509-849 <http://www.orange-book.com/>