

Vibration-proof Materials (underlay type)


The number next to the logo mark indicates items in stock for each brand.

Machine Tools

- O-Rings·Oil Seals
- Rubbers
- Resins
- Metal Materials
- Carbon Fibers
- Ceramic Materials
- Vibration Absorber
- Adjusters
- Plungers
- Springs for Die
- Springs
- Split Pins
- Snap Rings
- Oil Gauges
- Oil Tank Caps
- Knobs
- Lever
- Handles·Grips
- Handles
- Hinges
- Slide Rails
- Stays
- Toggle Latches
- Fastening Parts
- Aluminum Frames

TRUSCO Stock **38,650** Items

Vibration Absorbing Pad (natural rubber)

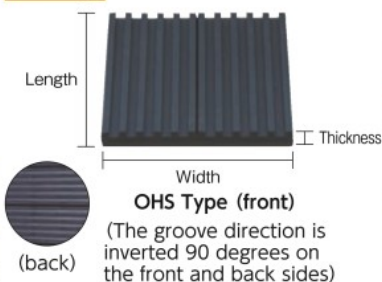


OHS Type (front)
(The groove direction is inverted 90 degrees on the front and back sides)

Features •As it is easy to process, it can be used by simply cutting the V-groove of 50mm interval with the utility knife.
Use •For machines that generate various vibrations and noise, such as machine tools, blowers, pumps various motors.
Specs •Rubber Hardness: 55° ±5 •Working Temperature Range: -5 to 70° C
 •Color: Black •Max Size: 600 x 1000mm
Materials •Natural Rubber (NR) **Origin** •China

Mini sheet type

Order Unit: 1 Sheet (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Allowable Surface Pressure (N/mm ²)	Thickness (mm)	Width (mm)	Length (mm)	SPQ (sheet)	Weight (kg)
405-4687	OHS-10-50	¥ 64	¥ 68	0.5	10	50	50	720	0.03
405-4695	OHS-10-100	¥166	¥180	0.5	10	100	100	180	0.10
405-4709	OHS-10-150	¥361	¥390	0.5	10	150	150	80	0.30
405-4717	OHS-10-200	¥528	¥570	0.5	10	200	200	80	0.40

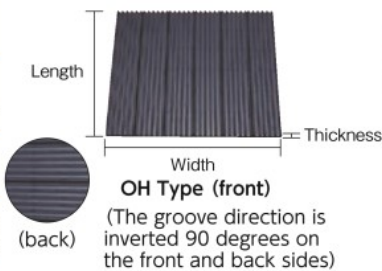


OH Type (front)
(The groove direction is inverted 90 degrees on the front and back sides)

Sheet Type

Order Unit: 1 Sheet (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Allowable Surface Pressure (N/mm ²)	Thickness (mm)	Width (mm)	Length (mm)	SPQ (sheet)	Weight (kg)
170-4583	OH-8	¥ 935	¥1,010	0.5	8	300	300	25	0.7
170-4605	OH-10	¥1,130	¥1,220	0.5	10	300	300	20	0.8
170-4621	OH-20	¥3,250	¥3,510	0.3	20	300	300	10	1.7

Warning
•OH-8does not have the V-shaped groove.

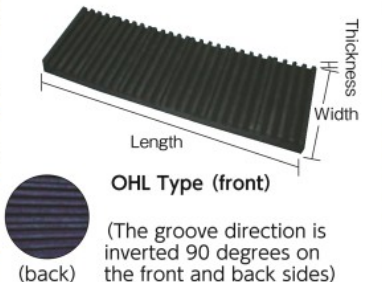

OHL Type (front)
(The groove direction is inverted 90 degrees on the front and back sides)

Belts Type

Order Unit: 1 Sheet (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Allowable Surface Pressure (N/mm ²)	Thickness (mm)	Width (mm)	Length (mm)	SPQ (sheet)	Weight (kg)
170-4648	OHL-10-100	¥ 1,361	¥ 1,470	0.5	10	100	1000	30	0.9
170-4656	OHL-10-150	¥ 2,009	¥ 2,170	0.5	10	150	1000	15	1.5
405-4725	OHL-10-300	¥ 4,092	¥ 4,420	0.5	10	300	1000	4	3.0
272-6971	OHL-10-600	¥ 6,555	¥ 7,080	0.5	10	600	1000	1	5.5
170-4664	OHL-15-100	¥ 1,824	¥ 1,970	0.4	15	100	1000	20	1.2
170-4672	OHL-15-150	¥ 2,675	¥ 2,890	0.4	15	150	1000	10	2.0
405-4733	OHL-15-300	¥ 5,433	¥ 5,870	0.4	15	300	1000	4	4.2
272-6980	OHL-15-600	¥11,970	¥12,930	0.4	15	600	1000	1	7.0
272-6998	OHL-20-600	¥14,608	¥15,780	0.3	20	600	1000	1	11.0

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

Vibration Absorbing Pad (synthetic rubber/heat resistant oil type)



OHS-CR Type (front)
(The groove direction is inverted 90 degrees on the front and back sides)


Features •As it is easy to process, it can be used by simply cutting the V-groove of 50mm interval with the utility knife.
 •Has tolerance to cutting oil, machine oil, lubricant oil, etc.
Use •For machines that generate various vibrations and noise, such as machine tools, blowers, pumps various motors.
Specs •Rubber Hardness: 55° ±5 •Working Temperature Range: -5 to 110° C •Color: Black
Materials •Synthetic Rubber (CR) **Origin** •China

Mini sheet type

Order Unit: 1 Sheet TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Allowable Surface Pressure (N/mm ²)	Thickness (mm)	Width (mm)	Length (mm)	SPQ (sheet)	Weight (kg)
484-3291	OHS-10-50CR	¥130	¥140	0.5	10	50	50	360	0.03
484-3266	OHS-10-100CR	¥334	¥360	0.5	10	100	100	180	0.10
484-3274	OHS-10-150CR	¥630	¥680	0.5	10	150	150	80	0.30
484-3282	OHS-10-200CR	¥926	¥1,000	0.5	10	200	200	40	0.40

Warning
•OH-8CRdoes not have the V-shaped groove.

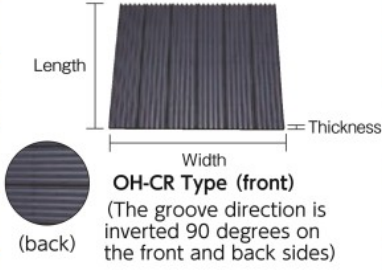

OH-CR Type (front)
(The groove direction is inverted 90 degrees on the front and back sides)

Sheet Type

Order Unit: 1 Sheet (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Allowable Surface Pressure (N/mm ²)	Thickness (mm)	Width (mm)	Length (mm)	SPQ (sheet)	Weight (kg)
170-4591	OH-8CR	¥1,786	¥1,930	0.5	8	300	300	25	0.7
170-4613	OH-10CR	¥2,213	¥2,390	0.5	10	300	300	20	0.8
170-4630	OH-20CR	¥5,998	¥6,480	0.3	20	300	300	10	1.7

Belts Type

Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Allowable Surface Pressure (N/mm ²)	Thickness (mm)	Width (mm)	Length (mm)	SPQ (sheet)	Weight (kg)
484-3177	OHL-10-100CR	¥ 2,685	¥ 2,900	0.5	10	100	1000	30	0.9
484-3185	OHL-10-150CR	¥ 3,795	¥ 4,100	0.5	10	150	1000	15	1.5
484-3193	OHL-10-300CR	¥ 9,257	¥10,000	0.5	10	300	1000	4	3.1
484-3207	OHL-10-600CR	¥16,663	¥18,000	0.5	10	600	1000	1	5.6
484-3215	OHL-15-100CR	¥ 3,333	¥ 3,600	0.4	15	100	1000	20	1.2
484-3223	OHL-15-150CR	¥ 4,999	¥ 5,400	0.4	15	150	1000	10	2.1
484-3231	OHL-15-300CR	¥16,015	¥17,300	0.4	15	300	1000	4	4.3
484-3240	OHL-15-600CR	¥31,659	¥34,200	0.4	15	600	1000	1	7.2
484-3258	OHL-20-600CR	¥36,658	¥39,600	0.3	20	600	1000	1	11.3

Contact us:0120-509-849 <http://www.orange-book.com/>