

SUGATSUNE
SUGATSUNE

Stock
766
Items

Torque Stay (stainless steel)




.Com
CAD



S-100T30 Type

- Features**
- A torque stay for top lid, upward opening lid, and sideways opening lid.
 - Free-stop specification that can hold any angle.
 - Compact and thin so space saving is possible.
 - Can also be used for upward opening lid and sideways opening lid.
- Use**
- For top lid door, etc.
- Materials**
- Stainless Steel (SUS430)
 - Gloss Barrel Polished Finishing
- Origin**
- Japan

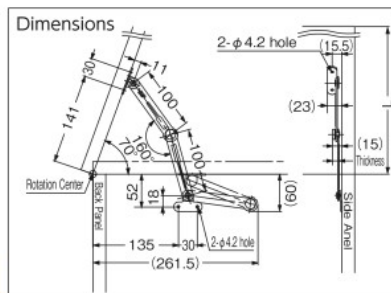

Warning

- Not made entirely out of stainless steel.

Order Unit: 1 Piece

SUGATSUNE KOGYO Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Designation	Total Length (mm)	Thickness (mm)	Rated Torque (N·m)	SPQ (piece)	Weight (g)
380-2361	S-100T30L	¥2,052	¥1,900	For left	236.5	10	3	30	100
380-2370	S-100T30R	¥2,052	¥1,900	For right	236.5	10	3	30	100

Contact us:03-3851-1122 <http://www.sugatsune.co.jp/>

SUGATSUNE
SUGATSUNE

Stock
766
Items

Spring Stay (stainless steel)




.Com
CAD



S-AT01/02 (for side panel mounting)
S-AT01S/02S (for back panel mounting)

- Features**
- Heavy top lid can be lifted lightly by the reaction force of the spring.
 - Can easily be held in position within the opening angle of approx. 10 to 80°.
 - Compact and space-saving.
- Use**
- For top lid door.
- Materials**
- Stainless Steel (SUS430)
 - Polyacetal (POM)
- Origin**
- Japan

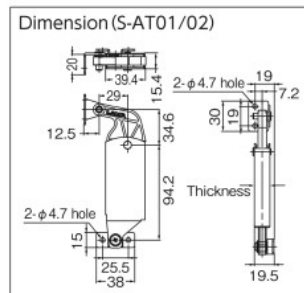

Order Unit: 1 Piece

SUGATSUNE KOGYO Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Designation	Total Length (mm)	Thickness (mm)	Shaft Torque (N/m) when using 1	SPQ (piece)	Weight (g)
380-2388	S-AT01	¥1,944	¥1,800	For Side Panel Mounting	151.3	15.4	6.1 to 8.8	10	180
380-2400	S-AT02	¥2,052	¥1,900	For Side Panel Mounting	151.3	15.4	8.8 to 11.8	10	180
380-2396	S-AT01S	¥1,944	¥1,800	For Back Panel Mounting	158.8	15.4	6.1 to 8.8	10	180
380-2418	S-AT02S	¥2,052	¥1,900	For Back Panel Mounting	158.8	15.4	8.8 to 11.8	10	180

Contact us:03-3851-1122 <http://www.sugatsune.co.jp/>

TRUSCO
TRUSCO

Stock
38,650
Items

Cabinet Stay (steel)





.Com
Drawing



TS-55L-R (for right)

- Features**
- By opening the lid, it becomes stopped state with the rotary function. When closing, the stopped state is released by slightly lifting it.
- Use**
- Assistance for furniture and others.
 - Equipment casing.
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Chrome Plated Finishing
- Origin**
- Japan

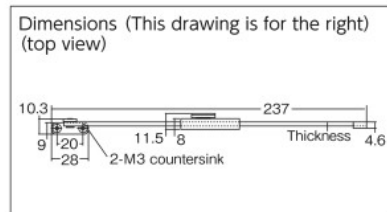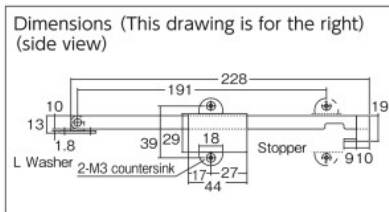

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Designation	Total Length (mm)	Thickness (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
302-1998	TS-55L-L	¥1,130	¥1,220	For left	223	3	3.3(L washer)	2(stopper), 2(L washer)	10	91
302-2005	TS-55L-R	¥1,130	¥1,220	For right	223	3	3.3(L washer)	2(stopper), 2(L washer)	10	91

Contact us:0120-509-849 <http://www.orange-book.com/>