

Hexagon Head Cap Bolts with Washer Cormic

The number next to the logo mark indicates items in stock for each brand.



Stock 38,650 Items


Hexagon Head Screw with Captive Washer (steel)



B716 Type



- Features • Saves you the trouble of setting washers and spring washers.
 Specs • Tensile Strength Rank: 4.8 • With round washer, spring (P-3 type)
 Materials • Low Carbon Steel (SWCH) • Surface Treatment: Trivalent Chromate Finishing (white)
 Origin • Japan

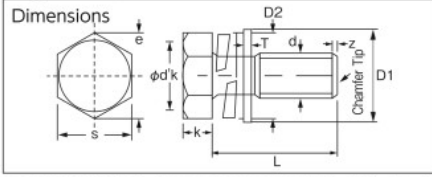

Basic Dimension

(unit: mm)

Nominal Designation of Thread (d)	Bolt Body						Plain Washer		Spring Lock Washer	
	k	s	e	d'k	z	D1	T	For Built-in		
M6	4	10	11.5	9.8	1	13	1	D2		
M8	5.5	13	15	12.6	1.2	18	1.6	14.5		
M10	7	17	19.6	16.5	1.5	22	1.6	17.5		
M12	8	19	21.9	18	2	26	2.3	20.5		

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
300-2616	B716-0610	¥602	¥650	M6 x 10	20	10	129.6
300-2624	B716-0612	¥602	¥650	M6 x 12	21	10	142.6
300-2632	B716-0615	¥602	¥650	M6 x 15	20	10	143.6
300-2641	B716-0616	¥602	¥650	M6 x 16	20	10	149.6
300-2659	B716-0620	¥602	¥650	M6 x 20	19	10	155.4
300-2667	B716-0625	¥602	¥650	M6 x 25	18	10	160.7
300-2675	B716-0630	¥602	¥650	M6 x 30	17	10	168.6
300-2683	B716-0815	¥602	¥650	M8 x 15	10	10	149.3
300-2691	B716-0816	¥602	¥650	M8 x 16	10	10	151.9
300-2705	B716-0820	¥602	¥650	M8 x 20	10	10	164.9
300-2519	B716-0825	¥602	¥650	M8 x 25	9	10	161.1
300-2527	B716-0830	¥602	¥650	M8 x 30	9	10	176.4
300-2535	B716-0835	¥602	¥650	M8 x 35	8	10	169.3
300-2543	B716-0840	¥602	¥650	M8 x 40	8	10	181.9
300-2551	B716-0845	¥602	¥650	M8 x 45	7	10	170.1
300-2560	B716-0850	¥602	¥650	M8 x 50	6	10	153.3

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
300-2578	B716-1020	¥602	¥650	M10 x 20	6	10	182.4
300-2586	B716-1025	¥602	¥650	M10 x 25	6	10	198.3
300-2594	B716-1030	¥602	¥650	M10 x 30	5	10	179.0
300-2608	B716-1035	¥602	¥650	M10 x 35	5	10	191.4
300-2411	B716-1040	¥602	¥650	M10 x 40	4	10	163.1
300-2420	B716-1045	¥602	¥650	M10 x 45	4	10	173.0
300-2438	B716-1050	¥602	¥650	M10 x 50	4	10	181.6
300-2446	B716-1220	¥602	¥650	M12 x 20	3	10	136.2
300-2454	B716-1225	¥602	¥650	M12 x 25	3	10	145.2
300-2462	B716-1230	¥602	¥650	M12 x 30	3	10	156.0
300-2471	B716-1235	¥602	¥650	M12 x 35	3	10	167.9
300-2489	B716-1240	¥602	¥650	M12 x 40	3	10	178.6
300-2497	B716-1245	¥602	¥650	M12 x 45	3	10	189.4
300-2501	B716-1250	¥602	¥650	M12 x 50	3	10	199.2

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Hexagon Head Screw with Captive Washer (steel)




B768 Type (trivalent chromate)



B68 Type (hexavalent chromate)

- Features • Saves you the trouble of setting washers and spring washers.
 Specs • Tensile Strength Rank: 4.8
 • With round washer, spring (P-3 type)
 • Upset type
 Materials • Low Carbon Steel (SWCH)
 Origin • Japan

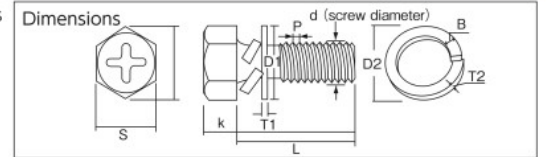

Compatible Screwdriver

M5	Plus No. 2
M6/M8	Plus No. 3

Basic Dimension

(unit: mm)

Nominal Designation of Thread (d)	Thread Pitch	Upset Head Bolt with Cross Recess		Plain Washer		Spring Lock Washer	
		k	S	D1	T1	D2	B x T2
M5	0.80	3.5	8.0	12.0	0.8	8.5	1.7 x 1.3
M6	1.00	4.0	10.0	13.0	1.0	11.5	2.7 x 1.5
M8	1.25	5.5	13.0	18.0	1.6	14.5	3.2 x 2.0

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
300-2110	B768-0508	¥602	¥650	M5 x 8	33	10	69.6
300-2128	B768-0510	¥602	¥650	M5 x 10	32	10	75.2
300-2136	B768-0512	¥602	¥650	M5 x 12	31	10	80.3
300-2144	B768-0515	¥602	¥650	M5 x 15	30	10	88.5
300-2152	B768-0516	¥602	¥650	M5 x 16	28	10	86.1
300-2161	B768-0520	¥602	¥650	M5 x 20	26	10	82.5
300-2179	B768-0525	¥602	¥650	M5 x 25	25	10	103.9
300-2187	B768-0530	¥602	¥650	M5 x 30	22	10	104.7
300-2195	B768-0535	¥602	¥650	M5 x 35	19	10	102.5
300-2209	B768-0540	¥602	¥650	M5 x 40	17	10	101.4
300-2012	B768-0610	¥602	¥650	M6 x 10	23	10	90.2
300-2021	B768-0612	¥602	¥650	M6 x 12	23	10	98.2
300-2039	B768-0615	¥602	¥650	M6 x 15	21	10	99.4
300-2047	B768-0616	¥602	¥650	M6 x 16	20	10	99.1
300-2055	B768-0620	¥602	¥650	M6 x 20	19	10	107.2
300-2063	B768-0625	¥602	¥650	M6 x 25	18	10	116.8

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
300-2071	B768-0630	¥602	¥650	M6 x 30	16	10	117.7
300-2080	B768-0635	¥602	¥650	M6 x 35	14	10	115.1
300-2098	B768-0640	¥602	¥650	M6 x 40	13	10	118.0
300-2101	B768-0645	¥602	¥650	M6 x 45	11	10	109.3
300-1911	B768-0650	¥602	¥650	M6 x 50	10	10	108.0
300-1920	B768-0812	¥602	¥650	M8 x 12	9	10	83.8
300-1938	B768-0815	¥602	¥650	M8 x 15	10	10	102.6
300-1946	B768-0816	¥602	¥650	M8 x 16	10	10	105.6
300-1954	B768-0820	¥602	¥650	M8 x 20	9	10	106.2
300-1962	B768-0825	¥602	¥650	M8 x 25	9	10	120.3
300-1971	B768-0830	¥602	¥650	M8 x 30	8	10	119.2
300-1989	B768-0835	¥602	¥650	M8 x 35	7	10	115.4
300-1997	B768-0840	¥602	¥650	M8 x 40	7	10	126.3
300-2004	B768-0845	¥602	¥650	M8 x 45	6	10	117.6
300-1903	B768-0850	¥602	¥650	M8 x 50	5	10	105.8

Order Unit: 1 Bag

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-4605	B68-0508	¥602	¥650	M5 x 8	80	10	168.9
159-4613	B68-0510	¥602	¥650	M5 x 10	80	10	188.2
159-4621	B68-0512	¥602	¥650	M5 x 12	85	10	220.4
159-4630	B68-0515	¥602	¥650	M5 x 15	80	10	236.0
159-4648	B68-0516	¥602	¥650	M5 x 16	80	10	246.0
159-4656	B68-0520	¥602	¥650	M5 x 20	75	10	266.8
159-4664	B68-0525	¥602	¥650	M5 x 25	65	10	270.4
159-4672	B68-0530	¥602	¥650	M5 x 30	60	10	285.7
159-4681	B68-0610	¥602	¥650	M6 x 10	60	10	235.5
159-4699	B68-0612	¥602	¥650	M6 x 12	60	10	256.2
159-4702	B68-0615	¥602	¥650	M6 x 15	60	10	284.4
159-4711	B68-0616	¥602	¥650	M6 x 16	55	10	272.6
159-4729	B68-0620	¥602	¥650	M6 x 20	50	10	282.2
159-4737	B68-0625	¥602	¥650	M6 x 25	45	10	292.6

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-4745	B68-0630	¥602	¥650	M6 x 30	40	10	294.4
159-4753	B68-0635	¥602	¥650	M6 x 35	35	10	287.7
159-4761	B68-0640	¥602	¥650	M6 x 40	30	10	272.4
212-7598	B68-0650	¥602	¥650	M6 x 50	25	10	270.0
212-7601	B68-0812	¥602	¥650	M8 x 12	30	10	279.3
159-4770	B68-0815	¥602	¥650	M8 x 15	30	10	307.8
159-4788	B68-0816	¥602	¥650	M8 x 16	30	10	316.8
159-4796	B68-0820	¥602	¥650	M8 x 20	25	10	295.2
159-4800	B68-0825	¥602	¥650	M8 x 25	25	10	334.2
159-4818	B68-0830	¥602	¥650	M8 x 30	20	10	298.6
159-4826	B68-0835	¥602	¥650	M8 x 35	20	10	329.8
159-4834	B68-0840	¥602	¥650	M8 x 40	20	10	361.0
212-7636	B68-0850	¥602	¥650	M8 x 50	18	10	381.0

Contact us: 0120-509-849 <http://www.orange-book.com/>