

Hexagon Socket Head Cap Screws (cap screw)

The number next to the logo mark indicates items in stock for each brand.

Screws • Bolts • Nuts

Hexagon Bolts

Hexagon Socket Head Cap Screws

Hexagon Socket Set Screws

Wing Bolts

Decoration Screws, Nuts

Nuts

Caps for Screw

Washers

Small Screws

Mischievous Prevention Screws

Drill Screws

Tapping Screws

Wood Screws

Nails



Stock 38,650 Items


Hexagon Socket Countersunk Head Screw (steel, half thread type)



- Features**
- The strength of the body where takes the load is higher compared with that of the full thread type.
- Specs**
- SSS Standard Product (SSS002-1977)
 - Tensile Strength Rank: 10.9
- Materials**
- Chromium Molybdenum Steel (SCM435)
 - Surface Treatment: Black Dye Finishing (triferric tetroxide coating)
- Origin**
- Japan



B73 Half Thread Type

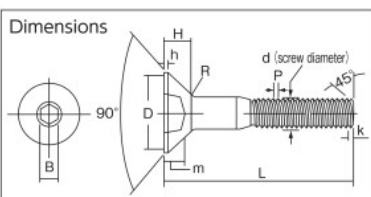

Basic Dimension		(unit: mm)							
Nominal Designation of Thread (d)	Thread Pitch (P)	d	D	H	B	m	R	k	h
		Basic Dimension	Basic Dimension	Max	Basic Dimension	Basic Dimension	Approx.	Max	Approx.
M8	1.25	8	16	4.4	5.0	3.5	0.4	1.8	0.4
M10	1.50	10	20	5.5	6.0	4.4	0.4	2.2	0.5

Order Unit: 1 Bag				TRUSCO NAKAYAMA CORPORATION			
Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
163-8734	B73-0850	¥778	¥840	M8 x 50	17	10	303.7
163-8866	B73-1050	¥778	¥840	M10 x 50	12	10	349.8

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items


Hexagon Socket Head Cap Bolt with Serrated Conical Spring Washer



- Features**
- A serrated conical spring washer is incorporated in the high strength bolt.
- Materials**
- Alloy steel for structure
 - Surface treatment: Nickel plating
- Origin**
- Japan



Y011 Full Thread Type

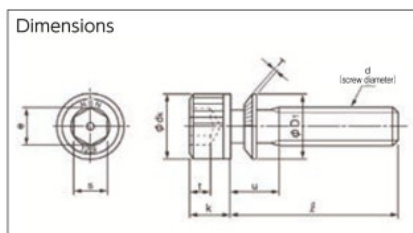

Basic Dimension		(unit: mm)				
Nominal Designation of Thread (d)	Thread Pitch (P)	dk	k	D1	T	
M3	0.5	5.5	3.0	5.5	0.5	
M4	0.7	7.0	4.0	7.0	0.6	
M5	0.8	8.5	5.0	8.5	0.7	
M6	1.0	10.0	6.0	10.0	0.8	

Order Unit: 1 Bag				TRUSCO NAKAYAMA CORPORATION			
Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
856-1135	Y011-0308	¥509	¥550	M3 x 8	13	5	11.2
856-1136	Y011-0310	¥509	¥550	M3 x 10	13	5	12.3
856-1137	Y011-0312	¥509	¥550	M3 x 12	13	5	13.4
856-1138	Y011-0316	¥509	¥550	M3 x 16	13	5	15.6
856-1139	Y011-0320	¥509	¥550	M3 x 20	12	5	16.5
856-1140	Y011-0406	¥509	¥550	M4 x 6	12	5	17.7
856-1141	Y011-0408	¥509	¥550	M4 x 8	12	5	20.0
856-1142	Y011-0410	¥509	¥550	M4 x 10	12	5	22.0
856-1143	Y011-0412	¥509	¥550	M4 x 12	12	5	23.1
856-1144	Y011-0416	¥509	¥550	M4 x 16	12	5	27.6
856-1145	Y011-0420	¥509	¥550	M4 x 20	12	5	31.2
856-1146	Y011-0512	¥509	¥550	M5 x 12	11	5	37.2
856-1147	Y011-0516	¥509	¥550	M5 x 16	11	5	41.8
856-1148	Y011-0520	¥509	¥550	M5 x 20	10	5	43.0
856-1149	Y011-0525	¥509	¥550	M5 x 25	9	5	44.3
856-1150	Y011-0610	¥509	¥550	M6 x 10	8	5	38.6
856-1151	Y011-0612	¥509	¥550	M6 x 12	8	5	40.4
856-1152	Y011-0616	¥509	¥550	M6 x 16	8	5	46.4
856-1153	Y011-0620	¥509	¥550	M6 x 20	7	5	45.6
856-1154	Y011-0625	¥509	¥550	M6 x 25	7	5	51.5

Contact us: 0120-509-849 <http://www.orange-book.com/>