

# Mischiefous Prevention Screws

Stock 181 Items

2-455

Screws • Bolts • Nuts


Prices displayed include 8% tax.

## Two Hole Pan Head Machine Screw (stainless steel) RoHS



B109 Type

- Features** • Cannot be removed with common tool due to double hole shape.
- Specs** • Tensile Strength Rank: Equivalent to A2-50
- Materials Origin** • Stainless Steel (A2) • USA

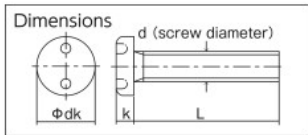

Basic Dimension (unit: mm)

Compatible Screwdriver	
M3	#4
M4	#8
M5	#10

Nominal Designation of Thread (d)	Head Outer Diameter dk	Head Thickness k
M3	6	1.8
M4	8	2.4
M5	10	3

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
765-0981	B109-0306	¥926	¥1,000	M3 x 6	4	10	12.2
765-0990	B109-0308	¥926	¥1,000	M3 x 8	4	10	12.5
765-1007	B109-0310	¥926	¥1,000	M3 x 10	4	10	12.8
765-1015	B109-0316	¥926	¥1,000	M3 x 16	4	10	14.0
765-1023	B109-0410	¥926	¥1,000	M4 x 10	5	10	17.2
765-1031	B109-0416	¥926	¥1,000	M4 x 16	5	10	19.9
765-1040	B109-0420	¥926	¥1,000	M4 x 20	4	10	18.4
765-1058	B109-0516	¥926	¥1,000	M5 x 16	5	10	26.2
765-1066	B109-0520	¥926	¥1,000	M5 x 20	4	10	24.8


Contact us: 0120-509-849 <http://www.orange-book.com/>

## Tri-Wing Countersunk Head Machine Screw (stainless steel) RoHS



B113 Type

- Features** • Since it is a triangle type groove shape, cannot be removed with normal tools.
- Specs** • Tensile Strength Rank: Equivalent to A2-50
- Materials Origin** • Stainless Steel (A2) • Japan

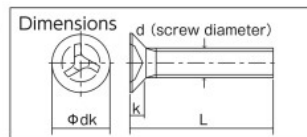

Basic Dimension (unit: mm)

Compatible Screwdriver	
M3	W2
M4	W4
M5	W5

Nominal Designation of Thread (d)	Head Outer Diameter dk	Head Thickness k
M3	5.5	1.65
M4	8.4	2.7
M5	9.3	2.7

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
765-1406	B113-0306	¥926	¥1,000	M3 x 6	14	10	14.8
765-1414	B113-0308	¥926	¥1,000	M3 x 8	14	10	16.0
765-1422	B113-0310	¥926	¥1,000	M3 x 10	14	10	17.0
765-1431	B113-0316	¥926	¥1,000	M3 x 16	13	10	20.0
765-1449	B113-0406	¥926	¥1,000	M4 x 6	14	10	21.5
765-1457	B113-0408	¥926	¥1,000	M4 x 8	14	10	23.4
765-1465	B113-0410	¥926	¥1,000	M4 x 10	14	10	26.0
765-1473	B113-0416	¥926	¥1,000	M4 x 16	13	10	30.5
765-1481	B113-0420	¥926	¥1,000	M4 x 20	11	10	30.7
765-1490	B113-0510	¥926	¥1,000	M5 x 10	10	10	25.0
765-1503	B113-0516	¥926	¥1,000	M5 x 16	10	10	35.0
765-1511	B113-0520	¥926	¥1,000	M5 x 20	9	10	37.0



Contact us: 0120-509-849 <http://www.orange-book.com/>

## Two Hole Countersunk Head Machine Screw (stainless steel) RoHS



 B110 Type

- Features** • Cannot be removed with common tool due to double hole shape.
- Specs** • Tensile Strength Rank: Equivalent to A2-50
- Materials Origin** • Stainless Steel (A2) • USA

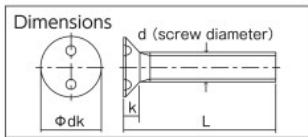

Basic Dimension (unit: mm)

Compatible Screwdriver	
M3	#4
M4	#8
M5	#10

Nominal Designation of Thread (d)	Head Outer Diameter dk	Head Thickness k
M3	5.6	1.65
M4	7.5	2.2
M5	9.2	2.5

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
765-1074	B110-0306	¥926	¥1,000	M3 x 6	4	10	11.4
765-1082	B110-0308	¥926	¥1,000	M3 x 8	4	10	11.8
765-1091	B110-0310	¥926	¥1,000	M3 x 10	4	10	12.1
765-1104	B110-0316	¥926	¥1,000	M3 x 16	4	10	13.2
765-1112	B110-0410	¥926	¥1,000	M4 x 10	5	10	15.2
765-1121	B110-0416	¥926	¥1,000	M4 x 16	4	10	15.7
765-1139	B110-0420	¥926	¥1,000	M4 x 20	4	10	17.2
765-1147	B110-0516	¥926	¥1,000	M5 x 16	4	10	19.2
765-1155	B110-0520	¥926	¥1,000	M5 x 20	4	10	21.7



Contact us: 0120-509-849 <http://www.orange-book.com/>

## Triangle Socket Button Bolt (stainless steel) RoHS



 B101 Type

- Features** • Cannot be removed with common tool due to triangular hole shape.
- Specs** • Tensile Strength Rank: Equivalent to A2-50
- Materials Origin** • Stainless Steel (A2) • Japan

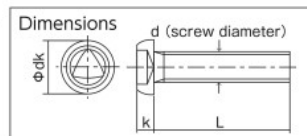

Basic Dimension (unit: mm)

Compatible Screwdriver	
M3	3
M4	4
M5	5

Nominal Designation of Thread (d)	Head Outer Diameter dk	Head Thickness k
M3	5.7	1.65
M4	7.6	2.2
M5	9.5	2.75

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
765-0060	B101-0306	¥926	¥1,000	M3 x 6	12	10	15.2
765-0078	B101-0308	¥926	¥1,000	M3 x 8	12	10	16.4
765-0086	B101-0310	¥926	¥1,000	M3 x 10	11	10	16.7
765-0094	B101-0316	¥926	¥1,000	M3 x 16	10	10	18.6
765-0108	B101-0406	¥926	¥1,000	M4 x 6	11	10	19.6
765-0116	B101-0408	¥926	¥1,000	M4 x 8	11	10	21.7
765-0124	B101-0410	¥926	¥1,000	M4 x 10	11	10	23.0
765-0132	B101-0416	¥926	¥1,000	M4 x 16	10	10	26.5
765-0141	B101-0420	¥926	¥1,000	M4 x 20	9	10	27.6
765-0159	B101-0510	¥926	¥1,000	M5 x 10	8	10	27.0
765-0167	B101-0516	¥926	¥1,000	M5 x 16	7	10	29.9
765-0175	B101-0520	¥926	¥1,000	M5 x 20	7	10	33.3

Contact us: 0120-509-849 <http://www.orange-book.com/>