

# Mischievous Prevention Screws

Stock 181 Items

2-457

Screws • Bolts • Nuts

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items** **5-Lobe Button Bolt (stainless steel)** RoHS


Com Drawing



B102 Type



Features • Since the shape has a vertical pin at the center of the 5 groove hole, cannot be removed by common tool.  
Specs • Tensile Strength Rank: Equivalent to A2-50  
Materials • Stainless Steel (A2)  
Origin • Japan

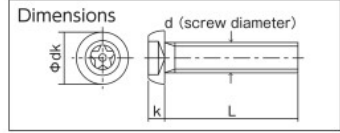

Basic Dimension (unit: mm)

Compatible Screwdriver		Nominal Designation of Thread (d)	Head Outer Diameter dk	Head Thickness k
M3	3	M3	5.7	1.63
M4	4	M4	7.6	2.2
M5	56	M5	9.5	2.75

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
765-0183	B102-0306	¥926	¥1,000	M3 x 6	12	10	15.2
765-0191	B102-0308	¥926	¥1,000	M3 x 8	12	10	16.4
765-0205	B102-0310	¥926	¥1,000	M3 x 10	11	10	16.5
765-0213	B102-0316	¥926	¥1,000	M3 x 16	10	10	18.4
765-0221	B102-0406	¥926	¥1,000	M4 x 6	11	10	19.8
765-0230	B102-0408	¥926	¥1,000	M4 x 8	11	10	21.6
765-0248	B102-0410	¥926	¥1,000	M4 x 10	11	10	23.3
765-0256	B102-0416	¥926	¥1,000	M4 x 16	10	10	26.4
765-0264	B102-0420	¥926	¥1,000	M4 x 20	9	10	27.6
765-0272	B102-0508	¥926	¥1,000	M5 x 8	8	10	24.8
765-0281	B102-0510	¥926	¥1,000	M5 x 10	8	10	26.8
765-0299	B102-0516	¥926	¥1,000	M5 x 16	7	10	30.1
765-0302	B102-0520	¥926	¥1,000	M5 x 20	7	10	33.5

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Hexagon Socket Head Set Screw with Pin (steel)** RoHS


Com Drawing



B105 Type



Features • Since the shape has a vertical pin at the center of the hexagon socket, cannot be removed by common tool.  
Specs • Tensile Strength Rank: 45H  
Materials • Alloy Steel  
• Surface Treatment: Black Dye  
Origin • Taiwan

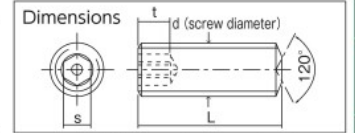

Basic Dimension (unit: mm)

Compatible Screwdriver		Nominal Designation of Thread (d)	s	t
M5	2.5	M5	2.5	min3
M6	3	M6	3	min3.5
M8	4	M8	4	min5

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
765-0540	B105-0508	¥926	¥1,000	M5 x 8	15	10	21.0
765-0558	B105-0510	¥926	¥1,000	M5 x 10	15	10	24.6
765-0566	B105-0608	¥926	¥1,000	M6 x 8	12	10	21.8
765-0574	B105-0610	¥926	¥1,000	M6 x 10	12	10	25.6
765-0582	B105-0616	¥926	¥1,000	M6 x 16	12	10	37.6
765-0591	B105-0810	¥926	¥1,000	M8 x 10	10	10	32.4
765-0604	B105-0816	¥926	¥1,000	M8 x 16	9	10	46.7

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items** **Tools for Tamper Proof Screws** RoHS

Com Drawing



B170 Type



B171 Type



B172 Type



B173 Type



B174 Type



B175 Type



B176 Type

**Bit** Features • Special bit for tamper resistant fastener. • Please use by inserting the screwdriver B178-0014 with magnet.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Type	Compatible	SPQ (piece)	Weight (g)
765-1619	B170-0002	¥870	¥940	Hexagon Socket with Pin	M3.0	1	4.8
765-1651	B170-0025	¥870	¥940	Hexagon Socket with Pin	M4.0	1	4.9
765-1627	B170-0003	¥870	¥940	Hexagon Socket with Pin	M5.0	1	4.8
765-1635	B170-0004	¥870	¥940	Hexagon Socket with Pin	M6.0	1	6.3
765-1643	B170-0005	¥870	¥940	Hexagon Socket with Pin	M8.0	1	5.5
765-1660	B171-0006	¥870	¥940	6-lobe	M2.0	1	4.3
765-1678	B171-0008	¥870	¥940	6-lobe	M2.6	1	4.3
765-1686	B171-0010	¥870	¥940	6-lobe	M3.0	1	4.4
765-1694	B171-0020	¥870	¥940	6-lobe	M4.0	1	4.6
765-1708	B171-0025	¥870	¥940	6-lobe	M5.0	1	4.8
765-1716	B172-0002	¥870	¥940	Tri-wing	M3.0	1	4.6
765-1724	B172-0004	¥870	¥940	Tri-wing	M4.0	1	5.0
765-1732	B172-0005	¥870	¥940	Tri-wing	M5.0	1	5.8

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Type	Compatible	SPQ (piece)	Weight (g)
765-1741	B173-0003	¥2,129	¥2,300	Triangle Socket	M3	1	5.9
765-1759	B173-0004	¥2,129	¥2,300	Triangle Socket	M4	1	6.3
765-1767	B173-0005	¥2,129	¥2,300	Triangle Socket	M5	1	6.5
765-1775	B174-0004	¥870	¥940	Two Hole	M3	1	4.6
765-1783	B174-0008	¥870	¥940	Two Hole	M4	1	4.8
765-1791	B174-0010	¥870	¥940	Two Hole	M5	1	5.3
765-1805	B175-0003	¥2,685	¥2,900	5-lobe	M3	1	6.0
765-1813	B175-0004	¥2,685	¥2,900	5-lobe	M4	1	7.0
765-1821	B175-0056	¥2,685	¥2,900	5-lobe	M5, 6	1	7.5
765-1830	B176-0002	¥870	¥940	Cross Recessed Pin	M3, 4, 5	1	5.0

## Screwdriver with Magnet

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	SPQ (piece)	Weight (g)
765-1864	B178-0014	¥3,703	¥4,000	1	100.0

## Remover Tool (for single sided screw)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible	SPQ (piece)	Weight (g)
765-1848	B177-0410	¥8,794	¥9,500	M3, 4	1	93.0
765-1856	B177-0510	¥8,794	¥9,500	M5	1	126.4

Contact us:0120-509-849 <http://www.orange-book.com/>



B177 Type (remover tool)