

# Low Head Tapping Screws

Stock 424Items

2-475

Prices displayed include 8% tax.

For Drill Screwdriver, see p. 5-124 to 156

TRUSCO Stock 38,650 Items

## Ultra Low Head Tapping Screw

RoHS

Com Drawing




TFTN Type (steel)



TFTS Type (stainless steel)

- Features**
- Since the height of the head is thin, the mounting surface can be flat.
  - Suitable for places where countersinking can not be performed, or where thickness becomes an obstacle.
- Origin**
- Japan

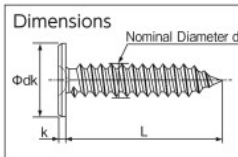

Compatible Screwdriver	
M3, M4	Plus No. 2

Basic Dimension (unit: mm)			
Nominal Diameter	Head Outer Diameter (Φ dk)	Head Thickness (k)	Screw Pilot Hole Dimension
d			
M3	8.0	0.9	2.6
M4	9.0	1.1	3.2

\*The screw pilot hole dimension is in case of the base material thickness of 1.2mm.

**Steel** Materials • Carbon steel for cold forging (SWRCH 18A)  
• Surface treatment: Nickel-plated finishing

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
819-5343	TFTN-0310	¥602	¥650	M3 x 10	30	10	19.6
819-5344	TFTN-0312	¥602	¥650	M3 x 12	30	10	21.4
819-5345	TFTN-0316	¥602	¥650	M3 x 16	30	10	24.9
819-5346	TFTN-0320	¥602	¥650	M3 x 20	26	10	25.3
819-5347	TFTN-0325	¥602	¥650	M3 x 25	24	10	27.3
819-5348	TFTN-0330	¥602	¥650	M3 x 30	20	10	26.7

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
819-5349	TFTN-0412	¥602	¥650	M4 x 12	22	10	27.6
819-5350	TFTN-0416	¥602	¥650	M4 x 16	20	10	29.7
819-5351	TFTN-0420	¥602	¥650	M4 x 20	18	10	31.0
819-5352	TFTN-0425	¥602	¥650	M4 x 25	16	10	32.3
819-5353	TFTN-0430	¥602	¥650	M4 x 30	14	10	32.6

**Stainless Steel** Materials • Stainless Steel (SUSXM7)

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
819-5354	TFTS-0310	¥741	¥800	M3 x 10	22	10	14.1
819-5355	TFTS-0312	¥741	¥800	M3 x 12	18	10	14.4
819-5356	TFTS-0316	¥741	¥800	M3 x 16	18	10	16.4
819-5357	TFTS-0320	¥741	¥800	M3 x 20	16	10	17.5
819-5358	TFTS-0325	¥741	¥800	M3 x 25	14	10	19.3
819-5359	TFTS-0330	¥741	¥800	M3 x 30	8	10	15.8

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
819-5360	TFTS-0412	¥741	¥800	M4 x 12	12	10	18.1
819-5361	TFTS-0416	¥741	¥800	M4 x 16	10	10	18.9
819-5362	TFTS-0420	¥741	¥800	M4 x 20	10	10	21.8
819-5363	TFTS-0425	¥741	¥800	M4 x 25	8	10	21.5
819-5364	TFTS-0430	¥741	¥800	M4 x 30	6	10	19.7

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

## Colored Low Head Tapping Screw

NEW



SCTN Type (white)

 
- Features**
- A tapping screw with a colored screw head.
  - Since the height of the head is thin, the mounting surface can be flat.
  - Suitable for places where countersinking can not be performed, or where thickness becomes an obstacle.
- Specs**
- For wood/thin iron plate.
- Materials**
- Stainless Steel (SUSXM7)
  - Head: Coated
- Origin**
- Japan




(black)



(gray)



(brown)

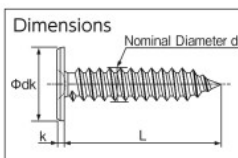

Compatible Screwdriver	
M3, M4	Plus No. 2

Basic Dimension (unit: mm)			
Nominal Diameter	Head Outer Diameter (Φ dk)	Head Thickness (k)	Screw Pilot Hole Dimension
d			
M3	8.0	0.9	2.6
M4	9.0	1.1	3.2

\*The screw pilot hole dimension is in case of the base material thickness of 1.2mm.

**White**

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Head Diameter (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
856-0838	SCTN-0312W	¥814	¥880	M3 x 12	8.0	18	10	17.7
856-0842	SCTN-0416W	¥907	¥980	M4 x 16	9.0	18	10	30.5
856-0846	SCTN-0420W	¥814	¥880	M4 x 20	9.0	10	10	22.5
856-0850	SCTN-0425W	¥768	¥830	M4 x 25	9.0	8	10	23.4

**Black**

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Head Diameter (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
856-0839	SCTN-0312BK	¥814	¥880	M3 x 12	8.0	18	10	17.7
856-0843	SCTN-0416BK	¥907	¥980	M4 x 16	9.0	18	10	30.5
856-0847	SCTN-0420BK	¥814	¥880	M4 x 20	9.0	10	10	22.5
856-0851	SCTN-0425BK	¥768	¥830	M4 x 25	9.0	8	10	23.4

**Gray**

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Head Diameter (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
856-0840	SCTN-0312GY	¥814	¥880	M3 x 12	8.0	18	10	17.7
856-0844	SCTN-0416GY	¥907	¥980	M4 x 16	9.0	18	10	30.5
856-0848	SCTN-0420GY	¥814	¥880	M4 x 20	9.0	10	10	22.5
856-0852	SCTN-0425GY	¥768	¥830	M4 x 25	9.0	8	10	23.4

**Brown**

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Head Diameter (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
856-0841	SCTN-0312BR	¥814	¥880	M3 x 12	8.0	18	10	17.7
856-0845	SCTN-0416BR	¥907	¥980	M4 x 16	9.0	18	10	30.5
856-0849	SCTN-0420BR	¥814	¥880	M4 x 20	9.0	10	10	22.5
856-0853	SCTN-0425BR	¥768	¥830	M4 x 25	9.0	8	10	23.4

Contact us: 0120-509-849 <http://www.orange-book.com/>

Screws • Bolts • Nuts

Hexagon Bolts

Hexagon Socket Head Cap Screws

Hexagon Socket Set Screws

Wing Bolts

Decorative Screws, Nuts

Nuts

Caps for Screw

Washers

Small Screws

Mischievous Prevention Screws

Drill Screws

Tapping Screws

Wood Screws

Nails