

Plate Type Rubber Casters (tire mark less type)

The number next to the logo mark indicates items in stock for each brand.

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers



Stock 38,650 Items


Plate Type Gray Rubber Caster (tire mark less type)



- Features**
- As the wheel employs gray rubber, tire marks on the floor surfaces can be reduced.
 - Steel wheels are shaped like a star with distinctive design characteristics. (registered design)
 - The adjustable pivot part adopts a double bearing, smooth rotation was achieved.
 - The wheel rotating part has excellent durability with commercial bearing.
- Specs**
- Plate Type
 - With Commercial Bearing
- Materials**
- Metal Fitting: Steel
 - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 - Wheel: Steel wheel, gray rubber
- Origin**
- Japan



TJB-G Type

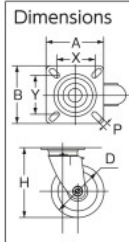

Flexible Specs • Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
772-9707	TJB-75G	¥1,286	¥1,390	64	65	75	32	100	82 x 82	63 x 63	9.5	25	0.60
772-9669	TJB-100G	¥1,759	¥1,900	78	80	100	35	144	95 x 95	67 to 74 x 67 to 74	10.5	18	1.15
772-9677	TJB-130G	¥2,703	¥2,920	147	150	130	42	177	110 x 110	75 to 90 x 75 to 90	11.0	10	1.95
772-9685	TJB-150G	¥3,018	¥3,260	167	170	150	45	198	120 x 120	75 to 90 x 75 to 90	11.0	8	2.25
772-9693	TJB-200G	¥4,888	¥5,280	225	230	200	46	250	140 x 140	100 to 115 x 100 to 115	11.5	4	3.75

TRUSCO NAKAYAMA CORPORATION



TJB-G Type

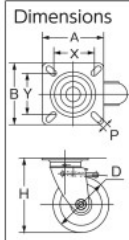


Flexible with double stopper Specs • Flexible Type (with double stopper)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
772-9758	TJB-75G	¥2,258	¥2,440	64	65	75	32	100	82 x 82	63 x 63	9.5	25	0.65
772-9715	TJB-100G	¥2,703	¥2,920	78	80	100	35	144	95 x 95	67 to 74 x 67 to 74	10.5	18	1.25
772-9723	TJB-130G	¥3,703	¥4,000	147	150	130	42	177	110 x 110	75 to 90 x 75 to 90	11.0	10	2.15
772-9731	TJB-150G	¥3,963	¥4,280	167	170	150	45	198	120 x 120	75 to 90 x 75 to 90	11.0	8	2.40
772-9740	TJB-200G	¥5,518	¥5,960	225	230	200	46	250	140 x 140	100 to 115 x 100 to 115	11.5	4	4.00



TK-G Type

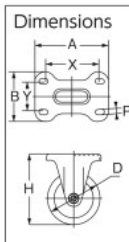


Fixed Specs • Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
772-9804	TK-75G	¥1,000	¥1,080	64	65	75	32	100	95 x 72	63 x 40	9.5	25	0.50
772-9766	TK-100G	¥1,314	¥1,420	78	80	100	35	144	115 x 80	80 to 90 x 45 to 50	10.5	18	0.85
772-9774	TK-130G	¥2,157	¥2,330	147	150	130	42	177	138 x 92	100 to 112 x 53 to 56	11.0	10	1.60
772-9782	TK-150G	¥2,472	¥2,670	167	170	150	45	198	138 x 92	100 to 112 x 53 to 56	11.0	8	1.85
772-9791	TK-200G	¥4,101	¥4,430	225	230	200	46	250	155 x 102	112 to 119 x 56 to 63	11.5	4	3.00



TW-G Type

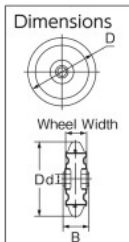

Replacement wheel

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Hub Width B (mm)	Hole Diameter d (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)						
772-9855	TW-75G	¥ 685	¥ 740	64	65	75	32	37	10	50	0.21
772-9812	TW-100G	¥ 907	¥ 980	78	80	100	35	44	12	50	0.35
772-9821	TW-130G	¥1,454	¥1,570	147	150	130	42	54	20	22	0.75
772-9839	TW-150G	¥1,713	¥1,850	167	170	150	45	55	20	18	0.98
772-9847	TW-200G	¥2,546	¥2,750	225	230	200	46	58	20	10	1.50

Contact us:0120-509-849 <http://www.orange-book.com/>

Selection Guide of Casters

Caster designation

Wheel designation