

# Plate Type Rubber Casters (tire mark less type)

Stock 646Items

2-667

Prices displayed include 8% tax.



Stock 38,650 Items

## Plate Type Gray Rubber Caster "High-tensile Caster" (tire mark less type)



It is thin, light, strong long life caster.

- Features**
- As the wheel employs gray rubber, tire marks on the floor surfaces can be reduced.
  - The durability of rotating part that will worn-out is more than 4 times due to usage of high-tensile steel. (compared with our existing items)
  - Silentness was improved due to adoption of radial bearings.
  - We used a high-tensile steel material with lightweight balance.
- Specs**
- Plate Type
  - With radial ball bearing
- Materials**
- Metal Fitting: High-Tensile Steel (steel)
  - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
  - Wheel: High-tensile material (steel) wheel, gray rubber
- Origin**
- Japan

☆Lifetime of turning part☆

High-tensile Steel → Hard  
Wear resistant ←


Long-lasting!



☆Running Silentness☆

With Radial Ball Bearing

→ Quiet!

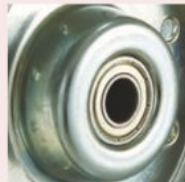


☆Lightweight☆


High-tensile Steel | Common Steel  
Strong High-Tensile Steel  
Thin Board → Light!

\*High-tensile steel is a steel material with higher strength than ordinary steel material, and it is widely used for car parts etc. because it is excellent in strength and safety even if it is made thin.

Comparison of high-tensile steel caster and pressed caster (existing items)

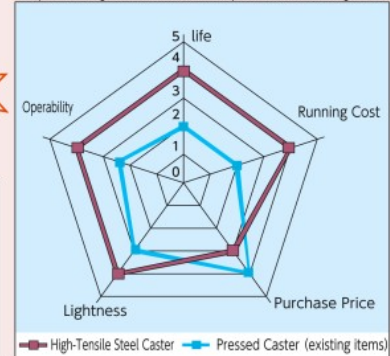

HTTJ-G Type

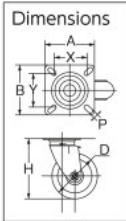

**Flexible** Specs •Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
772-9545	HTTJ-100G	¥2,258	¥2,440	98 100	100	32	144	95 x 95	67 to 74 x 67 to 74	11	18	0.92
772-9553	HTTJ-130G	¥3,601	¥3,890	177 180	130	38	177	110 x 110	75 to 90 x 75 to 90	11	10	1.39
772-9561	HTTJ-150G	¥3,916	¥4,230	196 200	150	40	198	120 x 120	75 to 90 x 75 to 90	11	8	1.60

TRUSCO NAKAYAMA CORPORATION



HTTJB-G Type

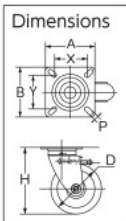

**Flexible with double stopper** Specs •Flexible Type (with double stopper)


•Simultaneously lock the turning part and the wheel

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
772-9570	HTTJB-100G	¥3,222	¥3,480	98 100	100	32	144	95 x 95	67 to 74 x 67 to 74	11	18	1.01
772-9588	HTTJB-130G	¥4,323	¥4,670	177 180	130	38	177	110 x 110	75 to 90 x 75 to 90	11	10	1.56
772-9596	HTTJB-150G	¥4,832	¥5,220	196 200	150	40	198	120 x 120	75 to 90 x 75 to 90	11	8	1.77



HTTK-G Type

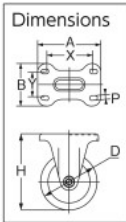


**Fixed** Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
772-9600	HTTK-100G	¥1,750	¥1,890	98 100	100	32	144	115 x 80	80 to 90 x 45 to 50	11	18	0.73
772-9618	HTTK-130G	¥2,841	¥3,070	177 180	130	38	177	138 x 92	100 to 112 x 53 to 56	11	10	1.13
772-9626	HTTK-150G	¥3,110	¥3,360	196 200	150	40	198	138 x 92	100 to 112 x 53 to 56	11	8	1.28



HTW-G Type

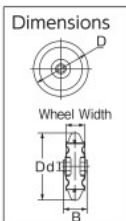

**Replacement wheel**

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Hub Width B (mm)	Hole Diameter d (mm)	SPQ (piece)	Weight (kg)
772-9634	HTW-100G	¥1,176	¥1,270	98 100	100	32	39.6	12	50	0.35
772-9642	HTW-130G	¥1,824	¥1,970	177 180	130	38	50.0	15	22	0.57
772-9651	HTW-150G	¥2,148	¥2,320	196 200	150	40	50.0	15	18	0.71

Contact us: 0120-509-849 <http://www.orange-book.com/>

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers