

Plate Type Urethane Casters (for medium/heavy load)

The number next to the logo mark indicates items in stock for each brand.



Stock 38,650 Items

Plate Type Caster "High-tensile Caster" (pressed urethane wheel)




Casters

- Plate Type Rubber Casters
- Plate Type Urethane Casters
- Plate Type Nylon Casters
- Plate Type Resin Casters
- Screwed Rubber Casters
- Screwed Urethane Casters
- Screwed Nylon Casters
- Screwed Resin Casters

It is thin, light, strong long life caster.

☆Lifetime of turning part☆
High-tensile Steel → Hard
Wear resistant ←
Long-lasting!

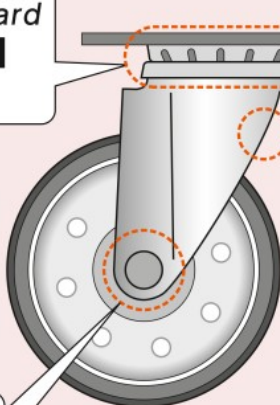


☆Running Silentness☆
With Radial Ball Bearing
Quiet!




- Features
- The durability of rotating part that will worn-out is more than 4 times due to usage of high-tensile steel. (compared with our existing items)
 - Silentness was improved due to adoption of radial bearings.
 - We used a High-tensile steel material with lightweight balance.
- Specs
- Plate Type
 - With radial ball bearing
- Materials
- Metal Fitting: High-tensile Steel (steel)
 - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 - Wheel: High-tensile Steel (steel) Wheel, Urethane
- Origin
- Japan

☆Lightweight☆
High-tensile Steel | Common Steel
Strong High-tensile Steel
Thin Board → **Light!**

*High-tensile steel is a steel material with higher strength than ordinary steel material, and it is widely used for car parts etc. because it is excellent in strength and safety even if it is made thin.

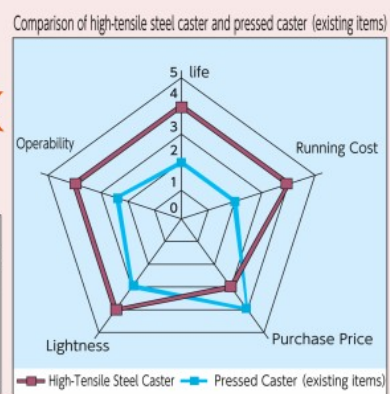


- Nuts, Spanners
- Stem Casters
- Stainless Steel Casters
- Angle Casters
- Corner Casters
- Dual Wheel Casters
- Sound Reducing Casters
- ESD-Safe Casters
- Shock Absorbing Casters
- Casters for Specific Environment
- Pneumatic/No-Puncture Caster
- Low Level Casters
- Heavy-Duty Casters
- Casting Casters
- Stoppers

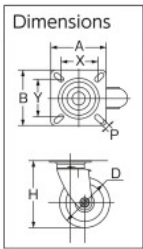

Flexible Specs •Flexible Type

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
392-5773	HTTUJ-100	¥3,165	¥3,420	171 174	100	32	144	95 x 95	67 to 74 x 67 to 74	11	18	0.93
392-5781	HTTUJ-130	¥4,471	¥4,830	250 255	130	38	177	110 x 110	75 to 90 x 75 to 90	11	10	1.40
392-5790	HTTUJ-150	¥5,202	¥5,620	300 306	150	40	198	120 x 120	75 to 90 x 75 to 90	11	8	1.61

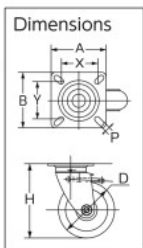

Flexible with double stopper Specs •Flexible Type (with double stopper) •Simultaneously lock the turning part and the wheel (Price revision date: Jan, 2015)

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
392-5803	HTTUJB-100	¥3,786	¥4,090	171 174	100	32	144	95 x 95	67 to 74 x 67 to 74	11	18	1.02
392-5811	HTTUJB-130	¥5,360	¥5,790	250 255	130	38	177	110 x 110	75 to 90 x 75 to 90	11	10	1.57
392-5820	HTTUJB-150	¥6,249	¥6,750	300 306	150	40	198	120 x 120	75 to 90 x 75 to 90	11	8	1.78

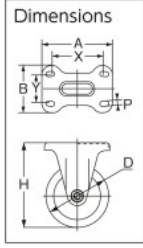

Fixed Specs •Fixed Type (Price revision date: Jan, 2015)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
392-5838	HTTUK-100	¥2,592	¥2,800	171 174	100	32	144	115 x 80	80 to 90 x 45 to 50	11	18	0.74
392-5846	HTTUK-130	¥3,870	¥4,180	250 255	130	38	177	138 x 92	100 to 112 x 53 to 56	11	10	1.14
392-5854	HTTUK-150	¥4,611	¥4,980	300 306	150	40	198	138 x 92	100 to 112 x 53 to 56	11	8	1.29

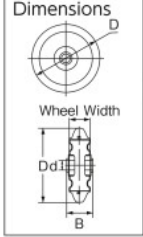

Replacement wheel (Price revision date: Jan, 2015)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Hub Width B (mm)	Hole Diameter d (mm)	SPQ (piece)	Weight (kg)
392-5862	HTUW-100	¥2,148	¥2,320	171 174	100	32	39.6	12	50	0.36
392-5871	HTUW-130	¥3,471	¥3,750	250 255	130	38	50.0	15	22	0.58
392-5889	HTUW-150	¥4,277	¥4,620	300 306	150	40	50.0	15	18	0.72

Contact us:0120-509-849 <http://www.orange-book.com/>