

Plate Type Stainless Steel Casters (rubber wheel)

Stock 338 Items

2-727

Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items

Plate Type Noise Reduction Caster (nylon wheel rubber tire/stainless steel fittings)


RoHS



- Features**
- The pivot part is sealed with rubber packings forming dust-proof and water-proof structure.
 - There is no unpleasant sound such as traveling sound that is specific to casters. (noise-free type)
 - Resistance during push start is reduced, turning/rotating is very easy. The wheel is an original star shape pattern.
- Specs**
- Plate Type
 - Swivel, Rotating Part: Using Radial Ball Bearing
 - With drip-proof and dust-proof cover
- Materials**
- Metal Fitting: Stainless Steel (SUS304)
 - Bearing: Steel
 - Wheel: Nylon wheel, rubber (with steel wheel cover)
- Origin**
- Japan



TXSJ Type

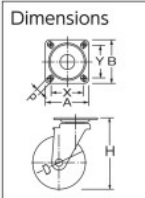


Flexible Specs •Flexible Type

Order Unit: 1 Piece (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
256-0615	TXSJ-100	¥4,249	¥4,590	100	102	100	33	132	95 x 95	67 to 74 x 67 to 74	11	18	1.08
256-0623	TXSJ-125	¥5,684	¥6,140	130	133	125	40	168	110 x 110	75 to 90 x 75 to 90	11	10	1.63
256-0631	TXSJ-150	¥6,036	¥6,520	140	143	150	40	190	110 x 110	75 to 90 x 75 to 90	11	8	1.79



TXSJB Type

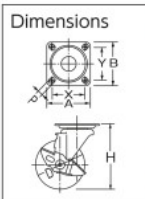


Flexible with stopper Specs •Flexible Type (with stopper)

Order Unit: 1 Piece (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
256-0739	TXSJB-100	¥4,888	¥5,280	100	102	100	33	132	95 x 95	67 to 74 x 67 to 74	11	18	1.17
256-0747	TXSJB-125	¥6,646	¥7,180	130	133	125	40	168	110 x 110	75 to 90 x 75 to 90	11	10	1.67
256-0755	TXSJB-150	¥6,850	¥7,400	140	143	150	40	190	110 x 110	75 to 90 x 75 to 90	11	8	1.99



TXSK Type

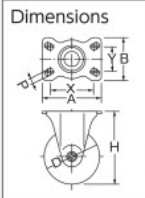

Fixed Specs •Fixed Type

Order Unit: 1 Piece (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
256-0674	TXSK-100	¥2,962	¥3,200	100	102	100	33	132	115 x 80	80 to 90 x 45 to 50	11	18	0.82
256-0682	TXSK-125	¥4,110	¥4,440	130	133	125	40	168	138 x 92	100 to 112 x 53 to 56	11	10	1.25
256-0691	TXSK-150	¥4,554	¥4,920	140	143	150	40	190	138 x 92	100 to 112 x 53 to 56	11	8	1.41

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 793 Items


Plate Type Caster "320S Series" (rubber wheel/stainless steel metal fittings)

RoHS

- Features**
- Since it is all stainless steel, it has excellent durability and water resistance.
- Specs**
- Plate Type
- Materials**
- Metal Fitting: Stainless Steel (SUS304)
 - Wheel: Rubber
- Origin**
- Japan



320S-RU100-BAR01

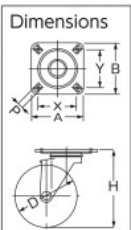


Flexible Specs •Flexible Type

Order Unit: 1 Piece HAMMER CASTER Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
242-1518	320S-RD50-BAR01	¥1,716	-	50	51.0	50	26	70	70 x 58	55 x 42	8.8	4	300
125-1252	320S-R65-BAR01	¥1,900	-	50	51.0	65	26	85	70 x 58	55 x 42	8.8	4	350
125-1261	320S-R75-BAR01	¥2,066	-	60	61.2	75	26	93	70 x 58	55 x 42	8.8	4	400
125-1279	320S-RU100-BAR01	¥4,349	-	120	122.4	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	1	890
125-1287	320S-RU125-BAR01	¥6,732	-	150	153.0	125	38	168	102 x 102	75 to 80 x 75 to 80	11.0	1	1550
125-1295	320S-RU150-BAR01	¥7,862	-	160	163.2	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	1	1740



315S-RU100-BAR01

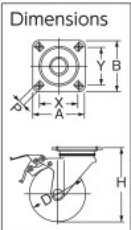


Flexible with stopper Specs •Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
242-1577	315S-RD50-BAR01	¥1,936	-	50	51.0	50	26	70	70 x 58	55 x 42	8.8	4	340
125-1350	315S-R65-BAR01	¥2,120	-	50	51.0	65	26	85	70 x 58	55 x 42	8.8	4	410
125-1368	315S-R75-BAR01	¥2,336	-	60	61.2	75	26	93	70 x 58	55 x 42	8.8	4	450
125-1376	315S-RU100-BAR01	¥6,263	-	120	122.4	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	1	1060
125-1384	315S-RU125-BAR01	¥8,877	-	150	153.0	125	38	168	102 x 102	75 to 80 x 75 to 80	11.0	1	1760
125-1392	315S-RU150-BAR01	¥9,957	-	160	163.2	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	1	1980



320SR-RU100-BAR01

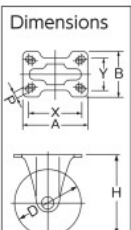

Fixed Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
242-1526	320SR-RD50-BAR01	¥ 739	-	50	51.0	50	26	70	70 x 47	55 x 28	8.8	4	190
125-1309	320SR-R65-BAR01	¥ 922	-	50	51.0	65	26	85	70 x 47	55 x 28	8.8	4	250
125-1317	320SR-R75-BAR01	¥ 1,317	-	60	61.2	75	26	93	70 x 47	55 x 28	8.8	4	290
125-1325	320SR-RU100-BAR01	¥3,323	-	120	122.4	100	32	132	110 x 78	80 to 90 x 45 to 50	11.0	1	650
125-1333	320SR-RU125-BAR01	¥5,280	-	150	153.0	125	38	168	140 x 94	100 to 112 x 53 to 56	11.0	1	1110
125-1341	320SR-RU150-BAR01	¥6,084	-	160	163.2	150	40	190	140 x 94	100 to 112 x 53 to 56	11.0	1	1420

URL <http://www.hammer-caster.co.jp/>

Wheel Diameter (mm)	Wheel Shape
50, 65, 75	Rubber-Integrated Wheel (with resin bush)
100, 125, 150	Nylon Wheel Rubber Roll Tire

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers