

# Plate Type Noise-reducing Casters

The number next to the logo mark indicates items in stock for each brand.

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers



Stock 38,650 Items

## Plate Type Noise Reduction Caster (nylon wheel rubber tire)




- Features**
- There is no unpleasant sound such as traveling sound that is specific to casters. (noise-free type)
  - Resistance during push start is reduced, turning/rotating is very easy. The wheel is an original star shape pattern.
- Specs**
- Plate Type
  - Swivel, Rotating Part: Using Radial Ball Bearing
- Materials**
- Metal Fitting: Steel
  - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
  - Wheel: Nylon Wheel, Rubber
- Origin**
- Japan



It is optimum to use on urban walkways and condominium roads where there are many casters tiles and brick-like pavements with noise reduction caster.



TXJ-Type

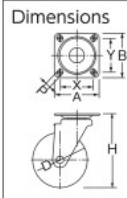

**Flexible** Specs •Flexible Type


Order Unit: 1 Piece

(Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Allowable Weight (daN) (kgf) | Wheel Diameter D (mm) | Wheel Width (mm) | Mounting Height H (mm) | Mounting Plate A x B (mm) | Mounting Pitch X x Y (mm) | Mounting Hole Diameter P (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------------------|-----------------------|------------------|------------------------|---------------------------|---------------------------|-------------------------------|-------------|-------------|
| 255-9498   | TXJ-100  | ¥1,786            | ¥1,930           | 100 102                      | 100                   | 33               | 132                    | 95 x 95                   | 67 to 74 x 67 to 74       | 11                            | 18          | 1.04        |
| 255-9501   | TXJ-125  | ¥2,398            | ¥2,590           | 130 133                      | 125                   | 40               | 168                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 10          | 1.56        |
| 255-9510   | TXJ-150  | ¥2,647            | ¥2,860           | 140 143                      | 150                   | 40               | 190                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 8           | 1.65        |



TXJB-Type

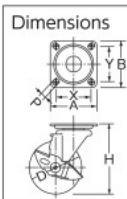

**Flexible with stopper** Specs •Flexible Type (with stopper)


Order Unit: 1 Piece

(Price revision date: Jan, 2015)

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Allowable Weight (daN) (kgf) | Wheel Diameter D (mm) | Wheel Width (mm) | Mounting Height H (mm) | Mounting Plate A x B (mm) | Mounting Pitch X x Y (mm) | Mounting Hole Diameter P (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------------------|-----------------------|------------------|------------------------|---------------------------|---------------------------|-------------------------------|-------------|-------------|
| 255-9561   | TXJB-100 | ¥2,426            | ¥2,620           | 100 102                      | 100                   | 33               | 132                    | 95 x 95                   | 67 to 74 x 67 to 74       | 11                            | 18          | 1.14        |
| 255-9579   | TXJB-125 | ¥3,138            | ¥3,390           | 130 133                      | 125                   | 40               | 168                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 10          | 1.76        |
| 255-9587   | TXJB-150 | ¥3,425            | ¥3,700           | 140 143                      | 150                   | 40               | 190                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 8           | 1.91        |



TXK-Type

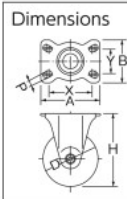

**Fixed** Specs •Fixed Type

Order Unit: 1 Piece

(Price revision date: Jan, 2015)

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Allowable Weight (daN) (kgf) | Wheel Diameter D (mm) | Wheel Width (mm) | Mounting Height H (mm) | Mounting Plate A x B (mm) | Mounting Pitch X x Y (mm) | Mounting Hole Diameter P (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------------------|-----------------------|------------------|------------------------|---------------------------|---------------------------|-------------------------------|-------------|-------------|
| 255-9625   | TXK-100  | ¥1,435            | ¥1,550           | 100 102                      | 100                   | 33               | 132                    | 115 x 80                  | 80 to 90 x 45 to 50       | 11                            | 18          | 0.79        |
| 255-9633   | TXK-125  | ¥1,889            | ¥2,040           | 130 133                      | 125                   | 40               | 168                    | 138 x 92                  | 100 to 112 x 53 to 56     | 11                            | 10          | 1.17        |
| 255-9641   | TXK-150  | ¥2,129            | ¥2,300           | 140 143                      | 150                   | 40               | 190                    | 138 x 92                  | 100 to 112 x 53 to 56     | 11                            | 8           | 1.30        |

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items


## Plate Type Noise Reduction Caster (nylon wheel urethane tire)



- Features**
- There is no unpleasant sound such as traveling sound that is specific to casters. (noise-free type)
  - Resistance during push start is reduced, turning/rotating is very easy.
  - The wheel is an original star shape pattern.
- Specs**
- Plate Type
  - Rotating Part, Rotating Part: Using Radial Ball Bearing
- Materials**
- Metal Fitting: Steel
  - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
  - Wheel: Nylon Wheel, Urethane
- Origin**
- Japan



TXUJ-Type

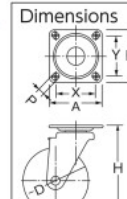

**Flexible** Specs •Flexible Type


Order Unit: 1 Piece

(Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Allowable Weight (daN) (kgf) | Wheel Diameter D (mm) | Wheel Width (mm) | Mounting Height H (mm) | Mounting Plate A x B (mm) | Mounting Pitch X x Y (mm) | Mounting Hole Diameter P (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------------------|-----------------------|------------------|------------------------|---------------------------|---------------------------|-------------------------------|-------------|-------------|
| 255-9536   | TXUJ-100 | ¥2,685            | ¥2,900           | 100 102                      | 100                   | 33               | 132                    | 95 x 95                   | 67 to 74 x 67 to 74       | 11                            | 18          | 1.08        |
| 255-9544   | TXUJ-125 | ¥3,777            | ¥4,080           | 130 133                      | 125                   | 40               | 168                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 10          | 1.63        |
| 255-9552   | TXUJ-150 | ¥4,175            | ¥4,510           | 140 143                      | 150                   | 40               | 190                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 8           | 1.80        |



TXUJB-Type

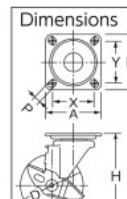

**Flexible with stopper** Specs •Flexible Type (with stopper)

Order Unit: 1 Piece

(Price revision date: Jan, 2015)

| Order Code | Item No.  | Price (per piece) | MSRP (per piece) | Allowable Weight (daN) (kgf) | Wheel Diameter D (mm) | Wheel Width (mm) | Mounting Height H (mm) | Mounting Plate A x B (mm) | Mounting Pitch X x Y (mm) | Mounting Hole Diameter P (mm) | SPQ (piece) | Weight (kg) |
|------------|-----------|-------------------|------------------|------------------------------|-----------------------|------------------|------------------------|---------------------------|---------------------------|-------------------------------|-------------|-------------|
| 255-9595   | TXUJB-100 | ¥3,601            | ¥3,890           | 100 102                      | 100                   | 33               | 132                    | 95 x 95                   | 67 to 74 x 67 to 74       | 11                            | 18          | 1.17        |
| 255-9609   | TXUJB-125 | ¥4,453            | ¥4,810           | 130 133                      | 125                   | 40               | 168                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 10          | 1.83        |
| 255-9617   | TXUJB-150 | ¥5,388            | ¥5,820           | 140 143                      | 150                   | 40               | 190                    | 110 x 110                 | 75 to 90 x 75 to 90       | 11                            | 8           | 1.96        |



TXUK-Type



**Fixed** Specs •Fixed Type

Order Unit: 1 Piece

(Price revision date: Jan, 2015)

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Allowable Weight (daN) (kgf) | Wheel Diameter D (mm) | Wheel Width (mm) | Mounting Height H (mm) | Mounting Plate A x B (mm) | Mounting Pitch X x Y (mm) | Mounting Hole Diameter P (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------------------|-----------------------|------------------|------------------------|---------------------------|---------------------------|-------------------------------|-------------|-------------|
| 255-9650   | TXUK-100 | ¥2,185            | ¥2,360           | 100 102                      | 100                   | 33               | 132                    | 115 x 80                  | 80 to 90 x 45 to 50       | 11                            | 18          | 0.83        |
| 255-9668   | TXUK-125 | ¥3,074            | ¥3,320           | 130 133                      | 125                   | 40               | 168                    | 138 x 92                  | 100 to 112 x 53 to 56     | 11                            | 10          | 1.27        |
| 255-9676   | TXUK-150 | ¥3,315            | ¥3,580           | 140 143                      | 150                   | 40               | 190                    | 138 x 92                  | 100 to 112 x 53 to 56     | 11                            | 8           | 1.36        |

Contact us:0120-509-849 <http://www.orange-book.com/>