

Plate Type Noise-reducing Casters

Stock 80Items

2-763

Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items


Plate Type Noise Reduction Caster (nylon wheel rubber tire)



- Features** •The original structure "DRS" is employed in which the double bearing specification enables extremely smooth turning to realize comfortable handling.
- Specs** •Plate Type
•Noise reduction Specifications
- Materials** •Main Body: Nylon
- Origin** •Japan

Demonstrates high performance by innovative structure "DRS"

The pivot part employs the original structure "DRS" (Dual Receive Structure) which is patented*. The load capacity is larger than that of our competitors and the turning is smooth. The wheel part also employs radial ball bearing. By the multiplied effect with the pivot part structure, the moving noise is very little to realize comfortable handling.

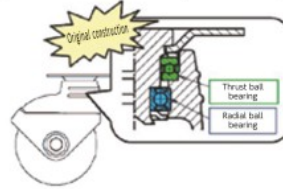

"DRS" is a structure in which the thrust ball bearing receives the load and radial ball bearing receives the twist force of the shaft. These 2 types of bearings securely receive the burden generating during driving.

*Patent No. 4234669

Flexible Specs •Flexible Type Materials •Wheel: Nylon Wheel, Rubber


Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
277-6588	TYPJ-100	¥2,157	¥2,330	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	9	16	1.02
277-6596	TYPJ-130	¥2,537	¥2,740	130 132.6	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	1.32



TYPJ-130

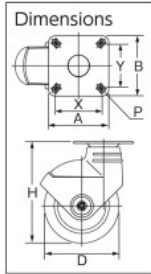

TYPK-130

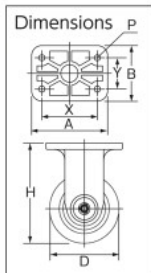


Fixed Specs •Fixed Type Materials •Wheel: Nylon Wheel, Rubber

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
277-6600	TYPK-100	¥1,537	¥1,660	100 102.0	100	32	144	110 x 80	80 x 45	9	16	0.57
277-6618	TYPK-130	¥1,750	¥1,890	130 132.6	130	40	177	130 x 90	100 x 56	11	8	0.84



TYPGJ-130BK

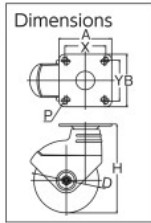

Gray rubber specification (tire mark less type) /flexible Features •As the wheel employs gray rubber, generation of tire marks can be reduced.

Specs •Flexible Type


Materials •Wheel: Nylon wheel, gray rubber

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
466-4957	TYPGJ-100BK	¥2,314	¥2,500	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	9	16	1.02
466-4965	TYPGJ-130BK	¥2,703	¥2,920	130 132.6	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	1.32



TYPGK-100BK

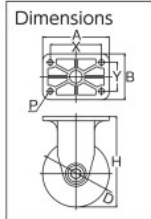

Gray rubber specification (tire mark less type) /fixed Features •As the wheel employs gray rubber, generation of tire marks can be reduced.

Specs •Fixed Type

Materials •Wheel: Nylon wheel, gray rubber

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
466-4973	TYPGK-100BK	¥1,805	¥1,950	100 102.0	100	32	144	110 x 80	80 x 45	9	16	0.57
466-4981	TYPGK-130BK	¥2,231	¥2,410	130 132.6	130	40	177	130 x 90	100 x 56	11	8	0.84

Contact us:0120-509-849 <http://www.orange-book.com/>

YUEI
 Stock 700 Items

Plate Type Noise Reduction Caster (nylon wheel rubber tire)



- Features** •A silent type. •Grey wheels, which are hard to soil the floor, are used.
- Specs** •Plate Type •With radial ball bearing
- Materials** •Metal Fitting: Steel •Metal Fitting Surface Treatment: Trivalent Unichrome Plated
- Wheel: Nylon Wheel, Rubber
- Origin** •Japan

Flexible Specs •Flexible Type


Order Unit: 1 Piece

YUEI CASTER Co.Ltd


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
380-3317	RJ2F-150NWR-G	¥2,700	-	120 122.4	150	34	190	102 x 102	75 to 80 x 75 to 80	11	4	1.3



RJ2F-150NWR-G

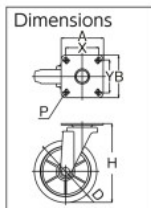

RJ2F-150NWR-G

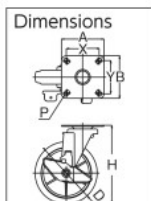

Flexible with stopper Specs •Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
380-3325	RJ2F-150NWR-G	¥3,214	-	120 122.4	150	34	190	102 x 102	75 to 80 x 75 to 80	11	4	1.5

Contact us:06-6747-5618 <http://www.yueicaster.co.jp/>

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers