

Welded Hinges (stainless steel)

For machine parts hinges, see p. 2-330 to 340

The number next to the logo mark indicates items in stock for each brand.

Hardware

TRUSCO

 


Stock 38,650 Items

Super Thick Welding Hinge



- Specs • Surface treatment: Hair line finishing
 • Mounting Method: Welding Type
 Materials • **Stainless Steel (SUS304)**
 Origin • Japan



ST-1000W-76

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-6162	ST-1000W-51	¥1,518	¥1,640	51	49	2.0	8	10	2	104
233-6171	ST-1000W-64	¥2,074	¥2,240	64	63	2.5	10	15	2	210
233-6189	ST-1000W-76	¥2,546	¥2,750	76	72	2.5	10	20	2	282
233-6197	ST-1000W-89	¥1,990	¥2,150	89	84	3.0	12	30	1	233
233-6201	ST-1000W-102	¥2,546	¥2,750	102	100	3.0	12	35	1	306
233-6219	ST-1000W-127	¥5,369	¥5,800	127	120	4.0	20	60	1	721
233-6227	ST-1000W-153	¥6,665	¥7,200	150	120	4.0	20	80	1	842

TRUSCO NAKAYAMA CORPORATION

Contact us: 0120-509-849 <http://www.orange-book.com/>

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

TRUSCO



Stock 38,650 Items

Super Thick Welding Flag Hinge



- Specs • Surface treatment: Hair line finishing
 • Mounting Method: Welding Type
 Materials • **Stainless Steel (SUS304)**
 Origin • Japan



ST-2000W-127R (for right)

For right

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
512-7939	ST-2000W-76R	¥2,823	¥3,050	78	102	3	18	30	2	492
512-7947	ST-2000W-102R	¥3,018	¥3,260	102	100	3	18	45	2	618
512-7955	ST-2000W-127R	¥1,759	¥1,900	127	112	3	18	55	1	397
512-7963	ST-2000W-153R	¥2,268	¥2,450	148	112	3	18	70	1	454


TRUSCO NAKAYAMA CORPORATION

For left

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-6260	ST-2000W-76L	¥2,823	¥3,050	78	102	3	18	30	2	492
233-6278	ST-2000W-102L	¥3,018	¥3,260	102	100	3	18	45	2	618
233-6286	ST-2000W-127L	¥1,759	¥1,900	127	112	3	18	55	1	397
233-6294	ST-2000W-153L	¥2,268	¥2,450	148	112	3	18	70	1	454

 Contact us: 0120-509-849 <http://www.orange-book.com/>



Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

TRUSCO




Stock 38,650 Items

Long Hinge



- Specs • Surface treatment: Mirror buffing process finishing
 • Mounting Method: Welding Type
 Materials • **Stainless Steel (SUS304)**
 Origin • Japan

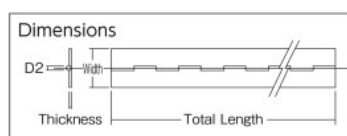

THS-1550-1000

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	SPQ (piece)	Weight (kg)
285-2993	THS-0825-300	¥ 658	¥ 710	300	25	0.8	2.5	20	0.07
285-2985	THS-0825-600	¥1,000	¥1,080	600	25	0.8	2.5	20	0.13
285-2977	THS-0825-1000	¥1,555	¥1,680	1000	25	0.8	2.5	10	0.22
285-2969	THS-0825-1800	¥3,101	¥3,350	1800	25	0.8	2.5	10	0.40
285-2951	THS-0832-300	¥ 666	¥ 720	300	32	0.8	2.5	20	0.08
285-2942	THS-0832-450	¥ 926	¥1,000	450	32	0.8	2.5	20	0.12
285-2934	THS-0832-600	¥1,065	¥1,150	600	32	0.8	2.5	20	0.16
285-2926	THS-0832-1000	¥1,713	¥1,850	1000	32	0.8	2.5	10	0.26
285-2918	THS-0832-1800	¥3,222	¥3,480	1800	32	0.8	2.5	10	0.50
285-3051	THS-0838-1000	¥1,805	¥1,950	1000	38	0.8	2.5	10	0.30
285-3043	THS-0838-1800	¥3,286	¥3,550	1800	38	0.8	2.5	10	0.55
285-3132	THS-1532-300	¥1,111	¥1,200	300	32	1.5	3.5	20	0.17
285-3124	THS-1532-350	¥1,278	¥1,380	350	32	1.5	3.5	20	0.19
285-3116	THS-1532-450	¥1,666	¥1,800	450	32	1.5	3.5	20	0.25
285-3108	THS-1532-600	¥2,175	¥2,350	600	32	1.5	3.5	20	0.34
285-3094	THS-1532-750	¥2,638	¥2,850	750	32	1.5	3.5	10	0.41
285-3086	THS-1532-850	¥3,009	¥3,250	850	32	1.5	3.5	10	0.47
285-3078	THS-1532-900	¥3,222	¥3,480	900	32	1.5	3.5	10	0.50
285-3060	THS-1532-1000	¥3,333	¥3,600	1000	32	1.5	3.5	10	0.58
285-3035	THS-1538-1000	¥3,333	¥3,600	1000	38	1.5	3.5	10	0.66
285-3027	THS-1538-1800	¥6,017	¥6,500	1800	38	1.5	3.5	10	1.09
285-3019	THS-1550-1000	¥3,842	¥4,150	1000	50	1.5	3.5	10	0.74
285-3001	THS-1550-1800	¥6,619	¥7,150	1800	50	1.5	3.5	10	1.36

TRUSCO NAKAYAMA CORPORATION

Contact us: 0120-509-849 <http://www.orange-book.com/>