

The number next to the logo mark indicates items in stock for each brand.

TRUSCO **Stock 38,650 Items**

Vehicle Door Stop Bracket (horizontal type)



Com **eco** Chemical Content Inspection **Com** Drawing

TDF-130Y

Features •Made of stainless steel and excellent in corrosion resistance.
 Use •Used as a stud when opening the door at the rear of the box type/container type truck.
 Materials •Stainless Steel (SUS304)
 Origin •China



Order Unit: 1 Set (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	A (mm)	W1 (mm)	d1 (mm)	C (mm)	B (mm)	L (mm)	W2 (mm)	d2 (mm)	SPQ (set)	Weight (g/set)
284-8082	TDF-130Y	¥2,083	¥2,250	62	20	6	6	137	31	25.2	6.5	20	138
284-8091	TDF-160Y	¥2,185	¥2,360	62	20	6	6	167	31	25.2	6.5	20	147

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Vehicle Door Stop Bracket (vertical type)



Com **eco** Chemical Content Inspection **Com** Drawing

TDF-130T

Features •Made of stainless steel and excellent in corrosion resistance.
 Use •Used as a stud when opening the door at the rear of the box type/container type truck.
 Materials •Stainless Steel (SUS304)
 Origin •China



Order Unit: 1 Set (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	A (mm)	W1 (mm)	d1 (mm)	C (mm)	B (mm)	L (mm)	W2 (mm)	d2 (mm)	SPQ (set)	Weight (g/set)
284-8066	TDF-130T	¥2,138	¥2,310	76.5	20	6	6	137	31	25.2	6.5	20	155
284-8074	TDF-160T	¥2,240	¥2,420	76.5	20	6	6	167	31	25.2	6.5	20	164

Contact us:0120-509-849 <http://www.orange-book.com/>

 
TRUSCO **Stock 38,650 Items**

Round Bar Slide Bolt Latch (for welding)

Com **eco** Chemical Content Inspection **Com** Drawing

TKY-450S

Features •The hole diameter of the catch has been made larger, and it corresponds to the gap after installation.
 •The handle part is subjected to anti-slip processing.
 Use •Steel gate door/steel joinery.
 Materials •Stainless Steel (SUS304) Origin •Japan



Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	A (mm)	B (mm)	C (mm)	SPQ (piece)	Weight (kg)
300-1733	TKY-300S	¥7,831	¥8,460	75	300	16	20	0.76
300-1741	TKY-450S	¥9,850	¥10,640	75	450	16	20	0.95
300-1750	TKY-600S	¥11,071	¥11,960	75	600	16	10	1.15

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

Round Bar Slide Bolt Latch (for wooden door)

Com **eco** Chemical Content Inspection **Com** Drawing

TKB-300S

Features •Made of stainless steel and excellent in corrosion resistance or heat resistance.
 •The hole diameter of the catch has been made larger, and it corresponds to the gap after installation.
 •The handle part is subjected to anti-slip processing.
 Use •Wooden gate door/wooden fittings.
 Materials •Stainless Steel (SUS304)
 Accessories •Wood screw stainless steel M4 x 35 tapping: 17 pieces
 Origin •Japan

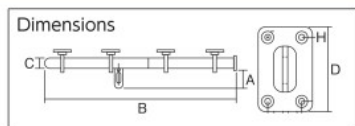

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	A (mm)	B (mm)	C (mm)	D (mm)	H (mm)	SPQ (piece)	Weight (kg)
300-1709	TKB-300S	¥7,998	¥8,640	75	300	16	57	4.8	20	0.95
300-1717	TKB-450S	¥9,961	¥10,760	75	450	16	57	4.8	20	1.05
300-1725	TKB-600S	¥11,358	¥12,270	75	600	16	57	4.8	10	1.25

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

Super Strong Round Bar Slide Bolt Latch

Com **eco** Chemical Content Inspection **Com** Drawing

TKN-650S

Features •Optimum for areas requiring greater strength such as large doors.
 •The hole diameter of the catch has been made larger than the existing items, and it corresponded to the gap after installation.
 •The handle part is subjected to anti-slip processing.
 Use •Large steel gate door/steel joinery.
 Materials •Stainless Steel (SUS304)
 Accessories •Stainless Steel M5 x 40 Tapping 20 Pieces Origin •Japan

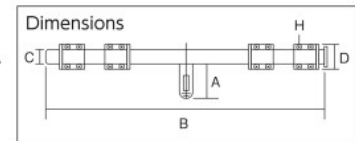

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	A (mm)	B (mm)	C (mm)	D (mm)	H (mm)	SPQ (piece)	Weight (kg)
300-1806	TKN-650S	¥21,226	¥22,930	120	650	19	50	5.2	5	2.3
300-1814	TKN-900S	¥46,711	¥50,460	120	900	19	50	5.2	3	2.9
300-1822	TKN-1200S	¥83,351	¥90,040	120	1200	22	50	5.2	3	4.6

Contact us:0120-509-849 <http://www.orange-book.com/>