


Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

Rope Stopper J Type

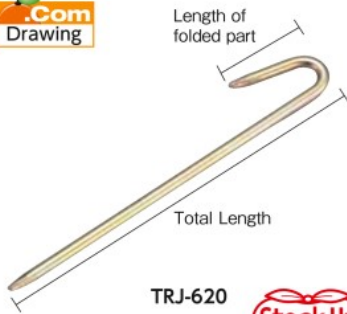

TRJ-620



Estimated Unit Price per Piece
¥77 to ¥90

- Features**
- The pull-out strength has been improved with a variant type (J type head).
 - It is used for pulling and fixing ropes, etc. to the ground.
 - Various tents, tarp setting, gardening, compartment rope installation, and the like.
- Materials**
- Steel
 - Surface Treatment: Chromate
 - Origin •China

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Length of Folded Part (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
275-3766	TRJ-615	¥93	¥100	6	47	150	100	45
275-3774	TRJ-620	¥93	¥100	6	47	200	100	55
275-3782	TRJ-624	¥102	¥110	6	47	240	100	65

In a box (30 pieces)

Order Unit: 1 Box

(Price revision date: Jan, 2016)

Order Code	Item No.	Price (per box)	MSRP (per box)	Diameter (mm)	Length of Folded Part (mm)	Total Length (mm)	Q'ty Per Box (piece)	SPQ (box)	Weight (kg/box)
380-3511	TRJ-615-30P	¥2,296	¥2,480	6	47	150	30	10	1.35
380-3520	TRJ-620-30P	¥2,407	¥2,600	6	47	200	30	10	1.65
380-3538	TRJ-624-30P	¥2,694	¥2,910	6	47	240	30	10	1.95

In a box (100 pieces)

Order Unit: 1 Box



Estimated Unit Price per Piece
¥63 to ¥76

Order Code	Item No.	Price (per box)	MSRP (per box)	Diameter (mm)	Length of Folded Part (mm)	Total Length (mm)	Q'ty Per Box (piece)	SPQ (box)	Weight (kg/box)
470-3022	TRJ-615-100P	¥6,295	¥6,800	6	47	150	100	1	4.5
470-3031	TRJ-620-100P	¥6,758	¥7,300	6	47	200	100	1	5.5
470-3049	TRJ-624-100P	¥7,591	¥8,200	6	47	240	100	1	6.5

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Rope Stopper J Type



TRJ-S625

- Features**
- It is made of stainless steel and resistant to rust.
 - It is used for pulling and fixing ropes, etc. to the ground.
 - Various tents, tarp setting, gardening, compartment rope installation, and the like.
- Materials**
- Stainless Steel (SUS304)
 - Origin •Japan

Example



Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Length of Folded Part (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
275-3863	TRJ-S615	¥648	¥700	6	35	150	100	45
275-3871	TRJ-S620	¥666	¥720	6	35	200	100	50
275-3880	TRJ-S625	¥676	¥730	6	35	250	100	68

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Heteromorphic Rope Stopper J Type



TRJ-Y1020I

- Features**
- The pull-out strength has been improved with a variant type (J type head).
 - Optimum for pulling ropes and wires, etc. to the ground.
 - Also for installing intrusion prevention rope.
- Materials**
- Steel
 - Surface Treatment: Unichrome
 - Origin •China

Example



Order Unit: 1 Piece


(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Length of Folded Part (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
275-3600	TRJ-Y1020I	¥306	¥330	10	50 to 60	200	120	150
275-3618	TRJ-Y1030I	¥352	¥380	10	50 to 60	300	100	210
275-3626	TRJ-Y1060I	¥537	¥580	10	50 to 60	600	50	400

Contact us:0120-509-849 <http://www.orange-book.com/>

YUTAKA **Stock 1,604 Items**

Hammering Stick Hook Type

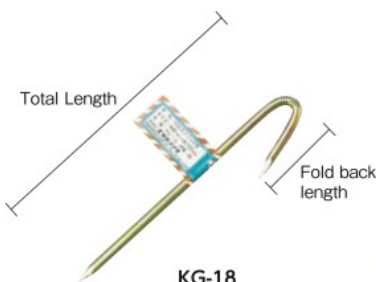

KG-18

- Features**
- A bracket that is hammered when fixing a rope, a net, etc., to the ground, etc.
 - Fixing a rope, a net, etc., to the ground.
- Materials**
- Steel
 - Surface Treatment: Plated Finishing
 - Origin •Japan

Order Unit: 1 Piece

YUTAKA MAKE Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Fold back length (mm)	Total Length (mm)	Type	SPQ (piece)	Weight (g)
794-6058	KG-18	¥104	-	6	48	150	Hook type	100	36
794-6066	KG-20	¥104	-	6	48	230	Hook type	100	52
794-6074	KG-21	¥109	-	6	48	280	Hook type	100	62
794-6082	KG-26	¥309	-	10	51	300	Hook type	50	182

Contact us:072-441-2220 <http://www.yutakamake.co.jp/>