

Suspension Brackets (bolt type)

Stock 223Items

2-975

Prices displayed include 8% tax.

TRUSCO
Stock 38,650 Items

Lifting Hook

RoHS

Com
Drawing



TTF-6

Features •Made of stainless steel and excellent in corrosion resistance.
Use •Set up on the wall, floor, pillar, etc., as a terminal metal fitting for the chain, wire, and rope.
Materials •Stainless Steel (SUS304) •Cut Anchor: Steel
Accessories •With cut anchor
Origin •China

Order Unit: 1 Set (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	D (mm)	B (mm)	W (mm)	S (mm)	Screw Diameter	Drill Diameter (mm)	Working Load (kN)	SPQ (set)	Weight (g/set)
380-4160	TTF-5	¥ 454	¥ 490	5.5	12	20	10	M6	11.0	0.18	20	33
380-4178	TTF-6	¥ 685	¥ 740	6.0	12	32	15	M6	11.0	0.20	20	53
380-4186	TTF-7	¥ 990	¥1,070	7.0	15	32	15	M8	12.5	0.49	20	78
380-4194	TTF-9	¥1,527	¥1,650	9.0	22	32	17	M10	14.5	1.18	20	150
380-4151	TTF-12	¥2,361	¥2,550	12.0	22	37	20	M12	18.0	1.96	10	256

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
Stock 38,650 Items

Bolt Hook

RoHS

Com
Drawing



TBF-6S

Features •Since it is attached with a detachment prevention, the thing hung is unlikely to come off accidentally.
Use •Set up on the wall, floor, pillar, etc., as a terminal metal fitting for the chain, wire, and rope.
Materials •Stainless Steel (SUS304) •Cut Anchor: Steel
Accessories •With cut anchor Origin •China

Order Unit: 1 Set (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	D (mm)	B (mm)	W (mm)	S (mm)	Screw Diameter	Drill Diameter (mm)	Working Load (kN)	SPQ (set)	Weight (g/set)
356-5572	TBF-5S	¥ 463	¥ 500	5.5	12	15	8.0	M6	11.0	0.18	20	33
356-5581	TBF-6S	¥ 703	¥ 760	6.0	12	19	8.5	M6	11.0	0.20	20	41
356-5599	TBF-8S	¥1,138	¥1,230	8.0	15	24	13.0	M8	12.5	0.59	20	74
356-5602	TBF-10S	¥1,695	¥1,830	10.0	18	32	16.0	M10	14.5	1.18	20	129

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
Stock 38,650 Items

"Petit Hook L Type"

RoHS

Com
Drawing



THL-8

Features •It is made of stainless steel and optimum around areas using water.
Use •For hanging items on outdoor water facilities (foot washing area, etc.).
Materials •Stainless Steel (SUS304) •Cut Anchor: Steel
Accessories •With cut anchor
Origin •China

Example



Order Unit: 1 Piece (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L (mm)	H (mm)	W (mm)	B (mm)	T (mm)	Screw Diameter	Drill Diameter (mm)	Working Load (kN)	SPQ (piece)	Weight (g)
409-9931	THL-6	¥454	¥490	6	20	30	25	10	2	M6	11.0	0.20	20	33
409-9940	THL-8	¥602	¥650	8	22	40	33	11	2	M8	12.5	0.49	20	57
409-9923	THL-10	¥768	¥830	10	22	50	40	13	2	M10	14.5	0.98	20	93

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
Stock 38,650 Items

Hang Hook

RoHS

Com
Drawing



TGH-12

Features •Since it is attached with a detachment prevention, the thing hung is unlikely to come off accidentally.
Use •Set up on the wall, floor, pillar, etc., as a terminal metal fitting for the chain, wire, and rope.
Materials •Stainless Steel (SUS304)
Origin •China

Example



Order Unit: 1 Piece (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	B (mm)	W (mm)	S (mm)	Screw Diameter	Working Load (kN)	SPQ (piece)	Weight (g)
409-9699	TGH-12	¥2,102	¥2,270	10.5	40	38	19.0	M12	1.47	10	135


Contact us:0120-509-849 <http://www.orange-book.com/>

MIZUMOTO MACHINE
Stock 529 Items

Net Hook

RoHS

Com
Drawing

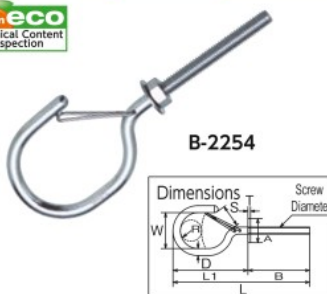

B-2254

Features •With hooks, it is difficult to remove items accidentally.
Use •For installation of a bird-proof net.
Materials •Stainless Steel (SUS304)
Accessories •Hexagon nut •Washer Origin •China

Order Unit: 1 Piece (Price revision date: Jan, 2016) MIZUMOTO MACHINE MFG.Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L (mm)	L1 (mm)	B (mm)	W (mm)	S (mm)	R (mm)	A (mm)	T (mm)	Screw Diameter	Working Load (kN)	SPQ (piece)	Weight (g)
378-9713	B-2254	¥ 536	¥ 630	4.0	75	37	38	19	12	5.0	8	1	M4	0.05	20	10
378-9721	B-2255	¥ 662	¥ 780	4.3	91	50	41	24	15	7.5	12	1	M5	0.07	20	18
378-9730	B-2256	¥ 858	¥1,010	5.2	115	63	52	30	18	9.0	20	2	M6	0.12	20	35
378-9748	B-2257	¥1,333	¥1,570	7.0	155	88	67	40	25	12.5	22	2	M8	0.20	15	77

Contact us:079-246-2501 <http://www.mizumoto-mm.co.jp/>

Hardware

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers

2-975