

Suspension Brackets (bolt type/screw-in type)


The number next to the logo mark indicates items in stock for each brand.

Hardware



Stock 529 Items

Bolt Hook

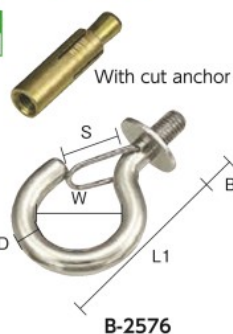

Use • Set up on the wall, floor, pillar, etc., as a terminal metal fitting for the chain, wire, and rope.
 Materials • **Main Body: Stainless Steel (SUS304)** • **Cut Anchor: Steel**
 Accessories • With cut anchor
 Origin • China

Order Unit: 1 Piece

MIZUMOTO MACHINE MFG.Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L1 (mm)	B (mm)	W (mm)	S (mm)	Screw Diameter	Drill Diameter (mm)	Working Load (kN)	SPQ (piece)	Weight (g)
833-7831	B-2576	¥ 501	¥ 590	5.5	33	12	15	8.0	W-1/4	11.0	0.18	20	33
833-7832	B-2577	¥ 746	¥ 880	6.0	40	12	19	8.5	W-1/4	11.0	0.20	20	41
833-7833	B-2578	¥1,198	¥1,410	8.0	50	15	24	13.0	W-5/16	12.5	0.59	20	74
833-7834	B-2579	¥1,782	¥2,100	10.0	62	18	32	16.0	W-3/8	14.5	1.18	20	129

Contact us:079-246-2501 <http://www.mizumoto-mm.co.jp/>

Door Closers

Door Stoppers



Stock 38,650 Items

Lamp Sling



Use • Screw into the wooden backing and used it as a hanging and fixing metal fittings.
 Materials • **Stainless Steel (SUS304)**
 Origin • Japan



Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm)		Inlet Size (mm)	Wire Diameter (mm)	Load Capacity (kg)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
				S	D						
275-7028	TYT-S16	¥361	¥390	9.5	16	5.0	2.2	1.2	17	10	22
275-7036	TYT-S20	¥361	¥390	11.0	20	8.5	2.4	1.8	15	10	28
275-7044	TYT-S22	¥361	¥390	11.0	22	9.0	2.4	1.8	14	10	29
275-7052	TYT-S25	¥361	¥390	14.0	25	9.5	2.8	3.0	10	10	34
275-7061	TYT-S28	¥361	¥390	16.0	28	11.0	3.1	3.5	8	10	34
275-7079	TYT-S32	¥361	¥390	17.0	32	13.5	3.5	4.5	7	10	34
275-7087	TYT-S35	¥361	¥390	18.0	35	15.0	3.8	5.0	4	10	34
275-7095	TYT-S38	¥361	¥390	18.0	38	16.0	3.8	5.0	4	10	34
275-7109	TYT-S45	¥361	¥390	21.0	45	21.0	4.2	5.0	2	10	30
275-7117	TYT-S50	¥361	¥390	23.0	50	22.0	4.8	5.0	2	10	34

Contact us:0120-509-849 <http://www.orange-book.com/>

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes



Stock 38,650 Items

Screw Hook



Use • Screw into the wooden backing wall and used it as a hanging and fixing brackets.
 Materials • **Stainless Steel (SUS304)**
 Origin • Japan



Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm)			Wire Diameter (mm)	Load Capacity (kg)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
				S	D	A					
275-7125	TYK-S16	¥361	¥390	9.5	16	10.5	2.20	1.2	17	10	21
275-7133	TYK-S20	¥361	¥390	11.0	20	12.5	2.40	1.8	15	10	23
275-7141	TYK-S22	¥361	¥390	11.0	22	14.0	2.40	1.8	14	10	27
275-7150	TYK-S25	¥361	¥390	14.0	25	14.5	2.80	3.0	11	10	29
275-7168	TYK-S28	¥361	¥390	16.0	28	15.5	3.10	3.5	9	10	34
275-7176	TYK-S32	¥361	¥390	17.0	32	20.0	3.45	4.0	7	10	34
275-7184	TYK-S35	¥361	¥390	18.0	35	21.0	3.90	4.5	5	10	34
275-7192	TYK-S38	¥361	¥390	18.0	38	22.5	3.90	4.5	5	10	34
275-7206	TYK-S45	¥361	¥390	22.0	45	25.0	4.20	5.0	3	10	34
275-7214	TYK-S50	¥361	¥390	25.0	50	28.0	4.80	5.0	2	10	30

Contact us:0120-509-849 <http://www.orange-book.com/>

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires


Wire Nets

Inspection Doors, Air Inlet/Outlets



Stock 38,650 Items

Heaton

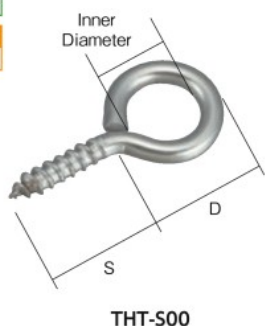

Use • Screw into the wooden backing wall and used it as a hanging and fixing brackets.
 Materials • **Stainless Steel (SUS304)**
 Origin • Japan



Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Nominal Dimension	Dimension (mm)		Wire Diameter (mm)	Inner Diameter (mm)	Load Capacity (kg)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
					S	D						
275-6927	THT-S00	¥361	¥390	00	7.8	7.2	1.6	4.0	0.3	22	10	20
275-6935	THT-S0	¥361	¥390	0	11.5	9.0	1.8	5.6	0.8	20	10	20
275-6943	THT-S2	¥361	¥390	2	12.0	10.5	2.1	6.8	1.0	18	10	20
275-6951	THT-S4	¥361	¥390	4	13.0	12.0	2.4	7.2	1.5	17	10	24
275-6960	THT-S6	¥361	¥390	6	14.0	14.5	2.8	9.4	2.5	11	10	28
275-6978	THT-S8	¥361	¥390	8	18.0	16.0	3.3	9.4	4.0	9	10	34
275-6986	THT-S10	¥361	¥390	10	22.0	20.0	3.9	12.2	4.5	7	10	46
275-6994	THT-S12	¥361	¥390	12	24.5	23.0	4.4	13.2	5.0	3	10	46
275-7001	THT-S14	¥361	¥390	14	29.5	24.5	4.7	14.1	5.0	2	10	46
275-7010	THT-S16	¥361	¥390	16	37.5	27.5	5.5	16.0	5.5	2	10	50

Contact us:0120-509-849 <http://www.orange-book.com/>

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers