

# Corner Brackets

The number next to the logo mark indicates items in stock for each brand.

TRUSCO




Stock 38,650 Items

## Corner Bracket Round Type



- Features**
- Countersink on both sides is attached.
  - Can be used either inward or outward.
  - Please use the countersunk head screw.
- Use**
- As a reinforcing metal fitting for the corner.
  - To prevent furniture from falling.
  - To make shelf.
- Materials**
- Stainless Steel (SUS304)
  - Hairline finishing
- Origin**
- China

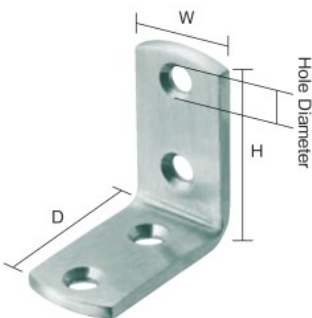

TKLR series



Round Type

Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	H (mm)	W (mm)	Board Thickness (mm)	Load capacity (2 pieces) (kg)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
328-8013	TKLR-1630	¥ 269	¥ 290	30	30	16	3	60	4.0	4	40	17
328-8021	TKLR-1635	¥ 296	¥ 320	35	35	16	3	60	4.0	4	40	20
328-8030	TKLR-1645	¥ 306	¥ 330	45	45	16	3	50	4.5	4	30	27
328-8048	TKLR-1660	¥ 361	¥ 390	60	60	16	3	40	4.5	4	20	37
328-8056	TKLR-1675	¥ 583	¥ 630	75	75	16	5	40	5.0	4	10	75
409-9231	TKLR-1690	¥ 713	¥ 770	90	90	16	5	40	5.0	4	10	92
409-9206	TKLR-16105	¥ 806	¥ 870	105	105	16	5	40	5.0	4	10	109
409-9214	TKLR-16120	¥ 806	¥ 870	120	120	16	5	20	5.0	4	10	128
409-9222	TKLR-16150	¥1,065	¥1,150	150	150	16	5	20	5.0	6	10	158
328-8064	TKLR-2045	¥ 361	¥ 390	45	45	20	3	60	4.5	4	30	35
328-8072	TKLR-2060	¥ 426	¥ 460	60	60	20	3	50	4.5	4	20	49
328-8081	TKLR-2075	¥ 509	¥ 550	75	75	20	3	30	4.5	4	10	63
409-9265	TKLR-2090	¥ 620	¥ 670	90	90	20	3	30	4.5	6	10	76
409-9249	TKLR-20105	¥ 806	¥ 870	105	105	20	3	20	4.5	6	10	89
409-9257	TKLR-20120	¥ 879	¥ 950	120	120	20	3	20	4.5	6	10	103
328-8099	TKLR-2535	¥ 399	¥ 430	35	35	25	3	80	4.5	4	30	32
328-8102	TKLR-2545	¥ 407	¥ 440	45	45	25	3	70	4.5	4	30	46
333-8525	TKLR-2560	¥ 482	¥ 520	60	60	25	3	60	4.5	4	20	63
333-8533	TKLR-2575	¥ 555	¥ 600	75	75	25	3	40	4.5	4	10	80
409-9290	TKLR-2590	¥ 713	¥ 770	90	90	25	3	40	4.5	6	10	97
409-9273	TKLR-25105	¥ 842	¥ 910	105	105	25	3	30	4.5	6	10	114
409-9281	TKLR-25120	¥ 954	¥1,030	120	120	25	3	30	4.5	6	10	130
409-9320	TKLR-3035	¥ 490	¥ 530	35	35	30	3	90	4.5	4	30	38
409-9338	TKLR-3045	¥ 518	¥ 560	45	45	30	3	80	4.5	4	30	55
409-9346	TKLR-3060	¥ 620	¥ 670	60	60	30	3	70	4.5	4	20	76
409-9354	TKLR-3075	¥ 713	¥ 770	75	75	30	3	50	4.5	4	10	96
409-9362	TKLR-3090	¥ 814	¥ 880	90	90	30	3	50	4.5	6	10	117
409-9303	TKLR-30105	¥ 907	¥ 980	105	105	30	3	40	4.5	6	10	137
409-9311	TKLR-30120	¥1,037	¥1,120	120	120	30	3	40	4.5	6	10	160

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO




Stock 38,650 Items

## Corner Bracket Square Type



- Features**
- Countersink on both sides is attached.
  - Can be used either inward or outward.
  - Please use the countersunk head screw.
- Use**
- As a reinforcing metal fitting for the corner.
  - To prevent furniture from falling.
  - To make shelf.
- Materials**
- Stainless Steel (SUS304)
  - Hairline finishing
- Origin**
- China

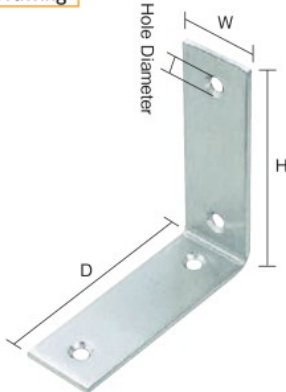

TKL series



Rectangular Type

Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	H (mm)	W (mm)	Board Thickness (mm)	Load capacity (2 pieces) (kg)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
409-9401	TKL-1630	¥ 269	¥ 290	30	30	16	3	60	4.0	4	40	18
409-9419	TKL-1635	¥ 296	¥ 320	35	35	16	3	60	4.0	4	40	21
409-9427	TKL-1645	¥ 306	¥ 330	45	45	16	3	50	4.5	4	30	28
409-9435	TKL-1660	¥ 361	¥ 390	60	60	16	3	40	4.5	4	20	40
409-9443	TKL-1675	¥ 583	¥ 630	75	75	16	5	40	5.0	4	10	76
409-9451	TKL-1690	¥ 713	¥ 770	90	90	16	5	40	5.0	4	10	93
409-9371	TKL-16105	¥ 806	¥ 870	105	105	16	5	40	5.0	4	10	111
409-9389	TKL-16120	¥ 806	¥ 870	120	120	16	5	20	5.0	4	10	129
409-9397	TKL-16150	¥1,065	¥1,150	150	150	16	5	20	5.0	6	10	160
409-9486	TKL-2045	¥ 361	¥ 390	45	45	20	3	60	4.5	4	30	36
409-9494	TKL-2060	¥ 426	¥ 460	60	60	20	3	50	4.5	4	20	50
409-9508	TKL-2075	¥ 509	¥ 550	75	75	20	3	30	4.5	4	10	64
409-9524	TKL-2090	¥ 620	¥ 670	90	90	20	3	30	4.5	6	10	79
409-9460	TKL-20105	¥ 806	¥ 870	105	105	20	3	20	4.5	6	10	90
409-9478	TKL-20120	¥ 879	¥ 950	120	120	20	3	20	4.5	6	10	104
409-9541	TKL-2545	¥ 407	¥ 440	45	45	25	3	70	4.5	4	30	48
409-9559	TKL-2560	¥ 482	¥ 520	60	60	25	3	60	4.5	4	20	65
409-9567	TKL-2575	¥ 555	¥ 600	75	75	25	3	40	4.5	4	10	82
409-9575	TKL-2590	¥ 713	¥ 770	90	90	25	3	40	4.5	6	10	99
409-9516	TKL-25105	¥ 842	¥ 910	105	105	25	3	30	4.5	6	10	117
409-9532	TKL-25120	¥ 954	¥1,030	120	120	25	3	30	4.5	6	10	136
409-9605	TKL-3045	¥ 518	¥ 560	45	45	30	3	80	4.5	4	30	58
409-9613	TKL-3060	¥ 620	¥ 670	60	60	30	3	70	4.5	4	20	79
409-9621	TKL-3075	¥ 713	¥ 770	75	75	30	3	50	4.5	4	10	100
409-9630	TKL-3090	¥ 814	¥ 880	90	90	30	3	50	4.5	6	10	120
409-9583	TKL-30105	¥ 907	¥ 980	105	105	30	3	40	4.5	6	10	142
409-9591	TKL-30120	¥1,037	¥1,120	120	120	30	3	40	4.5	6	10	163

Contact us:0120-509-849 <http://www.orange-book.com/>