

# Corner Joints/Joint Brackets

The number next to the logo mark indicates items in stock for each brand.

Hardware

TRUSCO



Stock 38,650 Items


## Wide Shelving Bracket

Com Drawing



TUWT-75X150 TUWT-100X200

- Features**
- With the double-sided countersunk, it can be used either inward or outward. (Please use the countersunk head screw.)
  - Optimum for reinforcement of corner parts and connecting parts of the wood.
  - A staple item as reinforcing hardware.
- Use**
- For reinforcement, fall prevention, shelf board, and bracket etc.
- Materials**
- Steel
  - Surface Treatment: Unichrome Plated Finishing
- Origin**
- Japan

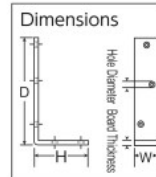

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	H (mm)	W (mm)	Board Thickness (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
381-8942	TUWT-75X150	¥454	¥490	150	75	32	4.5	5.3	5	30	230
381-8951	TUWT-100X200	¥573	¥620	200	100	32	4.5	5.5	5	30	314
381-8969	TUWT-125X250	¥703	¥760	250	125	32	4.5	5.9	7	20	394
381-8977	TUWT-150X300	¥879	¥950	300	150	32	4.5	5.9	7	20	495

Contact us:0120-509-849 <http://www.orange-book.com/>

Door Closers

Door Stoppers

Hinges


TRUSCO



Stock 38,650 Items

## "Joint Metal Fitting 15 Type L"

Com Drawing

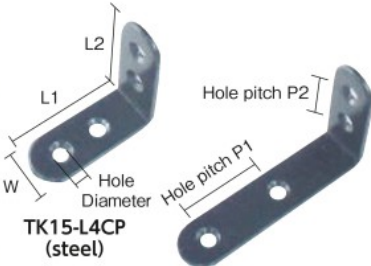

TK15-L4CP (steel)

TK15-L4ACP (steel)

- Features**
- Can be widely used as a connecting metal fitting for living goods, it is also a standard item as a carpentry work and reinforcing hardware.
- Use**
- Connecting metal fitting.
- Origin**
- Japan

Item No.	Hole pitch P1 (mm)	Hole pitch P2 (mm)
TK15-L4CP(S)	12.5	12.5
Others	25	25

Steel Materials •Steel

•Surface Treatment: Cathodic Electrodeposition Coating

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-1990	TK15-L4CP	¥176	¥190	2	15	36	36	4	4	20	14.1
497-2007	TK15-L4ACP	¥185	¥200	2	15	61	36	4	4	20	19.6
497-2015	TK15-L6ACP	¥213	¥230	2	15	111	36	4	6	20	30.4
497-2023	TK15-L8ACP	¥222	¥240	2	15	161	36	4	8	20	41.7

Stainless Steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-2031	TK15-L4S	¥204	¥220	2	15	36	36	4	4	20	13.2
497-2040	TK15-L4AS	¥222	¥240	2	15	61	36	4	4	20	18.6
497-2058	TK15-L6AS	¥259	¥280	2	15	111	36	4	6	20	28.8
497-2066	TK15-L8AS	¥296	¥320	2	15	161	36	4	8	20	39.0

Contact us:0120-509-849 <http://www.orange-book.com/>

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings


TRUSCO



Stock 38,650 Items

## "Joint Metal Fitting 15 Type Flat"

Com Drawing

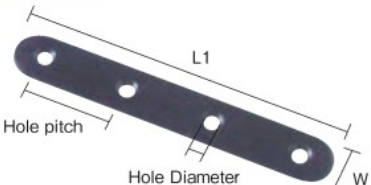

TK15-F4CP (steel)

- Features**
- A simple and versatile combination.
- Use**
- Connecting metal fitting.
- Specs**
- Hole Pitch: 25mm
- Origin**
- Japan

Steel Materials •Steel •Surface Treatment: Cathodic Electrodeposition Coating

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-1914	TK15-F4CP	¥166	¥180	2	15	94	4	4	20	19.8
497-1922	TK15-F6CP	¥194	¥210	2	15	144	4	6	20	30.8
497-1931	TK15-F8CP	¥204	¥220	2	15	194	4	8	20	41.6
497-1949	TK15-F12CP	¥231	¥250	2	15	294	4	12	20	63.5

Stainless Steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-1957	TK15-F4S	¥241	¥260	2	15	94	4	4	20	18.6
497-1965	TK15-F6S	¥287	¥310	2	15	144	4	6	20	28.8
497-1973	TK15-F8S	¥324	¥350	2	15	194	4	8	20	39.1
497-1981	TK15-F12S	¥361	¥390	2	15	294	4	12	20	59.5

Contact us:0120-509-849 <http://www.orange-book.com/>