


Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**


"Joint Metal Fitting 25 Type"

Com Drawing

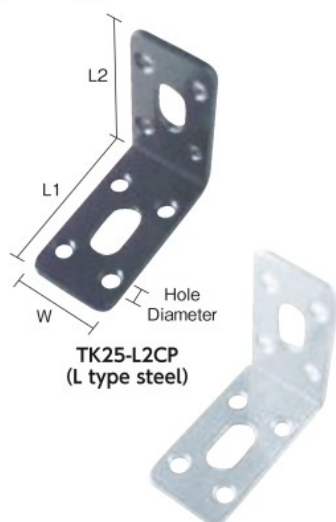

TK25-L2CP (L type steel)

TK25-L2S (L type stainless steel)

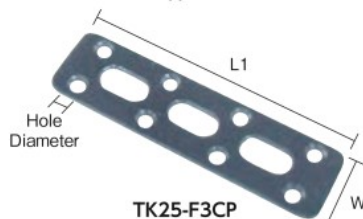

TK25-F3CP (flat type steel)



TK25-F3S (flat type stainless steel)

- Features**
- Easy and fine adjustment is possible even after temporarily attaching in advance when installing equipment.
 - Extensible adjustments are possible with a single screwdriver.
 - A simple and versatile combination.
- Use**
- Connecting metal fitting.
- Specs**
- Long Hole Diameter: 8 x 16mm
- Origin**
- Japan

L type steel Materials •Steel •Surface Treatment: Cathodic Electrodeposition Coating

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-2139	TK25-L2CP	¥231	¥250	3	25	49	49	8	10	20	43.6
497-2147	TK25-L3CP	¥249	¥270	3	25	74	49	8	13	20	54.3
497-2155	TK25-L4CP	¥269	¥290	3	25	74	74	8	16	20	64.6
497-2163	TK25-L6CP	¥296	¥320	3	25	124	74	8	24	10	85.7
497-2171	TK25-L10CP	¥342	¥370	3	25	199	99	8	34	10	127.0

L type stainless steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-2180	TK25-L2S	¥278	¥300	2	25	49	49	8	10	20	28.3
497-2198	TK25-L3S	¥306	¥330	2	25	74	49	8	13	20	35.3
497-2201	TK25-L4S	¥370	¥400	2	25	74	74	8	16	20	42.5
497-2210	TK25-L6S	¥518	¥560	3	25	124	74	8	24	10	84.9
497-2228	TK25-L10S	¥741	¥800	3	25	199	99	8	34	10	125.2

Flat type steel Materials •Steel •Surface Treatment: Cathodic Electrodeposition Coating

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-2074	TK25-F3CP	¥194	¥210	3	25	94	8	11	20	41
497-2082	TK25-F5CP	¥249	¥270	3	25	144	8	17	20	62
497-2091	TK25-F7CP	¥269	¥290	3	25	194	8	23	20	83

Flat type stainless steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-2104	TK25-F3S	¥287	¥310	2	25	94	8	11	20	26.8
497-2112	TK25-F5S	¥314	¥340	2	25	144	8	17	20	40.7
497-2121	TK25-F7S	¥361	¥390	2	25	194	8	23	20	54.8

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

"Joint Metal Fitting 43 Type Flat"

Com **eco** Chemical Content Inspection **Com** Drawing

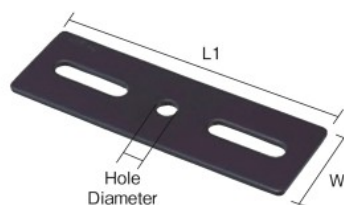

TK43-F2B (steel (black coating finishing))



TK43-F2S (stainless steel)

- Features**
- Easy and fine adjustment is possible even after temporarily attaching in advance when installing equipment.
 - Extensible adjustments are possible with a single screwdriver.
- Use**
- Connecting metal fitting.
 - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 8.5 x 35mm
- Origin**
- Japan

Steel Materials •Steel •Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1121	TK43-F2C	¥361	¥390	3.2	43	130	9	3	20	125

Steel (black coating finishing) Materials •Steel •Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0860	TK43-F2B	¥361	¥390	3.2	43	130	9	3	20	125

Stainless steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1252	TK43-F2S	¥731	¥790	3	43	130	9	3	20	113

Contact us: 0120-509-849 <http://www.orange-book.com/>