


TRUSCO **Stock 38,650 Items**


"Joint Metal Fitting 43 Type"

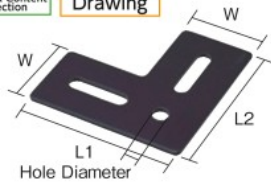

TK43-FL2B
(L type/flat)
(steel (black coating finishing))




TK43-FL2S
(L type/flat)
(stainless steel)

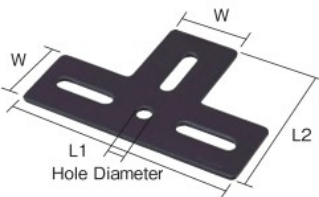

TK43-FT3B
(T type/flat)
(steel (black coating finishing))



TK43-FT3S
(T type/flat)
(stainless steel)

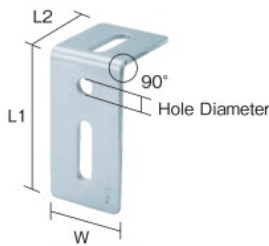

TK43-L2C
(L type)
(steel)



TK43-L2B
(L type)
(steel (black coating finishing))



TK43-L2S
(L type)
(stainless steel)

- Features**
- Easy and fine adjustment is possible even after temporarily attaching in advance when installing equipment.
 - Extensible adjustments are possible with a single screwdriver.
- Use**
- Connecting metal fitting.
 - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 8.5 x 35mm
- Origin**
- Japan

L type/flat steel Materials •Steel •Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1139	TK43-FL2C	¥435	¥470	3.2	43	90	90	9	3	20	133

L type/flat steel (black coating finishing) Materials •Steel •Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0878	TK43-FL2B	¥435	¥470	3.2	43	90	90	9	3	20	133

L type/flat stainless steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1261	TK43-FL2S	¥861	¥930	3	43	90	90	9	3	20	119

T type/flat steel Materials •Steel •Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1147	TK43-FT3C	¥555	¥600	3.2	43	130	93	9	4	20	172

T type/flat steel (black coating finishing) Materials •Steel •Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0886	TK43-FT3B	¥555	¥600	3.2	43	130	93	9	4	20	172

T type/flat stainless steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1279	TK43-FT3S	¥1,250	¥1,350	3	43	130	93	9	4	20	153

L type steel Materials •Steel •Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1619	TK43-L2C	¥435	¥470	3.2	43	88	52	9	3	20	116

L type steel (black coating finishing) Materials •Steel •Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0894	TK43-L2B	¥435	¥470	3.2	43	88	52	9	3	20	129

L type stainless steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1775	TK43-L2S	¥750	¥810	3	43	88	52	9	3	20	129

Contact us: 0120-509-849 <http://www.orange-book.com/>