

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

## "Joint Metal Fitting 45 Type L"



- Features**
- Can be widely used as a connecting metal fitting for living goods, it is also a standard item as a carpentry work and reinforcing hardware.
- Use**
- Connecting metal fitting.
- Specs**
- Long Hole Diameter 8 x 15mm
- Origin**
- Japan



### Steel

Materials •Steel •Surface Treatment: Cathodic Electrodeposition Coating

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-2236	TK45-L2CP	¥185	¥200	2	45	23	23	4	6	20	25.2
497-2244	TK45-L2ACP	¥213	¥230	2	45	37	37	4	10	20	43.8
497-2252	TK45-L3CP	¥249	¥270	2	45	62	42	4	13	20	62.2



### Stainless Steel

Materials •Stainless Steel (SUS304)


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
497-2261	TK45-L2S	¥231	¥250	2	45	23	23	4	6	20	24.1
497-2279	TK45-L2AS	¥334	¥360	2	45	37	37	4	10	20	42.0
497-2287	TK45-L3S	¥435	¥470	2	45	62	42	4	13	20	59.5


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

## Unequal Side Angle

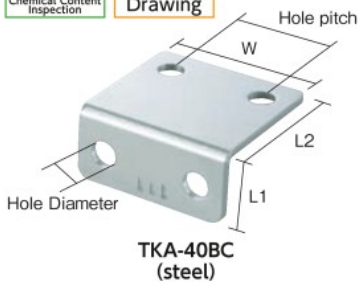

- Features**
- A material for simple and versatile mounting.
  - It is used for various usages such as a mount or supports for pipes, or others by combination.
- Use**
- Connecting metal fitting.
  - Car parts mounting metal fitting.
- Specs**
- Hole Pitch: 25mm
- Origin**
- Japan

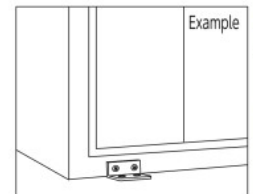

### Steel

Materials •Steel •Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1431	TKA-40BC	¥269	¥290	2	40	19	38	6.5	4	5	31
283-1449	TKA-90BC	¥379	¥410	2	90	19	38	6.5	8	5	71
283-1457	TKA-140BC	¥472	¥510	2	140	19	38	6.5	12	5	107

### Steel (black coating finishing)

Materials •Steel •Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0941	TKA-40BB	¥269	¥290	2	40	19	38	6.5	4	5	31
482-0967	TKA-90BB	¥379	¥410	2	90	19	38	6.5	8	5	71
482-0924	TKA-140BB	¥472	¥510	2	140	19	38	6.5	12	5	107



### Stainless Steel

Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1554	TKA-40BS	¥314	¥340	2	40	19	38	6.5	4	5	29
283-1562	TKA-90BS	¥500	¥540	2	90	19	38	6.5	8	5	67
287-9077	TKA-140BS	¥666	¥720	2	140	19	38	6.5	12	5	104



Contact us:0120-509-849 <http://www.orange-book.com/>