


Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

## "Joint Metal Fitting 76 Type"

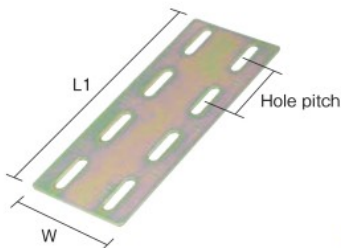

TK76-F4CM

- Features**
- It is used for various usages such as a mount or supports for pipes, or others by combination.
  - A simple and versatile combination.
- Use**
- Connecting metal fitting.
  - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 7 x 30mm
  - Hole pitch: 50mm
- Materials**
- **Steel**
  - **Surface treatment: Chromate plating finishing**
- Origin**
- Japan

Order Unit: 1 Piece


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Number	SPQ (piece)	Weight (g)
283-0817	TK76-F2CM	¥231	¥250	2	76	95	4	10	97
283-0825	TK76-F4CM	¥389	¥420	2	76	195	8	10	191
283-0833	TK76-F6CM	¥546	¥590	2	76	295	12	10	308

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

## "Joint Metal Fitting 33 Type L"

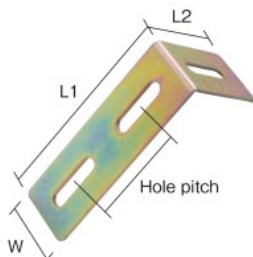

TK33-L3CM

- Features**
- It is used for various usages such as a mount or supports for pipes, or others by combination.
  - A simple and versatile combination.
- Use**
- Connecting metal fitting.
  - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 7 x 30mm
  - Hole pitch: 50mm
- Materials**
- **Steel**
  - **Surface treatment: Chromate plating finishing**
- Origin**
- Japan

Order Unit: 1 Piece


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1104	TK33-L3CM	¥249	¥270	2	33	101	51	3	10	67
283-1112	TK33-L4CM	¥249	¥270	2	33	151	51	4	10	89

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

## "Joint Metal Fitting 40 Type L"

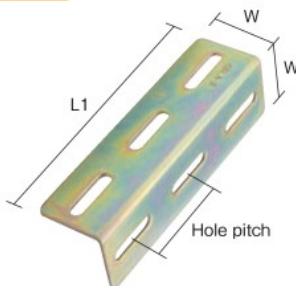

TK40-L3CM

- Features**
- It is used for various usages such as a mount or supports for pipes, or others by combination.
  - A simple and versatile combination.
- Use**
- Connecting metal fitting.
  - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 7 x 30mm
  - Hole pitch: 50mm
- Materials**
- **Steel**
  - **Surface treatment: Chromate plating finishing**
- Origin**
- Japan

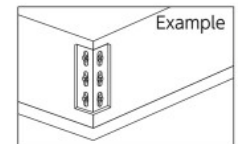

Order Unit: 1 Piece


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1783	TK40-L2CM	¥259	¥280	2	40	95	4	10	95
283-1791	TK40-L3CM	¥379	¥410	2	40	145	6	10	149

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

## "Joint Metal Fitting 76 Type L"

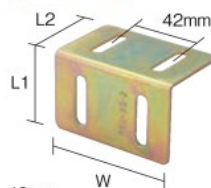

TK76-L2CM


- Features**
- It is used for various usages such as a mount or supports for pipes, or others by combination.
  - A simple and versatile combination.
- Use**
- Connecting metal fitting.
  - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 7 x 30mm
  - Hole pitch: 50mm
- Materials**
- **Steel**
  - **Surface treatment: Chromate plating finishing**
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1805	TK76-L2CM	¥278	¥300	2	76	50	50	4	10	99
283-1813	TK76-L4CM	¥444	¥480	2	76	100	100	8	10	204

Contact us:0120-509-849 <http://www.orange-book.com/>

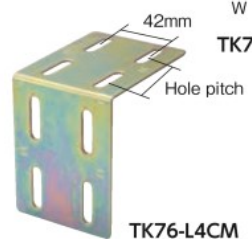

TK76-L4CM

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers