



Stock 38,650 Items

Urethane Coil Hose



UCH-3NG (neo gray)

- Features**
- Hard to be folded and it has excellent wear resistance.
 - Excellent in flexibility, elasticity, retractility. Moreover, it is tough.
 - Since the hand part is straight, hand hose is not necessary.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C
 - Working Pressure: 0.8MPa
 - Hose Inner Diameter x Outer Diameter: 5 x 8mm
 - Coupling Joint: With R1/4 external Thread, G1/4 external Thread, G1/4 Universal external Thread
- Materials**
- Polyurethane
- Origin**
- Japan

Color: Neo Gray

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
214-7351	UCH-3NG	¥2,481	¥2,680	42	Neo Gray	2.4	780	180	10	190
214-4072	UCH-5NG	¥2,944	¥3,180	42	Neo Gray	4.0	1000	400	10	280
214-7360	UCH-7NG	¥4,018	¥4,340	42	Neo Gray	5.6	1200	600	10	370

Color: Orange


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
104-2262	UCH-3	¥2,481	¥2,680	42	Orange	2.4	780	180	10	190
104-2271	UCH-5	¥2,944	¥3,180	42	Orange	4.0	1000	400	10	280
104-2289	UCH-7	¥4,018	¥4,340	42	Orange	5.6	1200	600	10	370

Contact us:0120-509-849 <http://www.orange-book.com/>

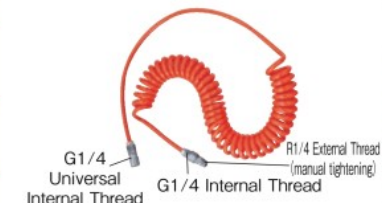


UCH-3 (orange)

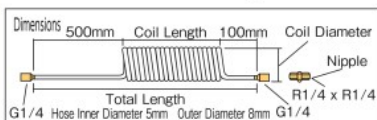

Stock 38,650 Items

α Urethane Coil Hose (with coupling)

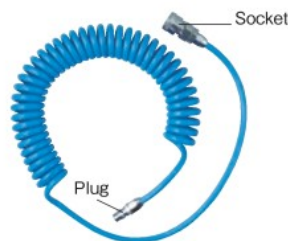

TUCH-3B


- Features**
- Since the highly elastic polyurethane plastic is a spiral processed tube, it has excellent mechanical spring characteristics which is hard to fold.
 - Smooth detachment from the air tool because it is attached with coupling.
 - Excellent in wear resistance and durability.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C (to be freeze free)
 - Working Pressure: 0.8MPa
 - Hose Inner Diameter x Outer Diameter: 5 x 8mm
 - With coupling plug
- Materials**
- Polyurethane
- Origin**
- China

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
336-2787	TUCH-3B	¥2,268	¥2,450	42	Blue	2.0	780	180	10	240
336-2795	TUCH-5B	¥2,546	¥2,750	42	Blue	4.0	1000	400	10	330
336-2809	TUCH-7B	¥2,870	¥3,100	42	Blue	6.0	1200	600	10	420
336-2817	TUCH-10B	¥3,147	¥3,400	42	Blue	8.0	1400	800	10	600

 Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Urethane Coil Hose (with resin coupling)



TUHJ-3


- Features**
- Scratches are not caused by resin coupling even when tools/equipment comes into contact.
 - Hard to be folded and it has excellent wear resistance.
 - Excellent in flexibility, elasticity, retractility. Moreover, it is tough.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C (to be freeze free)
 - Working Pressure: 0.8MPa
 - Connecting Joint: 1/4 Resin Coupling
 - Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Materials**
- Polyurethane
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
258-5171	TUHJ-3	¥2,740	¥2,960	42	Orange	2.4	780	180	10	230
258-5189	TUHJ-5	¥3,055	¥3,300	42	Orange	4.0	1000	400	10	320
258-5197	TUHJ-7	¥3,703	¥4,000	42	Orange	5.6	1200	600	10	410

Contact us:0120-509-849 <http://www.orange-book.com/>

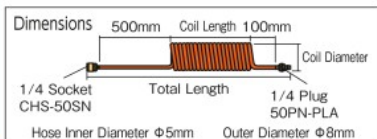

Description of the coupling in the pressurized state leads to serious accident.