

The number next to the logo mark indicates items in stock for each brand.

Connector Terminals

Clips, Test Reads

Modular Jacks

LAN Cables

Wires and Cables

Plugs Outlets

Switches

Cabling Systems

Cable Covers

Cable Ties

Installation Tools

Cable Mounts

Shrink Tubes

Cable Protecting Supplies

Switchboard Cabinets

Card Holders, Nameplates

Cable Labeling Supplies

Explosion Proof Fittings

TRUSCO
Stock **38,650** Items

Cable Clip



Features •Fix the wiring on the wall, etc. with screws.
Specs •For indoor Materials •Nylon 66 Origin •Taiwan

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	A (mm)	B (mm)	C (mm)	d (mm)	E (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
415-0589	TCC0	¥ 361	¥ 390	White	3.10	9.60	8.0	4.8	2.4	100	10	40
415-0597	TCC0.5	¥ 407	¥ 440	White	5.00	9.60	9.2	4.8	2.4	100	10	47
415-0601	TCC1	¥ 638	¥ 690	White	6.35	10.00	10.0	4.6	2.8	100	10	50
415-0619	TCC1.5	¥ 638	¥ 690	White	7.90	10.00	12.0	4.6	3.0	100	10	60
415-0627	TCC2	¥ 666	¥ 720	White	9.50	12.00	12.5	4.6	3.0	100	10	104
415-0635	TCC3	¥ 694	¥ 750	White	12.70	12.00	15.2	5.0	3.0	100	10	125
415-0643	TCC4	¥ 972	¥ 1,050	White	15.80	12.00	18.2	4.6	3.0	100	10	169
415-0651	TCC5	¥ 1,018	¥ 1,100	White	19.40	11.78	18.2	4.6	3.0	100	10	179
415-0660	TCC6	¥ 1,324	¥ 1,430	White	25.40	12.00	22.0	4.6	3.6	100	45	211
415-0678	TCC6.5	¥ 1,620	¥ 1,750	White	27.50	12.00	24.0	4.6	3.6	100	30	316
415-0686	TCC7	¥ 1,833	¥ 1,980	White	31.80	12.00	26.2	4.6	3.6	100	30	334
415-0694	TCC9	¥ 2,037	¥ 2,200	White	36.70	12.00	30.0	4.6	3.6	100	25	380

TRUSCO NAKAYAMA CORPORATION

Contact us:0120-509-849 <http://www.orange-book.com/>

PANDUIT
Stock **1,843** Items

Metal Clip



Features •Optimum for edges of panels and places where holes cannot be made for screwing for waterproof purpose.
•Pinching the edge of a panel with the mount, a bundle wire can be fixed with a cable tie.
•A cable tie can be inserted from four directions.
Use •For fixing cable ties and bundle wires.
Specs •For indoor, outdoor
•Fixing method: Clip
Materials •Zinc plated steel
Origin •USA

Item No.	Height (mm)	Vertical (mm)	Horizontal (mm)	Panel thickness (mm)
MCMS12-P-C	7.9	22.4	14.2	0.8 to 3.2
MCMS25-P-C	11.6	22.4	14.2	3.2 to 6.1
MCMS30-P-C	14.0	22.4	14.2	5.6 to 6.9


Order Unit: 1 Bag (Price revision date: Aug. 2015) Panduit Corp. Japan Branch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Working Cable Tie Width (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
477-4604	MCMS12-P-C	¥ 7,066	-	Silver	2.3 to 4.8	100	326
477-4612	MCMS25-P-C	¥ 10,599	-	Silver	2.3 to 4.8	100	326
477-4621	MCMS30-P-C	¥ 11,772	-	Silver	2.3 to 4.8	100	394

Contact us:03-6863-6060 <http://www.panduit.co.jp/>

PANDUIT
Stock **1,843** Items

Metal Clip for Solar

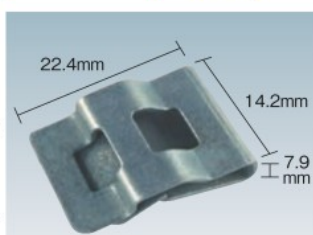

Features •When binding/fixing wires to the frame of a solar power generation panel, it is excellent in usability and can fix them firmly.
•Its high weather resistance, rust prevention and chemical resistance lead to long-standing durability.
•Can also correspond to temporary fastening.
•Can be fixed in both longitudinal and lateral directions.
Use •For binding/fixing wires to the frame of a solar power generation panel.
Specs •For outdoor
Materials •Zinc plated steel
Origin •USA

Warning
•Please use with weather resistant nylon 12 cable ties.

Item No.	Height (mm)	Vertical (mm)	Horizontal (mm)	Panel thickness (mm)
MCMS12-PJ-C	7.9	14.2	22.4	0.8 to 3.2


Order Unit: 1 Bag Panduit Corp. Japan Branch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Working Cable Tie Width (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
498-6296	MCMS12-PJ-C	¥ 7,467	-	Silver	2.3 to 4.8	100	305

Contact us:03-6863-6060 <http://www.panduit.co.jp/>

PANDUIT
Stock **1,843** Items

Connector Ring Mount (closed type)

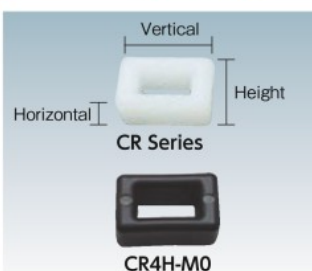

Features •Optimum when fixing bundle wires while connecting them, or when fixing them while hanging them from an overhead line.
Use •Used for connected fixing of bundle wires and when hanging them from an overhead line.
Specs •Working Temperature Range: -60 to 85°C
Origin •USA

Item No.	Comments	Height (mm)	Vertical (mm)	Horizontal (mm)	Materials
CR2-M	Indoor Use	5.1	8.4	6.1	Nylon 66
CR4H-M	Indoor Use	7.6	14.5	9.1	Nylon 66
CR4H-MO	Outdoor Use	7.6	14.5	9.1	Weather resistant nylon 66

Order Unit: 1 Bag (Price revision date: Aug. 2015) Panduit Corp. Japan Branch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Working Cable Tie Width (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
477-4469	CR2-M	¥ 25,889	-	Natural	2.3 to 4.8	1000	205
477-4477	CR4H-M	¥ 31,073	-	Natural	2.3 to 7.6	1000	700

Weather resistant type


Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Working Cable Tie Width (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
731-0706	CR4H-MO	¥ 34,174	-	Black	2.3 to 7.6	1000	755

Contact us:03-6863-6060 <http://www.panduit.co.jp/>

PANDUIT
Stock **1,843** Items

Connector Ring Mount (open type)

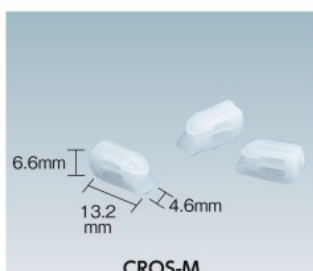

Features •Used when adding bundle wires without replacing cable ties of bundle wires.
Use •Used when adding bundle wires.
Specs •For indoor
•Working Temperature Range: -40 to 85°C
Materials •Nylon 66
Origin •USA

Item No.	Height (mm)	Vertical (mm)	Horizontal (mm)
CROS-M	4.6	6.6	13.2

Order Unit: 1 Bag (Price revision date: Aug. 2015) Panduit Corp. Japan Branch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Working Cable Tie Width (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
477-4485	CROS-M	¥ 23,313	-	Natural	2.3 to 4.8	1000	158

Contact us:03-6863-6060 <http://www.panduit.co.jp/>

