

The number next to the logo mark indicates items in stock for each brand.

TRUSCO  
Stock 38,650 Items

## Wiring Stopper



**Features** • Adhesive type wiring stopper that can be used in every field.  
 • Can be used for a wide variety of materials including steel, glass, aluminum and plastic.  
**Use** • Adhering to a flat surface, holds and fixes the wire, LAN cable etc. with the nail.  
**Specs** • For indoor  
**Origin** • Japan

**Steel Type** Materials • Main Body: Iron (SPCC)/Trivalent Chromate  
 Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	L x W (mm)	Claw Length (mm)	Tape	Q'ty Per Bag (piece)	Weight (g/bag)
497-4468	TWS-20-SI	¥241	¥260	10 x 20	17	3M#4032	10	11
497-4450	TWS-20-BK	¥269	¥290	10 x 20	17	Sekisui #518TF	10	11
497-4484	TWS-25-SI	¥287	¥310	15 x 25	26	3M#4032	10	21
497-4476	TWS-25-BK	¥314	¥340	15 x 25	26	Sekisui #518TF	10	21
497-4506	TWS-30-SI	¥490	¥530	19 x 30	39	Sekisui #535	10	40
497-4492	TWS-30-BK	¥555	¥600	19 x 30	39	Sekisui #518TF	10	40
497-4565	TWSW-30-SI	¥407	¥440	15 x 30	18 x 3 pieces	3M#4032	10	30

**Coated Type** Materials • Main body: Iron (SPCC)/Trivalent chromate/Insulating coating  
 Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	L x W (mm)	Claw Length (mm)	Tape	Q'ty Per Bag (piece)	Weight (g/bag)
497-4514	TWSC-20-BK	¥407	¥440	10 x 20	17	Sekisui #518TF	10	14
497-4522	TWSC-25-BK	¥463	¥500	15 x 25	26	Sekisui #518TF	10	27
497-4531	TWSC-30-BK	¥528	¥570	15 x 30	18 x 3 pieces	Sekisui #518TF	10	37


Contact us: 0120-509-849 <http://www.orange-book.com/>

**Stainless Steel Type** Materials • Main Body: Stainless Steel (SUS304)  
 Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	L x W (mm)	Claw Length (mm)	Tape	Q'ty Per Bag (piece)	Weight (g/bag)
497-4549	TWSS-20-SI	¥314	¥340	10 x 20	17	3M#4032	10	11
497-4557	TWSS-25-SI	¥407	¥440	15 x 25	26	3M#4032	10	21

PANDUIT  
Stock 1,843 Items

## Metal Cord Clip (with adhesive tape)

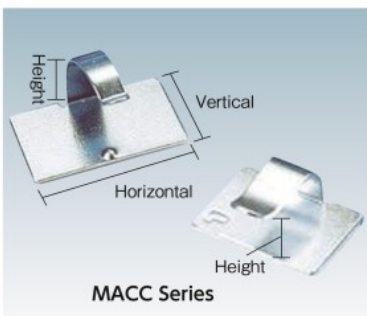

**Features** • Cables can be mounted and removed quickly.  
**Use** • For fixing cables.  
**Specs** • UL Standard Product • Color: Silver Materials • Zinc plated steel Origin • USA

### Standard type (rubber-based adhesive)

**Specs** • For indoor • Working Temperature Range: -29 to 49°C

Order Unit: 1 Bag (Price revision date: Aug, 2015) Panduit Corp. Japan Branch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Max Bundling Diameter (mm)	Vertical (mm)	Horizontal (mm)	Height (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
438-2536	MACC25-A-C	¥6,603	-	6.4	13.7	19.6	10.2	100	196
438-2552	MACC62-A-C	¥9,427	-	15.7	19.8	30.0	19.1	100	390

### Weather resistant/heat resistant type (VHB adhesive)

**Specs** • For indoor, outdoor • Working temperature range: -35 to 93°C

**Warning** • VHB is a trademark of 3M.


Order Unit: 1 Bag (Price revision date: Aug, 2015)

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Max Bundling Diameter (mm)	Vertical (mm)	Horizontal (mm)	Height (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
438-2544	MACC25-AV-D	¥28,250	-	6.4	13.7	19.6	10.2	500	1043
438-2561	MACC62-AV-C	¥11,309	-	15.7	19.8	30.0	19.1	100	177

Contact us: 03-6863-6060 <http://www.panduit.co.jp/>

PANDUIT  
Stock 1,843 Items

## Mount for Moving Part Wiring "Dynamic Cable Manager"

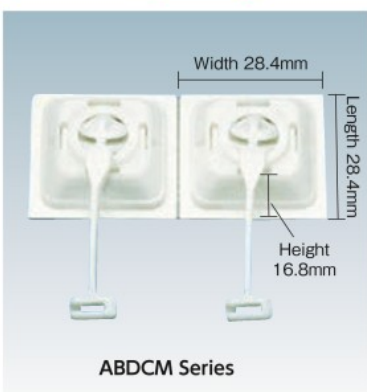

**Features** • Since the wiring and the mount can be separated, it is suitable for use at an opening/closing door part of a switchboard. • Since it has an adhesive tape, it can be installed easily.  
**Use** • For fixing of wiring at an opening/closing door part.  
**Materials** • Nylon 66 Origin • USA

**Standard type (rubber-based adhesive)** Specs • For indoor • Working Temperature Range: -29 to 49°C

Order Unit: 1 Bag (Price revision date: Aug, 2015) Panduit Corp. Japan Branch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Working Cable Tie Width (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
438-1793	ABDCM30-A-E	¥4,243	-	White	2.5-3.6-4.8	20	73
438-1785	ABDCM30-A-C	¥16,478	-	White	2.5-3.6-4.8	100	365

### Weather resistant/heat resistant type (VHB adhesive)

**Specs** • For indoor, outdoor • Working temperature range: -35 to 85°C

**Warning** • VHB is a trademark of 3M.

Order Unit: 1 Bag (Price revision date: Aug, 2015)

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Working Cable Tie Width (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
438-1807	ABDCM30-AV-C	¥17,203	-	White	2.5-3.6-4.8	100	365

Contact us: 03-6863-6060 <http://www.panduit.co.jp/>