

# Flap Wheels with Shaft (shaft diameter 6mm)

Stock 1,275 Items

5-1035

Prices displayed include 8% tax.






Stock 38,650 Items

## Flap Wheel (shaft diameter 6mm)



Use Origin • Working Tool: Micro grinder. (air/electric)  
• Japan

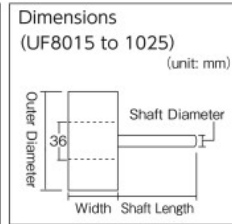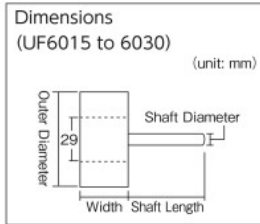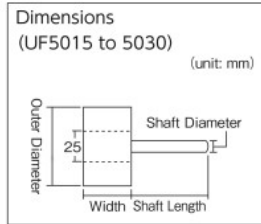

Estimated Unit Price per Piece  
¥496 to ¥920

### Outer Diameter 50mm Specs • Max Working Rotation Speed: 20000rpm

Order Unit: 1 Box										Order Unit: 1 Box									
Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)	Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
114-6921	UF5015	40	¥2,479	¥3,060	40	50 x 15 x 6 x 40	Approx. 62	5	265	114-7072	UF5025	150	¥2,617	¥3,230	150	50 x 25 x 6 x 40	Approx. 108	5	360
114-6939	UF5015	60	¥2,479	¥3,060	60	50 x 15 x 6 x 40	Approx. 85	5	265	114-7081	UF5025	180	¥2,617	¥3,230	180	50 x 25 x 6 x 40	Approx. 112	5	360
114-6947	UF5015	80	¥2,479	¥3,060	80	50 x 15 x 6 x 40	Approx. 95	5	265	114-7099	UF5025	240	¥2,617	¥3,230	240	50 x 25 x 6 x 40	Approx. 130	5	360
114-6955	UF5015	100	¥2,479	¥3,060	100	50 x 15 x 6 x 40	Approx. 102	5	265	114-7102	UF5025	320	¥2,617	¥3,230	320	50 x 25 x 6 x 40	Approx. 145	5	360
114-6963	UF5015	120	¥2,479	¥3,060	120	50 x 15 x 6 x 40	Approx. 108	5	265	114-7111	UF5025	400	¥2,617	¥3,230	400	50 x 25 x 6 x 40	Approx. 162	5	360
114-6971	UF5015	150	¥2,479	¥3,060	150	50 x 15 x 6 x 40	Approx. 108	5	265	114-7129	UF5030	40	¥2,786	¥3,440	40	50 x 30 x 6 x 40	Approx. 62	5	400
114-6980	UF5015	180	¥2,479	¥3,060	180	50 x 15 x 6 x 40	Approx. 112	5	265	114-7137	UF5030	60	¥2,786	¥3,440	60	50 x 30 x 6 x 40	Approx. 85	5	400
114-6998	UF5015	240	¥2,479	¥3,060	240	50 x 15 x 6 x 40	Approx. 130	5	265	114-7145	UF5030	80	¥2,786	¥3,440	80	50 x 30 x 6 x 40	Approx. 95	5	400
114-7005	UF5015	320	¥2,479	¥3,060	320	50 x 15 x 6 x 40	Approx. 145	5	265	114-7153	UF5030	100	¥2,786	¥3,440	100	50 x 30 x 6 x 40	Approx. 102	5	400
114-7013	UF5015	400	¥2,479	¥3,060	400	50 x 15 x 6 x 40	Approx. 162	5	265	114-7161	UF5030	120	¥2,786	¥3,440	120	50 x 30 x 6 x 40	Approx. 108	5	400
114-7021	UF5025	40	¥2,617	¥3,230	40	50 x 25 x 6 x 40	Approx. 62	5	360	114-7170	UF5030	150	¥2,786	¥3,440	150	50 x 30 x 6 x 40	Approx. 108	5	400
114-7030	UF5025	60	¥2,617	¥3,230	60	50 x 25 x 6 x 40	Approx. 85	5	360	114-7188	UF5030	180	¥2,786	¥3,440	180	50 x 30 x 6 x 40	Approx. 112	5	400
114-7048	UF5025	80	¥2,617	¥3,230	80	50 x 25 x 6 x 40	Approx. 95	5	360	114-7196	UF5030	240	¥2,786	¥3,440	240	50 x 30 x 6 x 40	Approx. 130	5	400
114-7056	UF5025	100	¥2,617	¥3,230	100	50 x 25 x 6 x 40	Approx. 102	5	360	114-7200	UF5030	320	¥2,786	¥3,440	320	50 x 30 x 6 x 40	Approx. 145	5	400
114-7064	UF5025	120	¥2,617	¥3,230	120	50 x 25 x 6 x 40	Approx. 108	5	360	114-7218	UF5030	400	¥2,786	¥3,440	400	50 x 30 x 6 x 40	Approx. 162	5	400

### Outer Diameter 60mm Specs • Max Working Rotation Speed: 18000rpm

Order Unit: 1 Box										Order Unit: 1 Box									
Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)	Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
114-7226	UF6015	40	¥2,786	¥3,440	40	60 x 15 x 6 x 40	Approx. 60	5	306	114-7374	UF6025	150	¥3,062	¥3,780	150	60 x 25 x 6 x 40	Approx. 120	5	517
114-7234	UF6015	60	¥2,786	¥3,440	60	60 x 15 x 6 x 40	Approx. 92	5	326	114-7382	UF6025	180	¥3,062	¥3,780	180	60 x 25 x 6 x 40	Approx. 130	5	518
114-7242	UF6015	80	¥2,786	¥3,440	80	60 x 15 x 6 x 40	Approx. 105	5	318	114-7391	UF6025	240	¥3,062	¥3,780	240	60 x 25 x 6 x 40	Approx. 150	5	428
114-7251	UF6015	100	¥2,786	¥3,440	100	60 x 15 x 6 x 40	Approx. 120	5	315	114-7404	UF6025	320	¥3,062	¥3,780	320	60 x 25 x 6 x 40	Approx. 160	5	433
114-7269	UF6015	120	¥2,786	¥3,440	120	60 x 15 x 6 x 40	Approx. 120	5	320	114-7412	UF6025	400	¥3,062	¥3,780	400	60 x 25 x 6 x 40	Approx. 170	5	417
114-7277	UF6015	150	¥2,786	¥3,440	150	60 x 15 x 6 x 40	Approx. 120	5	322	114-7421	UF6030	40	¥3,240	¥4,000	40	60 x 30 x 6 x 40	Approx. 60	5	484
114-7285	UF6015	180	¥2,786	¥3,440	180	60 x 15 x 6 x 40	Approx. 130	5	323	114-7439	UF6030	60	¥3,240	¥4,000	60	60 x 30 x 6 x 40	Approx. 92	5	473
114-7293	UF6015	240	¥2,786	¥3,440	240	60 x 15 x 6 x 40	Approx. 150	5	318	114-7447	UF6030	80	¥3,240	¥4,000	80	60 x 30 x 6 x 40	Approx. 105	5	474
114-7307	UF6015	320	¥2,786	¥3,440	320	60 x 15 x 6 x 40	Approx. 160	5	307	114-7455	UF6030	100	¥3,240	¥4,000	100	60 x 30 x 6 x 40	Approx. 120	5	481
114-7315	UF6015	400	¥2,786	¥3,440	400	60 x 15 x 6 x 40	Approx. 170	5	304	114-7463	UF6030	120	¥3,240	¥4,000	120	60 x 30 x 6 x 40	Approx. 120	5	517
114-7323	UF6025	40	¥3,062	¥3,780	40	60 x 25 x 6 x 40	Approx. 60	5	425	114-7471	UF6030	150	¥3,240	¥4,000	150	60 x 30 x 6 x 40	Approx. 120	5	509
114-7331	UF6025	60	¥3,062	¥3,780	60	60 x 25 x 6 x 40	Approx. 92	5	434	114-7480	UF6030	180	¥3,240	¥4,000	180	60 x 30 x 6 x 40	Approx. 130	5	502
114-7340	UF6025	80	¥3,062	¥3,780	80	60 x 25 x 6 x 40	Approx. 105	5	435	114-7498	UF6030	240	¥3,240	¥4,000	240	60 x 30 x 6 x 40	Approx. 150	5	487
114-7358	UF6025	100	¥3,062	¥3,780	100	60 x 25 x 6 x 40	Approx. 120	5	432	114-7501	UF6030	320	¥3,240	¥4,000	320	60 x 30 x 6 x 40	Approx. 160	5	458
114-7366	UF6025	120	¥3,062	¥3,780	120	60 x 25 x 6 x 40	Approx. 120	5	446	114-7510	UF6030	400	¥3,240	¥4,000	400	60 x 30 x 6 x 40	Approx. 170	5	475

### Outer Diameter 80mm Specs • Max Working Rotation Speed: 15000rpm

Order Unit: 1 Box										Order Unit: 1 Box									
Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)	Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
114-7528	UF8015	40	¥3,483	¥4,300	40	80 x 15 x 6 x 40	Approx. 75	5	492	114-7676	UF8025	150	¥3,848	¥4,750	150	80 x 25 x 6 x 40	Approx. 147	5	709
114-7536	UF8015	60	¥3,483	¥4,300	60	80 x 15 x 6 x 40	Approx. 104	5	494	114-7684	UF8025	180	¥3,848	¥4,750	180	80 x 25 x 6 x 40	Approx. 153	5	701
114-7544	UF8015	80	¥3,483	¥4,300	80	80 x 15 x 6 x 40	Approx. 125	5	480	114-7692	UF8025	240	¥3,848	¥4,750	240	80 x 25 x 6 x 40	Approx. 187	5	685
114-7552	UF8015	100	¥3,483	¥4,300	100	80 x 15 x 6 x 40	Approx. 135	5	482	114-7706	UF8025	320	¥3,848	¥4,750	320	80 x 25 x 6 x 40	Approx. 200	5	672
114-7561	UF8015	120	¥3,483	¥4,300	120	80 x 15 x 6 x 40	Approx. 138	5	503	114-7714	UF8025	400	¥3,848	¥4,750	400	80 x 25 x 6 x 40	Approx. 203	5	653
114-7579	UF8015	150	¥3,483	¥4,300	150	80 x 15 x 6 x 40	Approx. 147	5	516	114-7722	UF8030	40	¥4,131	¥5,100	40	80 x 30 x 6 x 40	Approx. 75	5	800
114-7587	UF8015	180	¥3,483	¥4,300	180	80 x 15 x 6 x 40	Approx. 153	5	505	114-7731	UF8030	60	¥4,131	¥5,100	60	80 x 30 x 6 x 40	Approx. 104	5	784
114-7595	UF8015	240	¥3,483	¥4,300	240	80 x 15 x 6 x 40	Approx. 187	5	500	114-7749	UF8030	80	¥4,131	¥5,100	80	80 x 30 x 6 x 40	Approx. 125	5	739
114-7609	UF8015	320	¥3,483	¥4,300	320	80 x 15 x 6 x 40	Approx. 200	5	477	114-7757	UF8030	100	¥4,131	¥5,100	100	80 x 30 x 6 x 40	Approx. 135	5	735
114-7617	UF8015	400	¥3,483	¥4,300	400	80 x 15 x 6 x 40	Approx. 203	5	461	114-7765	UF8030	120	¥4,131	¥5,100	120	80 x 30 x 6 x 40	Approx. 138	5	813
114-7625	UF8025	40	¥3,848	¥4,750	40	80 x 25 x 6 x 40	Approx. 75	5	680	114-7773	UF8030	150	¥4,131	¥5,100	150	80 x 30 x 6 x 40	Approx. 147	5	820
114-7633	UF8025	60	¥3,848	¥4,750	60	80 x 25 x 6 x 40	Approx. 104	5	680	114-7781	UF8030	180	¥4,131	¥5,100	180	80 x 30 x 6 x 40	Approx. 153	5	823
114-7641	UF8025	80	¥3,848	¥4,750	80	80 x 25 x 6 x 40	Approx. 125	5	666	114-7790	UF8030	240	¥4,131	¥5,100	240	80 x 30 x 6 x 40	Approx. 187	5	758
114-7650	UF8025	100	¥3,848	¥4,750	100	80 x 25 x 6 x 40	Approx. 135	5	687	114-7803	UF8030	320	¥4,131	¥5,100	320	80 x 30 x 6 x 40	Approx. 200	5	745
114-7668	UF8025	120	¥3,848	¥4,750	120	80 x 25 x 6 x 40	Approx. 138	5	729	114-7811	UF8030	400	¥4,131	¥5,100	400	80 x 30 x 6 x 40	Approx. 203	5	727

### Outer Diameter 100mm Specs • Max Working Rotation Speed: 10000rpm

Order Unit: 1 Box										Order Unit: 1 Box									
Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)	Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
114-7820	UF1025	40	¥4,601	¥5,680	40	100 x 25 x 6 x 40	Approx. 75	5	892	114-7871	UF1025	150	¥4,601	¥5,680	150	100 x 25 x 6 x 40	Approx. 147	5	823
114-7838	UF1025	60	¥4,601	¥5,680	60	100 x 25 x 6 x 40	Approx. 104	5	880	114-7889	UF1025	180	¥4,601	¥5,680	180	100 x 25 x 6 x 40	Approx. 153	5	924
114-7846	UF1025	80	¥4,6																