



Stock 38,650 Items

Spin Screw Type Nylon Flap Wheel (shaft replacement type)



UFNS425-120 (outer diameter 40mm)

Estimated Unit Price per Piece ¥767



UFNS525-120 (outer diameter 50mm)

Estimated Unit Price per Piece ¥773



UFNS625-120 (outer diameter 60mm)

Estimated Unit Price per Piece ¥904



UFNS825-120 (outer diameter 80mm)

Estimated Unit Price per Piece ¥1,047



SS-6040 (spinning axle (shaft diameter 6mm))

SS-6100 (spinning axle (shaft diameter 6mm))

SSB-6040 (spinning axle (hexagonal shaft))

Features •The shaft is screw thread in, you can detach with one touch.

 

- You can replace the shaft while attaching it to the chuck.
- By using the spin shaft sold separately, can replace the standard length (40mm) and deep hole (100mm) shaft.

Use

- Dual purpose for stainless steel, general metal.
- Paint removal, polishing before plating. Optimum for polishing stainless steel, iron, alloy, wood, plastic etc.

Specs Origin

- Working tool: straight grinder, rechargeable impact screwdriver (when hexagon shaft is used)
- Max Working Rotation Speed: 3000rpm
- Japan

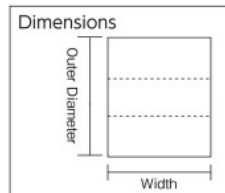

Warning
•Spinning axle is sold separately.

Outer Diameter 40mm

Order Unit: 1 Box

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter (mm)	Width (mm)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
437-3090	UFNS425-120	¥3,832	¥4,730	120	40	25	23	5	20	142
437-3103	UFNS425-240	¥3,832	¥4,730	240	40	25	22	5	20	115
437-3111	UFNS425-320	¥3,832	¥4,730	320	40	25	23	5	20	116
437-3120	UFNS425-600	¥3,832	¥4,730	600	40	25	24	5	20	112

Outer Diameter 50mm

Order Unit: 1 Box

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter (mm)	Width (mm)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
437-3138	UFNS525-120	¥3,864	¥4,770	120	50	25	36	5	20	216
437-3146	UFNS525-240	¥3,864	¥4,770	240	50	25	31	5	20	173
437-3154	UFNS525-320	¥3,864	¥4,770	320	50	25	33	5	20	170
437-3162	UFNS525-600	¥3,864	¥4,770	600	50	25	40	5	20	157

Outer Diameter 60mm


Order Unit: 1 Box

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter (mm)	Width (mm)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
437-3171	UFNS625-120	¥4,520	¥5,580	120	60	25	36	5	20	302
437-3189	UFNS625-240	¥4,520	¥5,580	240	60	25	31	5	20	222
437-3197	UFNS625-320	¥4,520	¥5,580	320	60	25	33	5	20	233
437-3201	UFNS625-600	¥4,520	¥5,580	600	60	25	40	5	20	215

Outer Diameter 80mm

Order Unit: 1 Box

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter (mm)	Width (mm)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
437-3219	UFNS825-120	¥5,233	¥6,460	120	80	25	44	5	20	459
437-3227	UFNS825-240	¥5,233	¥6,460	240	80	25	46	5	20	354
437-3235	UFNS825-320	¥5,233	¥6,460	320	80	25	50	5	20	385
437-3243	UFNS825-600	¥5,233	¥6,460	600	80	25	55	5	20	348

 

Spinning Axle (shaft diameter 6mm)

•Please be sure to check the conditions of use.

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Shaft Diameter (mm)	Shaft Length (mm)	SPQ (piece)	Weight (g)
275-8652	SS-6040	¥194	¥240	6	40	1	11.2
275-8661	SS-6100	¥384	¥475	6	100	1	28.0

Spinning Shaft (hexagon shaft)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Shaft Diameter (mm)	Shaft Length (mm)	SPQ (piece)	Weight (g)
437-4533	SSB-6040	¥194	¥240	6.35	40	1	17

Contact us:0120-509-849 <http://www.orange-book.com/>