

Shank Mounted Stones

The number next to the logo mark indicates items in stock for each brand.

Grinding Wheels

Disk Papers

Papers for Double Action Sander

Nylon Discs

Urethane Discs

Felt Discs

Diamond Wheels

Grinding Wheels

Dressers

Flap Wheels

Nylon Wheel with Shaft

Shank Mounted Felt Wheels with Shaft

Bands

Shank Mounted Stones

Carbide Bars

Diamond Bars

CBN Bars

Files

Diamond Files

Grinding Stones

Abrasives

Sheet Sanding Papers

Abrasive Belts

Cup Brushes

Wheel Brushes with Shank

Hand Brushes



Stock 38,650 Items

High Durability Whetstone with Shaft (shaft diameter 6mm)



- Features**
- Excellent polishing performance of 3 times higher durability by increasing the content of ceramic compared to existing products.
 - Finish surface precision is improved.
 - Since ceramic powder and alumina oxide raw material are sintered to synthetic rubber, abrasive grains are less likely to fall off and durability is excellent.
 - There is no fluctuation of the grindstones as performing the outer shape finish.
- Use**
- Optimum for fine scratches and burring.
 - Optimum for mirror surface finishing.
- Origin**
- Japan



RE815C (#80, red)

#80 Series/Color: Red

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
430-8662	RE815C	¥2,870	¥3,100	80	15 x 20 x 6 x 35	15000	5	10	90
430-8671	RE820C	¥3,055	¥3,300	80	20 x 25 x 6 x 35	15000	5	10	160
430-8689	RE825C	¥3,425	¥3,700	80	25 x 25 x 6 x 35	15000	5	10	220

TRUSCO NAKAYAMA CORPORATION

Estimated Unit Price per Piece
 ¥573 to ¥685



LB1215M (#120, blue)

#120 Series/Color: Blue

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
430-8697	LB1215M	¥2,870	¥3,100	120	15 x 20 x 6 x 35	15000	5	10	90
430-8701	LB1220M	¥3,055	¥3,300	120	20 x 25 x 6 x 35	15000	5	10	160
430-8719	LB1225M	¥3,425	¥3,700	120	25 x 25 x 6 x 35	15000	5	10	220

Estimated Unit Price per Piece
 ¥573 to ¥685




GR2215F (#220, green)

#220 Series/Color: Green

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
430-8727	GR2215F	¥2,870	¥3,100	220	15 x 20 x 6 x 35	15000	5	10	90
430-8735	GR2220F	¥3,055	¥3,300	220	20 x 25 x 6 x 35	15000	5	10	160
430-8743	GR2225F	¥3,425	¥3,700	220	25 x 25 x 6 x 35	15000	5	10	220

Estimated Unit Price per Piece
 ¥573 to ¥685

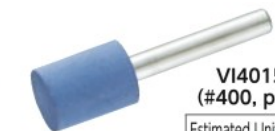

VI4015VF (#400, purple)

#400 Series/Color: Purple

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
430-8751	VI4015VF	¥2,870	¥3,100	400	15 x 20 x 6 x 35	15000	5	10	90
430-8760	VI4020VF	¥3,055	¥3,300	400	20 x 25 x 6 x 35	15000	5	10	160
430-8778	VI4025VF	¥3,425	¥3,700	400	25 x 25 x 6 x 35	15000	5	10	220

Estimated Unit Price per Piece
 ¥573 to ¥685



BR6015SF (#600, brown)

#600 Series/Color: Brown

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
430-8786	BR6015SF	¥2,870	¥3,100	600	15 x 20 x 6 x 35	15000	5	10	90
430-8794	BR6020SF	¥3,055	¥3,300	600	20 x 25 x 6 x 35	15000	5	10	160
430-8808	BR6025SF	¥3,425	¥3,700	600	25 x 25 x 6 x 35	15000	5	10	220

Estimated Unit Price per Piece
 ¥573 to ¥685



GY10015VS (#1000, gray)

#1000 Series/Color: Gray

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
430-8816	GY10015VS	¥3,147	¥3,400	1000	15 x 20 x 6 x 35	15000	5	10	90
430-8824	GY10020VS	¥3,333	¥3,600	1000	20 x 25 x 6 x 35	15000	5	10	160
430-8832	GY10025VS	¥3,888	¥4,200	1000	25 x 25 x 6 x 35	15000	5	10	220

Estimated Unit Price per Piece
 ¥630 to ¥778

Contact us: 0120-509-849 <http://www.orange-book.com/>