

The number next to the logo mark indicates items in stock for each brand.

Welding Machines

Engine Welders

Spot Welders

Plasma Cutting Machines

Welding Tables

Welding Rods

Accessories for Welding Equipment

Welding Scale Removers

Gas Torches

Gas Burners

Gas Cutting Equipments

Gas Regulators

Brazing Filler Metals

Welding Masks

Protective Eyewears for Welding

Protective Tools for Welding

Spatter Sheets


Protective Fences for Welding

Industrial Markers



Stock 38,650 Items

Tungsten Electrode Rod for TIG Welding

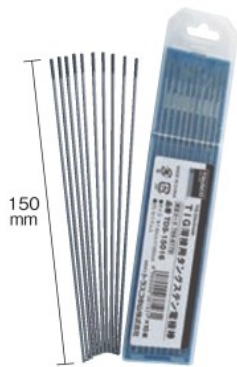

TDS-15016

- Features**
- It is a tungsten electrode rod that can be used for both DC/AC welding.
 - Especially suitable for aluminum welding.
- Use**
- For TIG welding.
- Specs**
- 2% Cerium Input
- Origin**
- China

2% Cerium for TIG Welding Suitable Welding Current Range (A)

Item No.	DC (electrode negative)	Alternating Current
	Iron, Stainless	Aluminum
TDS-15016	60 to 150A	40 to 130A
TDS-15020	120 to 200A	60 to 180A
TDS-15024	170 to 250A	70 to 220A
TDS-15032	225 to 330A	110 to 290A

Order Unit: 10 Pieces

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Electrode Diameter (mm)	Length (mm)	Weight (g)
765-8770	TDS-15016	¥314*	¥340*	10	1.6	150	5.6
765-8788	TDS-15020	¥454*	¥490*	10	2.0	150	8.7
765-8796	TDS-15024	¥555*	¥600*	10	2.4	150	12.3
765-8800	TDS-15032	¥972*	¥1,050*	10	3.2	150	21.5


TRUSCO NAKAYAMA CORPORATION

Contact us: 0120-509-849 <http://www.orange-book.com/>




Stock 40 Items

Tungsten Electrode Rod for TIG Welding

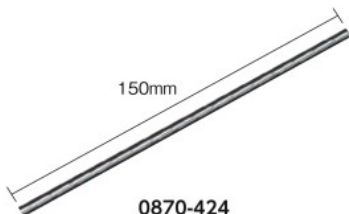

0870-424

- Use**
- For TIG welding.
- Specs**
- 2% Cerium Input
- Origin**
- China

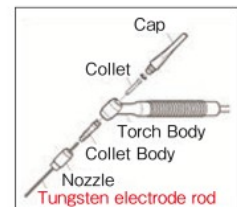

Order Unit: 10 Pieces

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Electrode Diameter (mm)	Length (mm)	Weight (g)
854-9805	0870-416	¥329*	¥305*	10	1.6	150	8
854-9806	0870-424	¥567*	¥525*	10	2.4	150	15
854-9807	0870-432	¥1,058*	¥980*	10	3.2	150	24

DAIHEN Welding Mechatronics System Corporation

URL <http://www.dwms.co.jp/>

Summer




Stock 11 Items

Purge Dam



S786001 (coupler connection type)

- Features**
- Purges the inside of a 6-inch piping to 1% or less oxygen within 3 minutes.
 - Air bags are resistant to heat and spark.
 - Durable stainless steel spiral hose is used for the center part.
- Use**
- For reduction in usage of back shield gas and reduction in work time when welding.
- Origin**
- USA

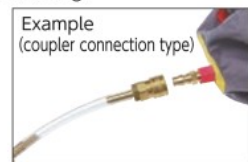


Coupler Connection Type

- Specs**
- Hose connection side: 9mm (socket)
 - Balloon connection side: PT1/4 inches (plug)
- Accessories**
- Coupler socket, coupler plug

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Size	Filling hose	SPQ (piece)	Weight (g)
829-1448	S786000	¥54,810	¥58,000	50mm (2 inches)	1 Piece	1	450
829-1449	S786001	¥59,535	¥63,000	75mm (3 inches)	1 Piece	1	450
829-1450	S786002	¥78,435	¥83,000	100mm (4 inches)	1 Piece	1	450
829-1451	S786045	¥76,829	¥81,300	125mm (5 inches)	1 Piece	1	450
829-1452	S786003	¥83,160	¥88,000	150mm (6 inches)	1 Piece	1	450
829-1453	S786004	¥87,885	¥93,000	200mm (8 inches)	1 Piece	1	500
829-1454	S786005	¥94,500	¥100,000	250mm (10 inches)	1 Piece	1	600

SAMNER

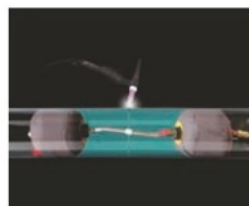

It is easy to confirm the alignment since there is luminous tape at the center.

Hand Tightening Connection Type

- Specs**
- Hose connection side: 1/4 inches, 3/8 inches
 - Balloon connection side: PT1/4 inches
- Accessories**
- Hose plug x 2, 1/4 plug screw

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Size	Filling hose	SPQ (piece)	Weight (g)
829-1455	S786006	¥104,895	¥111,000	300mm (12 inches)	2 Pieces	1	850
829-1456	S786007	¥113,400	¥120,000	350mm (14 inches)	2 Pieces	1	860
829-1457	S786008	¥121,905	¥129,000	400mm (16 inches)	2 Pieces	1	900

Contact us: 052-911-7165 <http://www.asada.co.jp/>