

Spatter Sheets/Heat-insulating Mats

The number next to the logo mark indicates items in stock for each brand.

Welding Machines

Engine Welders

Spot Welders

Plasma Cutting Machines

Welding Tables

Welding Rods

Accessories for Welding Equipment

Welding Scale Removers

Gas Torches

Gas Burners

Gas Cutting Equipments

Gas Regulators

Brazing Filler Metals

Welding Masks

Protective Eyewears for Welding

Protective Tools for Welding

Spatter Sheets

Protective Fences for Welding

Industrial Markers

TRUSCO **Stock 38,650 Items**

Spatter Sheet "Gold" (no coating)



Com **eco** Chemical Content Inspection
Com **Drawing**




SPS-4G



SPS-RG (roll)

- Features**
- It is the finest type.
 - Adheres received sparks and slag.
 - Safe product not containing asbestos and RCF (refractory ceramic fiber).
 - Fits softly to the workpieces.
 - Strong against tearing and tearing and excellent in durability.
 - For slag receiving work. (Becomes more effective by sprinkling water)
- Use**
- Specs**
- JIS A 1323 Class A Passing No. 55220
 - (foundation) Japan Fire Retardant Association Flame Retardant Performance Test No. C2120013
 - Thickness: 1.32mm
- Materials**
- Silica Fiber (highly heat-resistant glass fiber)
- Origin**
- Latvia

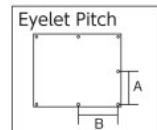

Order Unit: 1 Sheet

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
121-0254	SPS-1G	¥ 9,720	¥ 10,500	No. 1	4	780	880	820 x 920	10	1.13
121-0262	SPS-2G	¥ 19,440	¥ 21,000	No. 2	12	390	470	820 x 1920	5	2.25
121-0271	SPS-4G	¥ 38,880	¥ 42,000	No. 4	16	415	470	1700 x 1920	3	4.50
121-0289	SPS-6G	¥ 58,320	¥ 63,000	No. 6	20	415	480	1700 x 2920	2	6.75
121-0297	SPS-RG	¥210,137	¥227,000	Roll	-	-	-	900 x 25m	1	25.00

Sell by Piece Type Features •You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★455-1354	SPS-RG-CUT	¥8,702	¥9,400	Cut	-	-	-	900 x In meter unit	1

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Spatter Sheet "Gold Alpha" (no coating)



Com **eco** Chemical Content Inspection
Com **Drawing**




SPS-4GA



SPS-RGA (roll)

- Features**
- Popular product of the gold type.
 - Adheres received sparks and slag.
 - Safe product not containing asbestos and RCF (refractory ceramic fiber).
 - Sparks scatter less.
 - Lightweight type, so it is convenient to carry.
 - For slag receiving work. (Becomes more effective by sprinkling water)
- Use**
- Specs**
- JIS A 1323 Class A Passing No. 55221
 - (foundation) Japan Fire Retardant Association Flame Retardant Performance Test No. C2120012
 - Thickness: 0.81mm
- Materials**
- Silica Fiber (highly heat-resistant glass fiber)
- Origin**
- Latvia

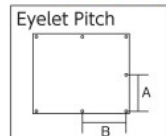

Order Unit: 1 Sheet

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
121-0173	SPS-1GA	¥ 5,693	¥ 6,150	No. 1	4	780	880	820 x 920	20	0.63
121-0181	SPS-2GA	¥11,386	¥ 12,300	No. 2	12	390	470	820 x 1920	10	1.27
121-0190	SPS-4GA	¥22,763	¥ 24,590	No. 4	16	415	470	1700 x 1920	6	2.54
121-0203	SPS-6GA	¥34,140	¥ 36,880	No. 6	20	415	480	1700 x 2920	4	3.81
121-0211	SPS-RGA	¥96,589	¥104,340	Roll	-	-	-	900 x 25m	1	14.00

Sell by Piece Type Features •You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★455-1346	SPS-RGA-CUT	¥4,397	¥4,750	Cut	-	-	-	900 x In meter unit	0.56

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Non-combustible Heat Insulating Mat



FDM-2030

Cloth

- Features**
- You can use spatter sheet alpha gold (passed JIS A1323 A type) as outer material and alumina fiber blanket for inner material and also as high temperature heat insulation material.
 - Spatter sheet alpha gold of external material the silica fiber (high heat resistance glass fiber) which is the fabric of gold alpha is inorganic, so the product itself will not burn up.
 - You can work without removing the cords, hoses, plastic parts when hoisting the automobile sheet metal body.
 - Working more efficiently with spatter sheets combined.
 - Safe product not containing asbestos and RCF (refractory ceramic fiber).
 - For piping brazing work.
 - To prevent burning accident of wallboard, wallpaper.
 - For attaching PVC pipe, to work on it.
 - P tile, to protect the width wood made from PVC.
- Use**
- Available separately: Up to 900 x 600mm
 - Thickness: Approx. 15mm
- Materials**
- Exterior Material: Spatter Sheet Alpha Gold (silica fiber)
 - Inner Material: Alumina Fiber Blanket
- Origin**
- Japan



Example
Ideal for pipe brazing work

Order Unit: 1 Sheet

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	W x L (mm)	SPQ (sheet)	Weight (g)
177-2210	FDM-2030	¥ 6,646	¥ 7,180	200 x 300	20	175
177-2228	FDM-3040	¥13,219	¥14,280	300 x 400	10	350

Contact us:0120-509-849 <http://www.orange-book.com/>

What is alumina fiber blanket
High temperature refractory insulation material which is made by continuously laminating crystalline short fibers containing alumina, silica as the principal component. Since it does not fall under the RCF regulation, you can use it with confidence.

