

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items


## "Spatter Felt 20AD"

Made to Order



- Features**
- Coated with single-sided special flame retardant resin, spark repelling is good and the non-coated side on the back absorbs water and the safety aspect has improved.
  - There is no sewing thread at No. 4/ No. 6 of the sheet.
  - Dual purpose type for repelling of (front) and adhesion (back) to sparks and slag.
  - Safe with no asbestos/RCF.
- Specs**
- JIS A1323 Class C passing No. 02A1615
  - Thickness: 1.65mm
- Materials**
- Flame resistant fiber
  - Single-sided Special Flame Retardant Resin
- Origin**
- Japan

Front Repel Back Attach

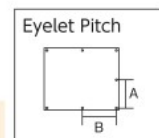

**Warning**  
• Can not be used to prevent spark scattering of the grindstone cutting equipment.

Order Unit: 1 Sheet (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
228-4651	20AD-1	¥ 3,888	¥ 4,200	No. 1	4	880	880	920 x 920	30	0.3
228-4669	20AD-2	¥ 7,776	¥ 8,400	No. 2	12	440	470	920 x 1920	15	0.6
228-4677	20AD-4	¥ 15,552	¥ 16,800	No. 4	16	470	470	1920 x 1920	10	1.2
228-4685	20AD-6	¥ 23,328	¥ 25,200	No. 6	20	470	480	1920 x 2920	6	1.8
228-4693	20AD-R	¥ 121,990	¥ 131,780	Roll	-	-	-	2000 x 20m	1	10.8



**Sell by Piece Type** Features • You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included | (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★455-1273	20AD-R-CUT	¥6,322	¥6,830	Cut	-	-	-	2000 x In meter unit	0.54

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items


## "Spatter Felt 28EX"

 Made to Order



- Features**
- Coated with single-sided special flame retardant resin, spark repelling is good and the non-coated side on the back absorbs water and the safety aspect has improved.
  - There is no sewing thread at No. 4/ No. 6 of the sheet.
  - Dual purpose type for repelling of (front) and adhesion (back) to sparks and slag.
  - Safe with no asbestos/RCF.
- Specs**
- JIS A1323 Class A passing No. 02A1158
  - Thickness: 2.5mm
- Materials**
- Flame resistant fiber
  - Single-sided Special Flame Retardant Resin
- Origin**
- Japan

Front Repel Back Attach



**Warning**  
• Can not be used to prevent spark scattering of the grindstone cutting equipment.

Order Unit: 1 Sheet (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
228-4596	28EX-1	¥ 4,962	¥ 5,360	No. 1	4	880	880	920 x 920	30	0.45
228-4600	28EX-2	¥ 9,914	¥ 10,710	No. 2	12	440	470	920 x 1920	15	0.90
228-4618	28EX-4	¥ 19,829	¥ 21,420	No. 4	16	470	470	1920 x 1920	10	1.80
228-4626	28EX-6	¥ 29,743	¥ 32,130	No. 6	20	470	480	1920 x 2920	6	2.70
228-4634	28EX-R	¥ 150,660	¥ 162,750	Roll	-	-	-	2000 x 20m	1	16.80



**Sell by Piece Type** Features • You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included | (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★455-1281	28EX-R-CUT	¥7,869	¥8,500	Cut	-	-	-	2000 x In meter unit	0.84

Contact us: 0120-509-849 <http://www.orange-book.com/>

Welding Machines

Engine Welders

Spot Welders

Plasma Cutting Machines

Welding Tables

Welding Rods

Accessories for Welding Equipment

Welding Scale Removers

Gas Torches

Gas Burners

Gas Cutting Equipments

Gas Regulators

Brazing Filler Metals

Welding Masks

Protective Eyeweares for Welding

Protective Tools for Welding

Spatter Sheets

Protective Fences for Welding

Industrial Markers