

Welding Shield Fences (stand alone type)

Stock 290Items


7-383

Prices displayed include 8% tax.


TRUSCO Stock 38,650 Items

Welding Shield Fence (stand alone type/steel) Fixed Foot Type

Com Drawing

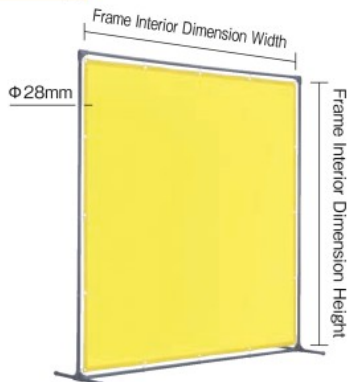

YFAK Type

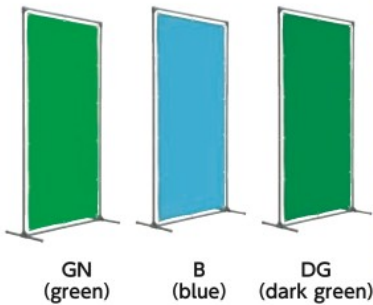

- Features**
- Shields harmful ultraviolet rays during welding and creates a comfortable working environment.
 - Since the frame is an infixing type, anyone can easily assemble it.
 - It can be expanded by combining with a connection type.
- Specs**
- (foundation) Japan Fire Retardant Association Flame Retardant Performance Test Number acquired (AT860027)
 - Resin Coated Steel Pipe Frame
 - Sheet thickness: 0.35mm
 - Frame Diameter: 28mm
- Materials**
- Sheet: PVC
- Origin**
- Japan

Ray Transmittance 74%	Ray Transmittance 8%	Ray Transmittance 33%	Ray Transmittance 1%
Y (yellow)	GN (green)	B (blue)	DG (dark green)

Warning
• Cannot be used for shielding of laser beam.

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Frame Interior Dimension (W x H) (mm)	Color	Foot Shape	SPQ (piece)	Weight (kg)
487-5559	YF1015K-DG	¥23,374	¥25,250	1000 x 1500	Dark Green	Fixed Foot	1	4.7
487-5567	YF1015K-GN	¥23,374	¥25,250	1000 x 1500	Green	Fixed Foot	1	4.7
487-5575	YF1015K-Y	¥23,374	¥25,250	1000 x 1500	Yellow	Fixed Foot	1	4.7
487-5541	YF1015K-B	¥23,374	¥25,250	1000 x 1500	Blue	Fixed Foot	1	4.7
487-6083	YFBK-DG	¥24,310	¥26,260	1000 x 2000	Dark Green	Fixed Foot	1	5.4
487-6091	YFBK-GN	¥24,310	¥26,260	1000 x 2000	Green	Fixed Foot	1	5.4
487-6105	YFBK-Y	¥24,310	¥26,260	1000 x 2000	Yellow	Fixed Foot	1	5.4
487-6075	YFBK-B	¥24,310	¥26,260	1000 x 2000	Blue	Fixed Foot	1	5.4
487-5711	YF1515K-DG	¥28,225	¥30,490	1500 x 1500	Dark Green	Fixed Foot	1	5.6
487-5729	YF1515K-GN	¥28,225	¥30,490	1500 x 1500	Green	Fixed Foot	1	5.6
487-5737	YF1515K-Y	¥28,225	¥30,490	1500 x 1500	Yellow	Fixed Foot	1	5.6
487-5702	YF1515K-B	¥28,225	¥30,490	1500 x 1500	Blue	Fixed Foot	1	5.6
487-5877	YF2015K-DG	¥29,938	¥32,340	2000 x 1500	Dark Green	Fixed Foot	1	6.4
487-5885	YF2015K-GN	¥29,938	¥32,340	2000 x 1500	Green	Fixed Foot	1	6.4
487-5893	YF2015K-Y	¥29,938	¥32,340	2000 x 1500	Yellow	Fixed Foot	1	6.4
487-5869	YF2015K-B	¥29,938	¥32,340	2000 x 1500	Blue	Fixed Foot	1	6.4
487-6008	YFAK-DG	¥31,604	¥34,140	2000 x 2000	Dark Green	Fixed Foot	1	7.4
487-6016	YFAK-GN	¥31,604	¥34,140	2000 x 2000	Green	Fixed Foot	1	7.4
487-6024	YFAK-Y	¥31,604	¥34,140	2000 x 2000	Yellow	Fixed Foot	1	7.4
487-5991	YFAK-B	¥31,604	¥34,140	2000 x 2000	Blue	Fixed Foot	1	7.4

Contact us: 0120-509-849 <http://www.orange-book.com/>


TRUSCO Stock 38,650 Items

Welding Shield Fence (stand alone type/steel) with Caster

Com Drawing

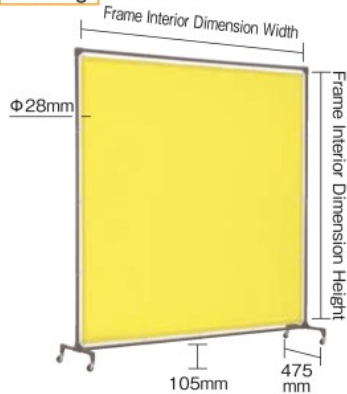

YFA Type

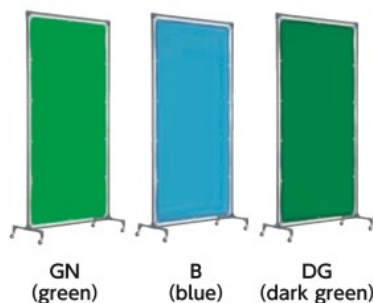

- Features**
- Shields harmful ultraviolet rays during welding and creates a comfortable working environment.
 - Since the frame is an infixing type, anyone can easily assemble it.
 - Equipped with casters that make it easy to move.
 - It can be expanded by combining with a connection type.
- Specs**
- (foundation) Japan Fire Retardant Association Flame Retardant Performance Test Number acquired (AT860027)
 - Resin Coated Steel Pipe Frame
 - Sheet thickness: 0.35mm
 - Frame Diameter: 28mm
 - Caster diameter: φ50mm
- Materials**
- Sheet: PVC
- Origin**
- Japan

Ray Transmittance 74%	Ray Transmittance 8%	Ray Transmittance 33%	Ray Transmittance 1%
Y (yellow)	GN (green)	B (blue)	DG (dark green)

Warning
• Cannot be used for shielding of laser beam.



Example

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Frame Interior Dimension (W x H) (mm)	Color	Foot Shape	SPQ (piece)	Weight (kg)
487-5524	YF1015-DG	¥23,374	¥25,250	1000 x 1500	Dark Green	Caster Type	1	5.6
487-5532	YF1015-GN	¥23,374	¥25,250	1000 x 1500	Green	Caster Type	1	5.6
487-5664	YF1015-Y	¥23,374	¥25,250	1000 x 1500	Yellow	Caster Type	1	5.6
487-5516	YF1015-B	¥23,374	¥25,250	1000 x 1500	Blue	Caster Type	1	5.6
255-2981	YFB-DG	¥24,310	¥26,260	1000 x 2000	Dark Green	Caster Type	1	6.3
255-2973	YFB-GN	¥24,310	¥26,260	1000 x 2000	Green	Caster Type	1	6.3
255-2965	YFB-Y	¥24,310	¥26,260	1000 x 2000	Yellow	Caster Type	1	6.3
328-9583	YFB-B	¥24,310	¥26,260	1000 x 2000	Blue	Caster Type	1	6.3
487-5681	YF1515-DG	¥28,225	¥30,490	1500 x 1500	Dark Green	Caster Type	1	6.5
487-5699	YF1515-GN	¥28,225	¥30,490	1500 x 1500	Green	Caster Type	1	6.5
487-5826	YF1515-Y	¥28,225	¥30,490	1500 x 1500	Yellow	Caster Type	1	6.5
487-5672	YF1515-B	¥28,225	¥30,490	1500 x 1500	Blue	Caster Type	1	6.5
487-5842	YF2015-DG	¥29,938	¥32,340	2000 x 1500	Dark Green	Caster Type	1	7.3
487-5851	YF2015-GN	¥29,938	¥32,340	2000 x 1500	Green	Caster Type	1	7.3
487-5982	YF2015-Y	¥29,938	¥32,340	2000 x 1500	Yellow	Caster Type	1	7.3
487-5834	YF2015-B	¥29,938	¥32,340	2000 x 1500	Blue	Caster Type	1	7.3
255-2957	YFA-DG	¥31,604	¥34,140	2000 x 2000	Dark Green	Caster Type	1	8.3
255-2949	YFA-GN	¥31,604	¥34,140	2000 x 2000	Green	Caster Type	1	8.3
255-2931	YFA-Y	¥31,604	¥34,140	2000 x 2000	Yellow	Caster Type	1	8.3
328-9575	YFA-B	¥31,604	¥34,140	2000 x 2000	Blue	Caster Type	1	8.3

Contact us: 0120-509-849 <http://www.orange-book.com/>