


Welding Shield Fences (connection type)


The number next to the logo mark indicates items in stock for each brand.

TRUSCO **Stock 38,650 Items**

Welding Shield Fence (connection type/steel) Fixed Foot Type

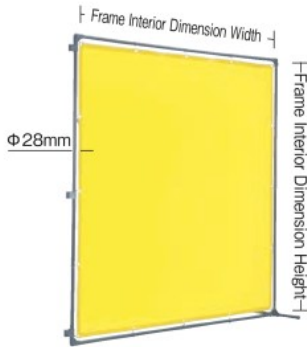

YFASK Type

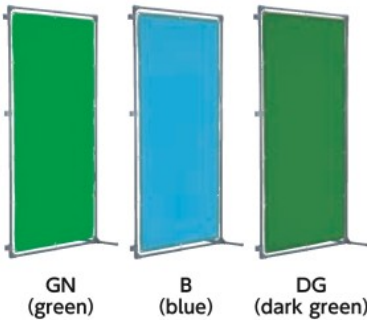

- Features**
- Shields harmful ultraviolet rays during welding and creates a comfortable working environment.
 - Since the frame is an infixing type, anyone can easily assemble it.
 - Can be added by connecting to the welding shield fence (stand alone type).
- Specs**
- (foundation) Japan Fire Retardant Association Flame Retardant Performance Test Number acquired (AT860027)
 - Resin Coated Steel Pipe Frame
 - Sheet thickness: 0.35mm
 - Frame Diameter: 28mm
- Materials**
- Sheet: PVC
- Origin**
- Japan



Example

Ray Transmittance 74% Y (yellow)	Ray Transmittance 8% GN (green)	Ray Transmittance 33% B (blue)	Ray Transmittance 1% DG (dark green)
-------------------------------------	------------------------------------	-----------------------------------	---

Warning

- Does not stand independently by connecting type alone. Please use in combination with a single body.
- Cannot be used for shielding of laser beam.


Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Frame Interior Dimension (W x H) (mm)	Color	Foot Shape	SPQ (piece)	Weight (kg)
487-5621	YF1015SK-DG	¥23,374	¥25,250	1000 x 1500	Dark Green	Fixed Foot	1	4.6
487-5630	YF1015SK-GN	¥23,374	¥25,250	1000 x 1500	Green	Fixed Foot	1	4.6
487-5648	YF1015SK-Y	¥23,374	¥25,250	1000 x 1500	Yellow	Fixed Foot	1	4.6
487-5613	YF1015SK-B	¥23,374	¥25,250	1000 x 1500	Blue	Fixed Foot	1	4.6
487-6121	YFBSK-DG	¥24,310	¥26,260	1000 x 2000	Dark Green	Fixed Foot	1	5.2
487-6130	YFBSK-GN	¥24,310	¥26,260	1000 x 2000	Green	Fixed Foot	1	5.2
487-6148	YFBSK-Y	¥24,310	¥26,260	1000 x 2000	Yellow	Fixed Foot	1	5.2
487-6113	YFBSK-B	¥24,310	¥26,260	1000 x 2000	Blue	Fixed Foot	1	5.2
487-5788	YF1515SK-DG	¥28,225	¥30,490	1500 x 1500	Dark Green	Fixed Foot	1	5.4
487-5796	YF1515SK-GN	¥28,225	¥30,490	1500 x 1500	Green	Fixed Foot	1	5.4
487-5800	YF1515SK-Y	¥28,225	¥30,490	1500 x 1500	Yellow	Fixed Foot	1	5.4
487-5770	YF1515SK-B	¥28,225	¥30,490	1500 x 1500	Blue	Fixed Foot	1	5.4
487-5940	YF2015SK-DG	¥29,938	¥32,340	2000 x 1500	Dark Green	Fixed Foot	1	6.3
487-5958	YF2015SK-GN	¥29,938	¥32,340	2000 x 1500	Green	Fixed Foot	1	6.3
487-5966	YF2015SK-Y	¥29,938	¥32,340	2000 x 1500	Yellow	Fixed Foot	1	6.3
487-5931	YF2015SK-B	¥29,938	¥32,340	2000 x 1500	Blue	Fixed Foot	1	6.3
487-6041	YFASK-DG	¥31,604	¥34,140	2000 x 2000	Dark Green	Fixed Foot	1	7.2
487-6059	YFASK-GN	¥31,604	¥34,140	2000 x 2000	Green	Fixed Foot	1	7.2
487-6067	YFASK-Y	¥31,604	¥34,140	2000 x 2000	Yellow	Fixed Foot	1	7.2
487-6032	YFASK-B	¥31,604	¥34,140	2000 x 2000	Blue	Fixed Foot	1	7.2


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Welding Shield Fence (connection type/steel) with Caster

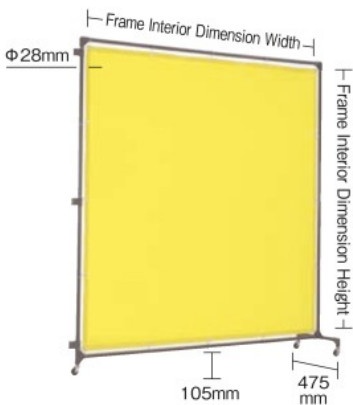

YFSA Type

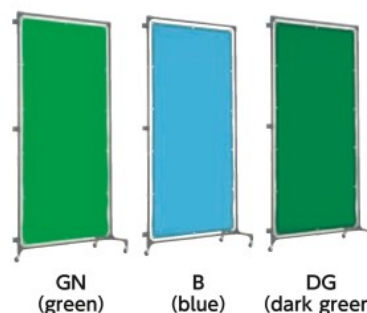

- Features**
- Shields harmful ultraviolet rays during welding and creates a comfortable working environment.
 - Since the frame is an infixing type, anyone can easily assemble it.
 - Equipped with casters that make it easy to move.
 - Can be added by connecting to the welding shield fence (stand alone type).
- Specs**
- (foundation) Japan Fire Retardant Association Flame Retardant Performance Test Number acquired (AT860027)
 - Resin Coated Steel Pipe Frame
 - Sheet thickness: 0.35mm
 - Frame Diameter: 28mm
 - Caster diameter: Φ50mm
- Materials**
- Sheet: PVC
- Origin**
- Japan

Ray Transmittance 74% Y (yellow)	Ray Transmittance 8% GN (green)	Ray Transmittance 33% B (blue)	Ray Transmittance 1% DG (dark green)
-------------------------------------	------------------------------------	-----------------------------------	---

Warning

- Does not stand independently by connecting type alone. Please use in combination with a single body.
- Cannot be used for shielding of laser beam.

Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Frame Interior Dimension (W x H) (mm)	Color	Foot Shape	SPQ (piece)	Weight (kg)
487-5591	YF1015S-DG	¥23,374	¥25,250	1000 x 1500	Dark Green	Caster Type	1	5.2
487-5605	YF1015S-GN	¥23,374	¥25,250	1000 x 1500	Green	Caster Type	1	5.2
487-5656	YF1015S-Y	¥23,374	¥25,250	1000 x 1500	Yellow	Caster Type	1	5.2
487-5583	YF1015S-B	¥23,374	¥25,250	1000 x 1500	Blue	Caster Type	1	5.2
255-3040	YFBS-DG	¥24,310	¥26,260	1000 x 2000	Dark Green	Caster Type	1	5.9
255-3031	YFBS-GN	¥24,310	¥26,260	1000 x 2000	Green	Caster Type	1	5.9
255-3023	YFBS-Y	¥24,310	¥26,260	1000 x 2000	Yellow	Caster Type	1	5.9
328-9605	YFBS-B	¥24,310	¥26,260	1000 x 2000	Blue	Caster Type	1	5.9
487-5753	YF1515S-DG	¥28,225	¥30,490	1500 x 1500	Dark Green	Caster Type	1	6.1
487-5761	YF1515S-GN	¥28,225	¥30,490	1500 x 1500	Green	Caster Type	1	6.1
487-5818	YF1515S-Y	¥28,225	¥30,490	1500 x 1500	Yellow	Caster Type	1	6.1
487-5745	YF1515S-B	¥28,225	¥30,490	1500 x 1500	Blue	Caster Type	1	6.1
487-5915	YF2015S-DG	¥29,938	¥32,340	2000 x 1500	Dark Green	Caster Type	1	6.9
487-5923	YF2015S-GN	¥29,938	¥32,340	2000 x 1500	Green	Caster Type	1	6.9
487-5974	YF2015S-Y	¥29,938	¥32,340	2000 x 1500	Yellow	Caster Type	1	6.9
487-5907	YF2015S-B	¥29,938	¥32,340	2000 x 1500	Blue	Caster Type	1	6.9
255-3015	YFAS-DG	¥31,604	¥34,140	2000 x 2000	Dark Green	Caster Type	1	7.9
255-3007	YFAS-GN	¥31,604	¥34,140	2000 x 2000	Green	Caster Type	1	7.9
255-2990	YFAS-Y	¥31,604	¥34,140	2000 x 2000	Yellow	Caster Type	1	7.9
328-9591	YFAS-B	¥31,604	¥34,140	2000 x 2000	Blue	Caster Type	1	7.9

Contact us: 0120-509-849 <http://www.orange-book.com/>