

Pierced Pipe Couplings (for fluororesin tube)

Stock 446Items

7-529

Prices displayed include 8% tax.




Stock 38,650 Items

Stainless Steel Coupling Male Elbow



TS8-02ML

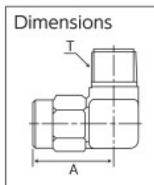


- Features • Connect with a fluorine resin tube.
 Use • Most suitable for clean air, purified water piping, chemicals, corrosive gas piping.
 • Food, chemical, medical treatment, semiconductor manufacturing, etc.
 Specs • Working Fluid: Clean Air, Purified Water (corrosive fluid) • Fluid Temperature: Water 0 to 100°C, Air -65 to 260°C
 Materials • Stainless Steel (SUS316) Origin • Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable Tube (mm) Outer Diameter x Inner Diameter	Screw T	Dimension A (mm)	SPQ (piece)	Weight (g)
256-1051	TS4-01ML	¥2,416	¥2,610	4 x 2	R1/8	22.0	10	40.0
256-1069	TS4-02ML	¥2,416	¥2,610	4 x 2	R1/4	22.0	10	40.0
256-1077	TS6-01ML	¥1,814	¥1,960	6 x 4	R1/8	22.0	10	41.8
256-1085	TS6-02ML	¥1,861	¥2,010	6 x 4	R1/4	22.0	10	37.0
256-1093	TS6-03ML	¥2,092	¥2,260	6 x 4	R3/8	27.5	10	71.0
256-1107	TS8-01ML	¥2,037	¥2,200	8 x 6	R1/8	23.5	10	43.7
256-1115	TS8-02ML	¥2,037	¥2,200	8 x 6	R1/4	23.5	10	43.0
256-1123	TS8-03ML	¥2,268	¥2,450	8 x 6	R3/8	29.0	10	72.0
256-1131	TS10-02ML	¥2,841	¥3,070	10 x 8	R1/4	27.5	10	72.6
256-1140	TS10-03ML	¥2,740	¥2,960	10 x 8	R3/8	27.5	10	78.2
256-1158	TS10-04ML	¥3,250	¥3,510	10 x 8	R1/2	32.0	10	131.5
256-1166	TS12-02ML	¥2,906	¥3,140	12 x 10	R1/4	33.0	10	135.5
256-1174	TS12-03ML	¥2,906	¥3,140	12 x 10	R3/8	33.0	10	133.0
256-1182	TS12-04ML	¥3,425	¥3,700	12 x 10	R1/2	33.0	10	133.5

 Contact us: 0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Stainless Steel Coupling Male Branch Tee



TS8-02MT

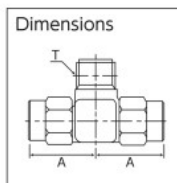

- Features • Connect with a fluorine resin tube.
 Use • Most suitable for clean air, purified water piping, chemicals, corrosive gas piping.
 • Food, chemical, medical treatment, semiconductor manufacturing, etc.
 Specs • Working Fluid: Clean Air, Purified Water (corrosive fluid) • Fluid Temperature: Water 0 to 100°C, Air -65 to 260°C
 Materials • Stainless Steel (SUS316) Origin • Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable Tube (mm) Outer Diameter x Inner Diameter	Screw T	Dimension A (mm)	SPQ (piece)	Weight (g)
256-1191	TS4-01MT	¥3,444	¥3,720	4 x 2	R1/8	22.0	10	50.8
256-1204	TS4-02MT	¥3,444	¥3,720	4 x 2	R1/4	22.0	10	50.2
256-1212	TS6-01MT	¥2,805	¥3,030	6 x 4	R1/8	22.0	10	54.2
256-1221	TS6-02MT	¥2,953	¥3,190	6 x 4	R1/4	22.0	10	53.7
256-1239	TS6-03MT	¥3,406	¥3,680	6 x 4	R3/8	27.5	10	90.7
256-1247	TS8-01MT	¥3,416	¥3,690	8 x 6	R1/8	23.5	10	58.5
256-1255	TS8-02MT	¥3,305	¥3,570	8 x 6	R1/4	23.5	10	58.0
256-1263	TS8-03MT	¥3,758	¥4,060	8 x 6	R3/8	29.0	10	92.5
256-1271	TS10-02MT	¥4,694	¥5,070	10 x 8	R1/4	27.5	10	96.0
256-1280	TS10-03MT	¥4,694	¥5,070	10 x 8	R3/8	27.5	10	102.5
256-1298	TS10-04MT	¥5,332	¥5,760	10 x 8	R1/2	32.0	10	162.5
256-1301	TS12-02MT	¥4,721	¥5,100	12 x 10	R1/4	33.0	10	170.0
256-1310	TS12-03MT	¥4,721	¥5,100	12 x 10	R3/8	33.0	10	167.0
256-1328	TS12-04MT	¥5,323	¥5,750	12 x 10	R1/2	33.0	10	168.0

Contact us: 0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Stainless Steel Coupling Male Run Tee



TS8-02RT

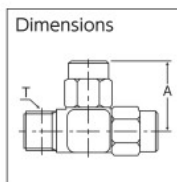

- Features • Connect with a fluorine resin tube.
 Use • Most suitable for clean air, purified water piping, chemicals, corrosive gas piping.
 • Food, chemical, medical treatment, semiconductor manufacturing, etc.
 Specs • Working Fluid: Clean Air, Purified Water (corrosive fluid) • Fluid Temperature: Water 0 to 100°C, Air -65 to 260°C
 Materials • Stainless Steel (SUS316) Origin • Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable Tube (mm) Outer Diameter x Inner Diameter	Screw T	Dimension A (mm)	SPQ (piece)	Weight (g)
256-1336	TS4-01RT	¥3,444	¥3,720	4 x 2	R1/8	22.0	10	50.8
256-1344	TS4-02RT	¥3,444	¥3,720	4 x 2	R1/4	22.0	10	50.2
256-1352	TS6-01RT	¥2,805	¥3,030	6 x 4	R1/8	22.0	10	54.2
256-1361	TS6-02RT	¥2,953	¥3,190	6 x 4	R1/4	22.0	10	53.7
256-1379	TS6-03RT	¥3,406	¥3,680	6 x 4	R3/8	27.5	10	90.7
256-1387	TS8-01RT	¥3,416	¥3,690	8 x 6	R1/8	23.5	10	58.5
256-1395	TS8-02RT	¥3,305	¥3,570	8 x 6	R1/4	23.5	10	58.0
256-1409	TS8-03RT	¥3,758	¥4,060	8 x 6	R3/8	29.0	10	92.5
256-1417	TS10-02RT	¥4,694	¥5,070	10 x 8	R1/4	27.5	10	96.0
256-1425	TS10-03RT	¥4,694	¥5,070	10 x 8	R3/8	27.5	10	102.5
256-1433	TS10-04RT	¥5,332	¥5,760	10 x 8	R1/2	32.0	10	162.5
256-1441	TS12-02RT	¥4,721	¥5,100	12 x 10	R1/4	33.0	10	170.0
256-1450	TS12-03RT	¥4,721	¥5,100	12 x 10	R3/8	33.0	10	167.0
256-1468	TS12-04RT	¥5,323	¥5,750	12 x 10	R1/2	33.0	10	168.0

Contact us: 0120-509-849 <http://www.orange-book.com/>