

Angles for Pipe Support

The number next to the logo mark indicates items in stock for each brand.

Valves

Screwed Type Pipe Fittings

High Pressure Joints

Welding Fittings

Flanges

Flexible Metal Hoses

Piping Joints for Minor Diameters

Sanitary Pipe Couplings

PVC Pipes

PVC Pipe Joints

PVC Valves

Joints for Water Piping

Protect Accessories for Plumbing

Support Accessories for Plumbing

Maintenance Accessories for Plumbing

Air Conditioning Materials

Valve Pipe Identifying Goods

Spray Nozzles

TRUSCO Stock 38,650 Items


Multi-bracket for Piping Support



Specs • Long Hole: 10 x 25mm • Nail Hole: 4.5mm Origin • Japan



TKLM-WB150-S

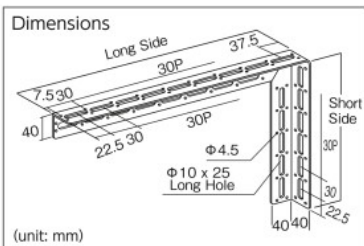

Stainless Steel Materials • Stainless Steel (SUS304)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Long Side (mm)	Short Side (mm)	Thickness (mm)	SPQ (piece)	Weight (kg)
287-2617	TKLM-WB150-S	¥1,527	¥1,650	150	120	3.0	10	0.5
287-2625	TKLM-WB210-S	¥1,962	¥2,120	210	150	3.0	10	0.6
287-2633	TKLM-WB300-S	¥2,703	¥2,920	300	210	3.0	10	0.9
287-2641	TKLM-WB390-S	¥3,333	¥3,600	390	240	3.0	10	1.1
287-2650	TKLM-WB510-S	¥4,240	¥4,580	510	300	3.0	10	1.4
287-2668	TKLM-WB600-S	¥4,767	¥5,150	600	300	3.0	10	1.6
287-2676	TKLM-WB690-S	¥6,017	¥6,500	690	390	3.0	10	1.9
287-2684	TKLM-WB810-S	¥6,711	¥7,250	810	390	3.0	10	2.1
287-2692	TKLM-WB900-S	¥7,776	¥8,400	900	510	3.0	10	2.5

Steel Materials • Steel (SPHC)

• Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Long Side (mm)	Short Side (mm)	Thickness (mm)	SPQ (piece)	Weight (kg)
287-2528	TKLM-WB150-U	¥555	¥600	150	120	3.2	10	0.5
287-2536	TKLM-WB210-U	¥676	¥730	210	150	3.2	10	0.7
287-2544	TKLM-WB300-U	¥861	¥930	300	210	3.2	10	1.0
287-2552	TKLM-WB390-U	¥1,018	¥1,100	390	240	3.2	10	1.2
287-2561	TKLM-WB510-U	¥1,250	¥1,350	510	300	3.2	10	1.5
287-2579	TKLM-WB600-U	¥1,389	¥1,500	600	300	3.2	10	1.7
287-2587	TKLM-WB690-U	¥1,648	¥1,780	690	390	3.2	10	2.0
287-2595	TKLM-WB810-U	¥1,805	¥1,950	810	390	3.2	10	2.3
287-2609	TKLM-WB900-U	¥2,110	¥2,280	900	510	3.2	10	2.6

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items


Safety Bracket for Pipe Support



Specs • Long Hole: 10 x 25mm • Nail Hole: 4.5mm Origin • Japan



TKC4-UB510-S

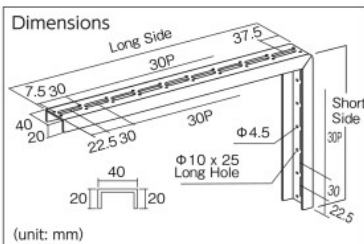

Stainless Steel Materials • Stainless Steel (SUS304)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Long Side (mm)	Short Side (mm)	Thickness (mm)	SPQ (piece)	Weight (kg)
287-2757	TKC4-UB150-S	¥1,500	¥1,620	150	120	3.0	10	0.4
287-2765	TKC4-UB210-S	¥1,851	¥2,000	210	150	3.0	10	0.6
287-2773	TKC4-UB300-S	¥2,453	¥2,650	300	210	3.0	10	0.8
287-2781	TKC4-UB390-S	¥2,888	¥3,120	390	240	3.0	10	1.0
287-2790	TKC4-UB510-S	¥3,471	¥3,750	510	300	3.0	10	1.3

Steel Materials • Steel (SPHC)

• Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Long Side (mm)	Short Side (mm)	Thickness (mm)	SPQ (piece)	Weight (kg)
287-2706	TKC4-UB150-U	¥814	¥880	150	120	3.2	10	0.5
287-2714	TKC4-UB210-U	¥954	¥1,030	210	150	3.2	10	0.6
287-2722	TKC4-UB300-U	¥1,185	¥1,280	300	210	3.2	10	0.9
287-2731	TKC4-UB390-U	¥1,379	¥1,490	390	240	3.2	10	1.1
287-2749	TKC4-UB510-U	¥1,630	¥1,760	510	300	3.2	10	1.4

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items


Double Use Facing Triangular Bracket for Pipe Support



Specs • Long Hole: 10 x 25mm • Nail Hole: 4.5mm Origin • Japan



TKL4-SB210-S

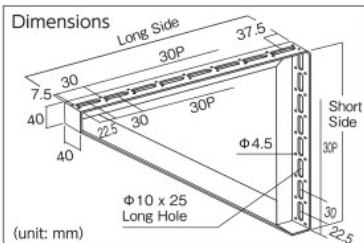

Stainless Steel Materials • Stainless Steel (SUS304)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Long Side (mm)	Short Side (mm)	Thickness (mm)	SPQ (piece)	Weight (kg)
287-2838	TKL4-SB210-S	¥6,295	¥6,800	210	210	3.0	10	1.3
287-2846	TKL4-SB300-S	¥7,822	¥8,450	300	300	3.0	8	1.9
287-2854	TKL4-SB360-S	¥8,887	¥9,600	360	360	3.0	6	2.2

Steel Materials • Steel (SPHC)

• Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Long Side (mm)	Short Side (mm)	Thickness (mm)	SPQ (piece)	Weight (kg)
287-2803	TKL4-SB210-U	¥2,453	¥2,650	210	210	3.2	10	1.4
287-2811	TKL4-SB300-U	¥2,870	¥3,100	300	300	3.2	8	1.9
287-2820	TKL4-SB360-U	¥3,194	¥3,450	360	360	3.2	6	2.3

Contact us:0120-509-849 <http://www.orange-book.com/>